


TECHSPEC®

12.5mm 532nm, Laser Line Non-Polarizing Cube Beamsplitter

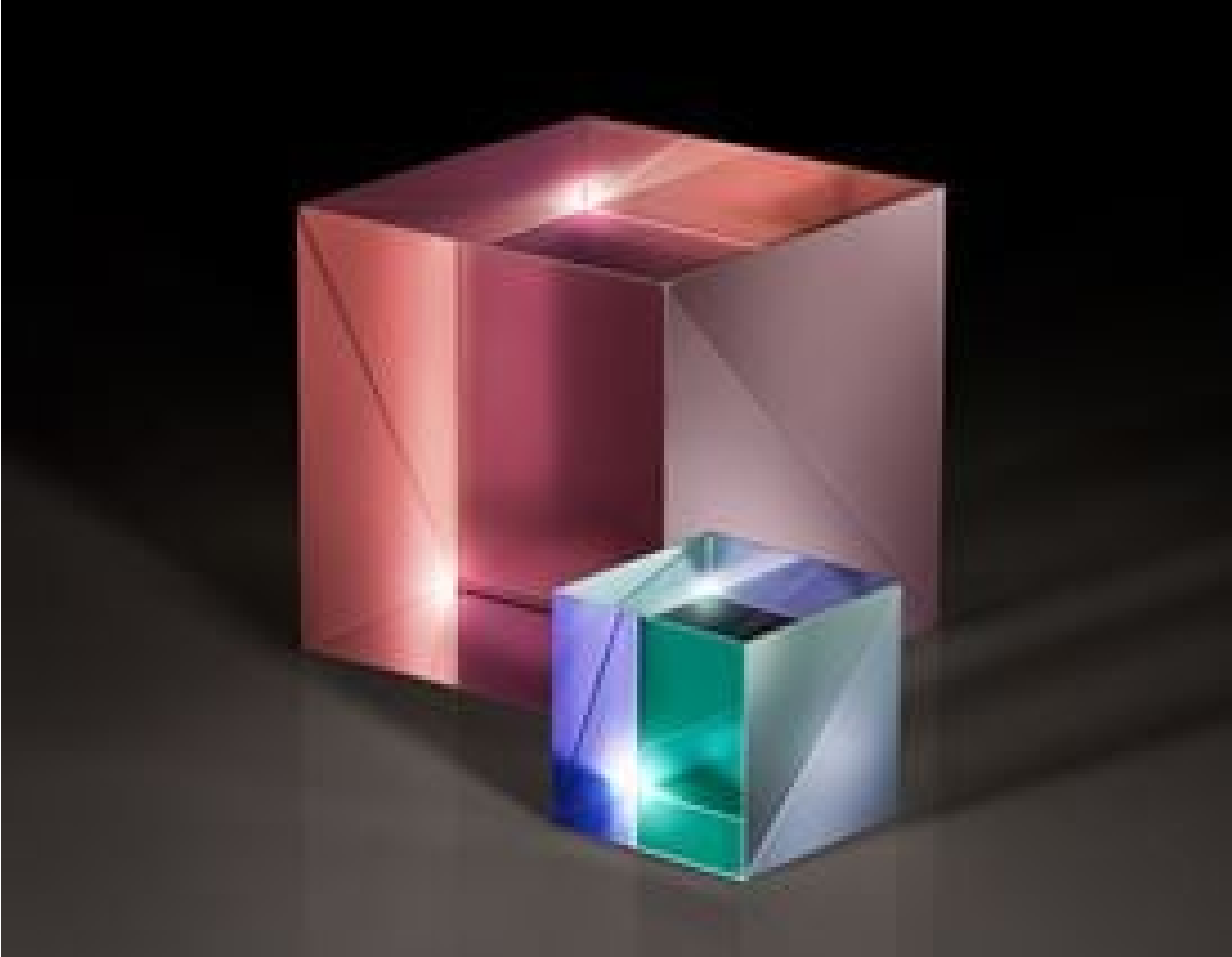

Laser Line Non-Polarizing Cube Beamsplitters



Stock #35-959 10 TO 12 DAYS

- 1 +

₹22,011.00

ADD TO CART

Qty 1-5
₹22,011.00
Qty 6+
₹17,618.00
Volume Pricing
Request Quote

Get Product Downloads

Beam Deviation (arcmin):
±2

Bevel:
Protective as needed

Clear Aperture (%):

90
Coating Specification: <0.25% Reflection on Entrance and Exit Faces
Construction: Cube
Design Wavelength DWL (nm): 532
Dimensions (mm): 12.5 x 12.5 x 12.5 ±0.1
Reflection/Transmission Tolerance (%): ±5
Substrate:  N-BK7
Surface Flatness (P-V): λ/8
Surface Quality: 40-20
Transmission (%): <45% ±5% @ DWL
Type: Non-Polarizing Beamsplitter
 Ts-Tp : <3% @ DWL

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View