

[See all 60 Products in Family](#)

TECHSPEC[®] 125mm, Center Drive, Standard Top, English Stage



TECHSPEC[®] Crossed-Roller Bearing Linear Translation Stages (Standard-Top Model)



[+2](#)

Stock #66-450 1 In Stock

-

1

+

₹44,377

ADD TO CART

Volume Pricing	
Qty 1-2	₹44,377 each
Qty 3+	₹38,736 each
Need More?	Request Quote

Product Downloads

General

Type:


English

Physical & Mechanical Properties


Type of Movement:

Linear (X)


Guide System:

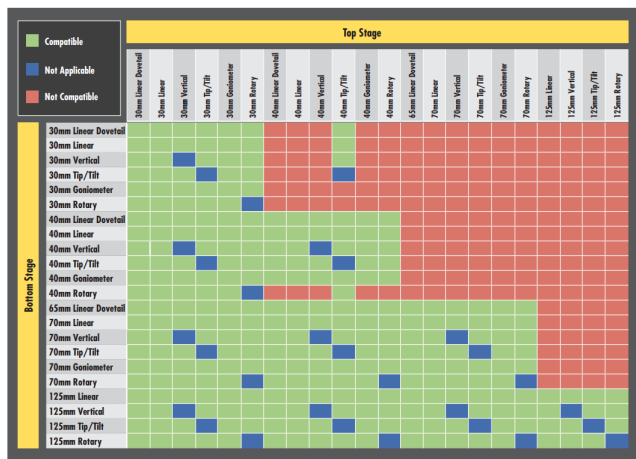


30mm Standard-Top Stages - Center Drive

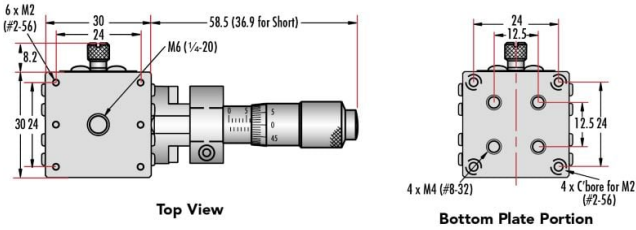


30mm Standard-Top Stages - Side Drive

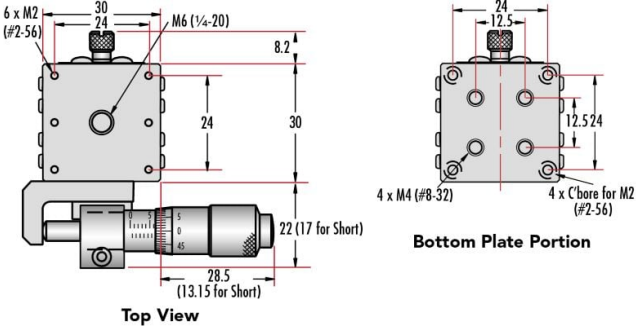


40mm Standard-Top Stages - Center Drive

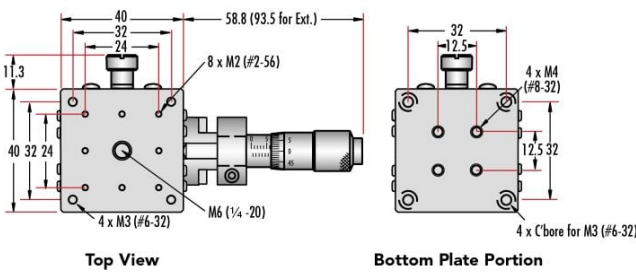


40mm Standard-Top Stages - Side Drive

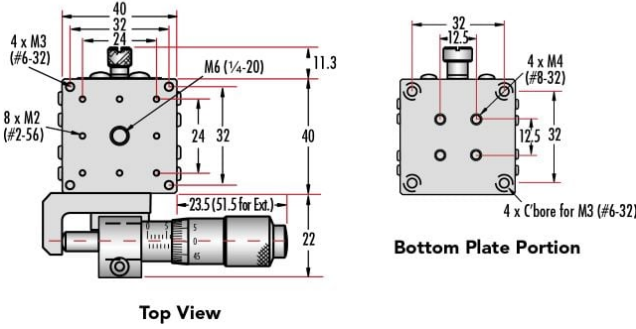


70mm Standard-Top Stages - Center Drive

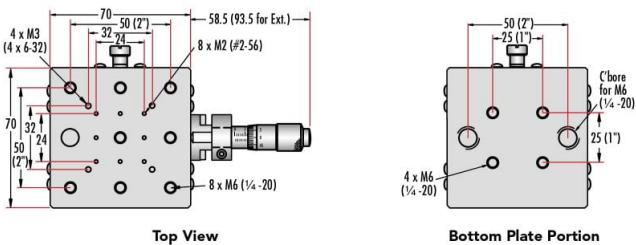

70mm Standard-Top Stages - Side Drive

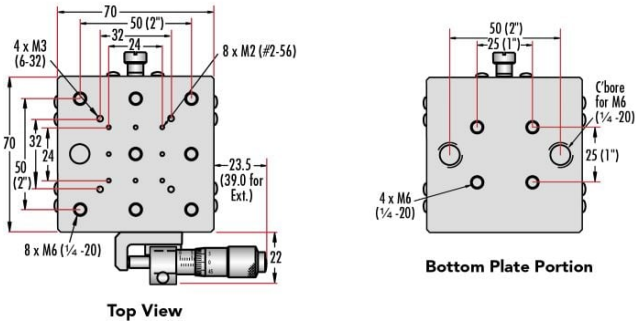

125mm Standard-Top Stages - Center Drive

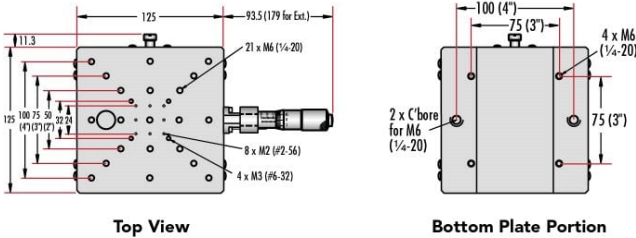

125mm Standard-Top Stages - Side Drive

