


12.5mm Dia. High Contrast UV Polarizer

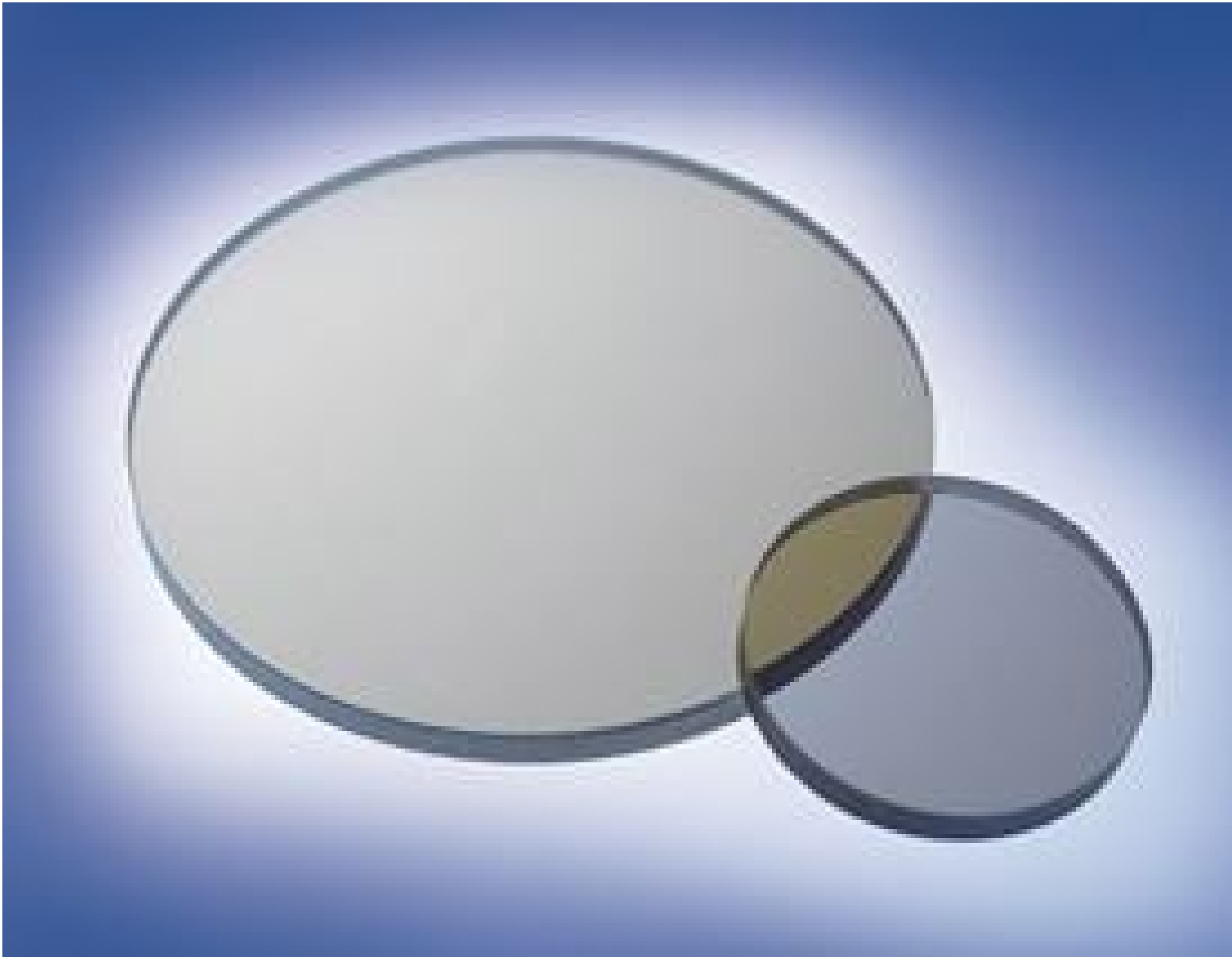

Stock #36-650 10 TO 12 DAYS

-

1

+

₹29,754.00

ADD TO CART

Qty 1-9
₹29,754.00
Qty 10+
₹25,839.00
Volume Pricing
Request Quote

Get Product Downloads

Angle of Incidence (°):
±20

Clear Aperture CA (mm):
11.25

Diameter (mm):
12.50

Extinction Ratio:
100,000:1

Substrate: Soda Lime Float Glass
Operating Temperature (°C): -20 to +80
Thickness (mm): 2.00
Thickness Tolerance (mm): ±0.2
Transmission (%): >51
Type: Linear Polarizer
Dimensional Tolerance (mm): +0.0/-0.2
Construction: Nanoparticle
Clear Aperture (%): 90
Transmitted Wavefront, P-V: < λ/4
Beam Deviation (arcmin): <1
Polarization Axis Mark (%): ±2
Wavelength Range (nm): 365 - 395

Regulatory Compliance

RoHS 2015: Compliant
Reach 197: Compliant
Certificate of Conformance: View