


TECHSPEC® 12.5mm Diameter Uncoated, Calcium Fluoride Window

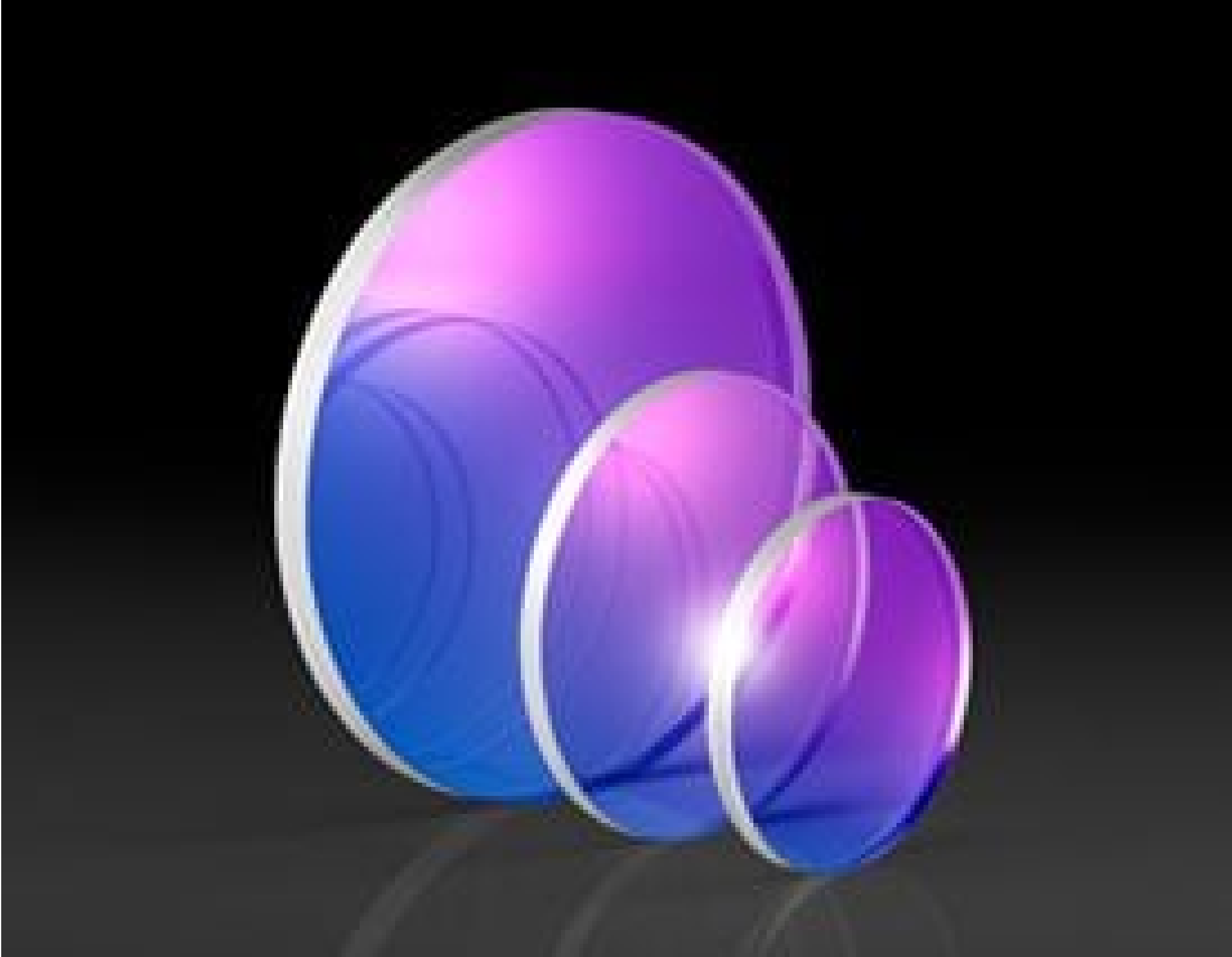

TECHSPEC Calcium Fluoride (CaF₂) Windows

Stock **#47-682** 10 TO 12 DAYS

⊖ 1 ⊕ **₹10,440.00**

ADD TO CART

Qty 1-10
₹10,440.00
Qty 11+
₹9,396.00
Volume Pricing
Request Quote

Get Product Downloads



Abbe Number (v_d):
94.99

Axis Orientation:
Random

Bevel:
Protective as needed

Clear Aperture (%) : 90
Clear Aperture CA (mm) : 11.25
Diameter (mm) : 12.50 +0.0/-0.1
Thickness (mm) : 2.00 ±0.1
Coating : Uncoated
Coefficient of Thermal Expansion CTE (10⁻⁶/°C) : 18.85
Density (g/cm³) : 3.18
Edges : Fine Ground
Index of Refraction n_d : 1.434
Knoop Hardness (kg/mm²) : 158.3
Parallelism (arcmin) : <1
Poisson's Ratio : 0.26
Substrate : Calcium Fluoride (CaF ₂) Vacuum UV Grade
Surface Flatness (P-V) : λ/2
Surface Quality : 40-20
Type : Protective Window
Wavelength Range (nm) : 200 - 7000
Young's Modulus (GPa) : 75.8

Regulatory Compliance

RoHS 2015 : Compliant
Reach 219 : Compliant
Certificate of Conformance : View