


12.7mm Dia. 1064nm 0°, Low Cost Nd:YAG Mirror

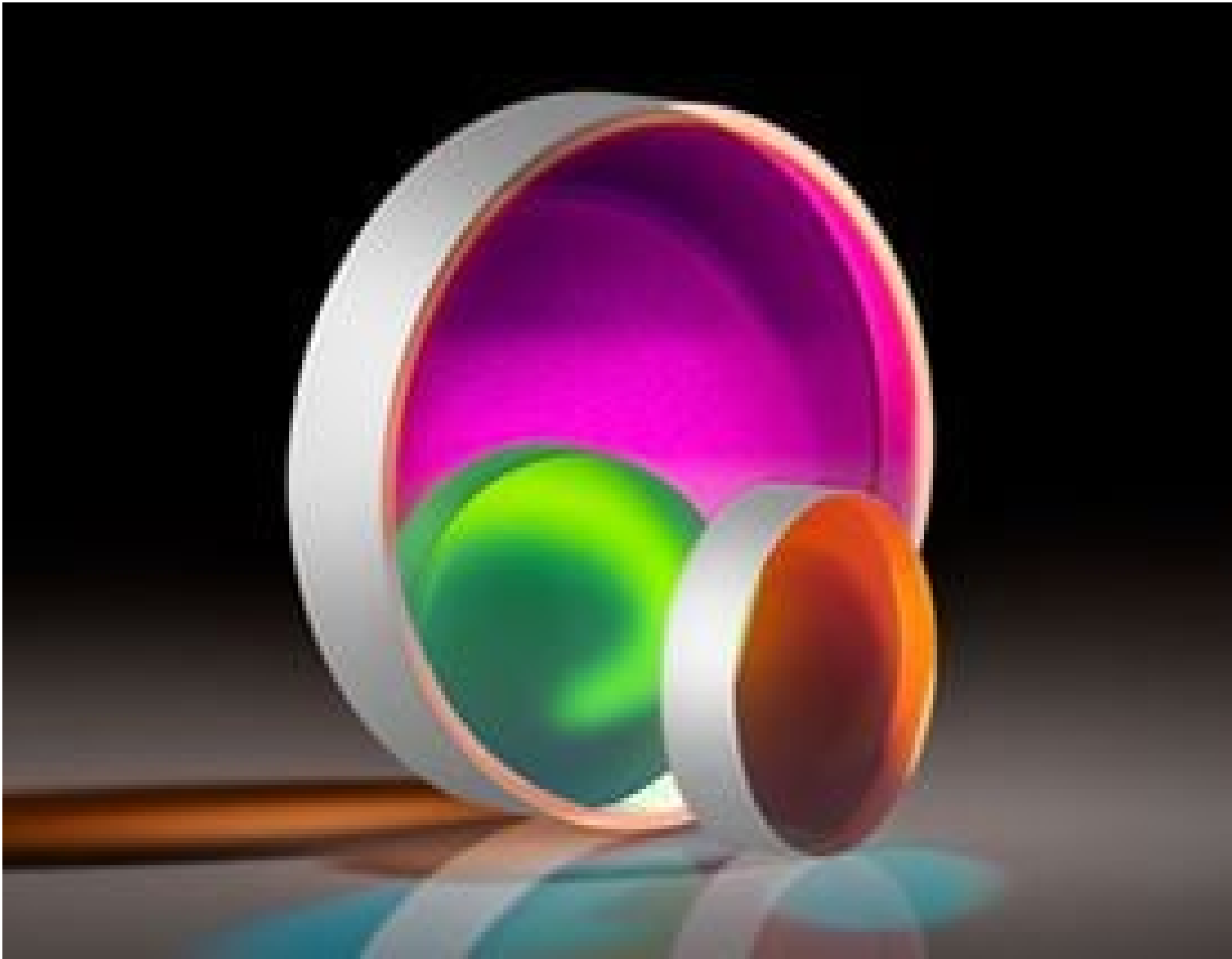

Stock #38-621 10 TO 12 DAYS

- 1 + ₹8,352.00

ADD TO CART

Qty 1-10
₹8,352.00
Qty 11+
₹7,569.00
Volume Pricing
Request Quote

Get Product Downloads



Surface Quality:
20-10

Type:
Laser Mirror

Parallelism (arcmin):
<3

Clear Aperture (%):

>90
Back Surface: Commercial Polish
Reflection at DWL (%): 99
Coating Specification: R _{abs} >99% @ 1064nm
Surface Flatness (P-V): λ/10
Coating Type: Dielectric
Coating: Laser Mirror (1064nm)
Design Wavelength DWL (nm): 1064
Diameter (mm): 12.70 +0.0/-0.1
Thickness (mm): 6.35 ±0.2
Angle of Incidence (°): 0
Substrate: ☐ N-BK7
Damage Threshold, By Design: ☐ 5 J/cm² @ 1064nm, 20ns, 20Hz

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View