


TECHSPEC® 12.7mm Dia. UV, Precision Broadband Laser Mirror

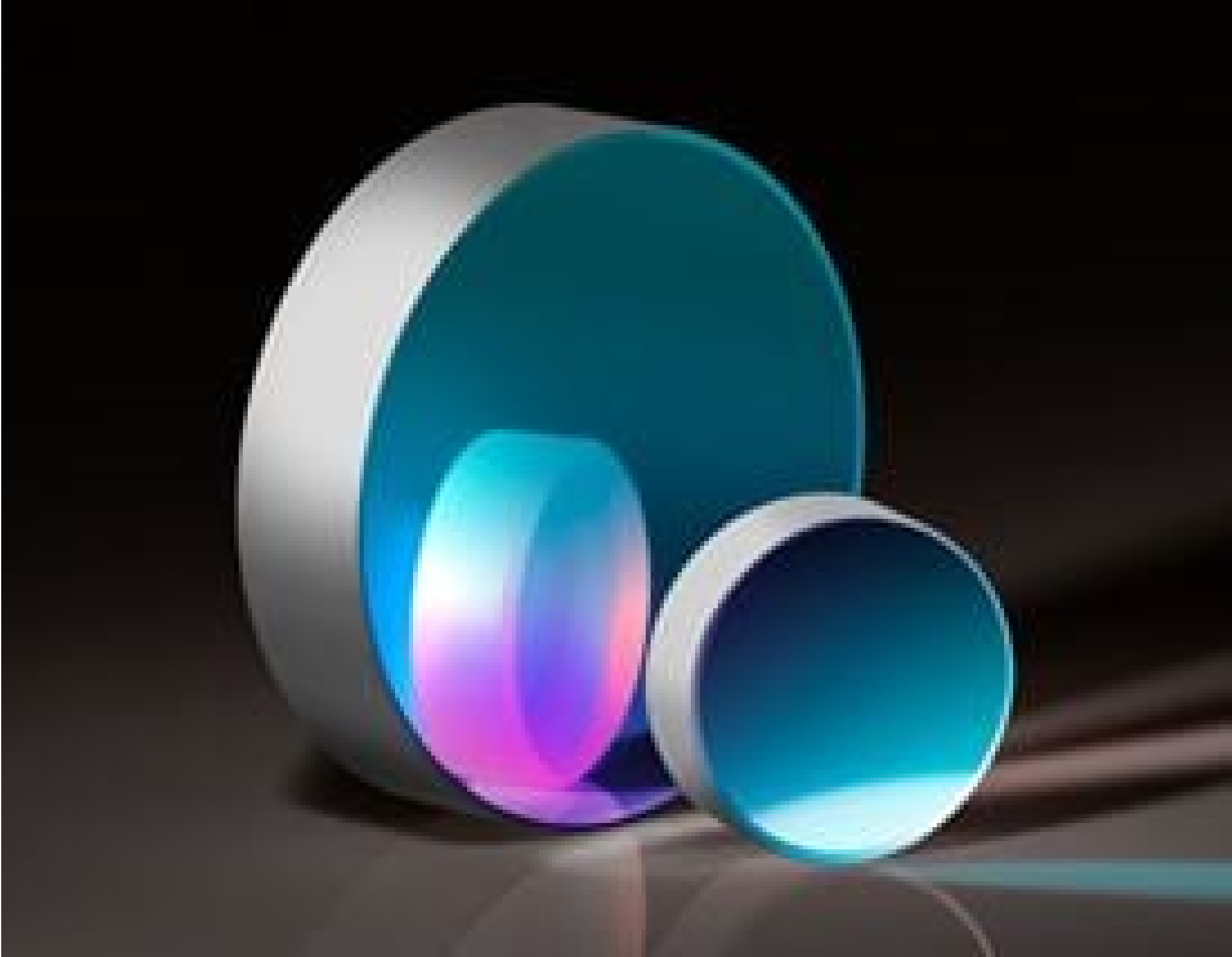

Stock **#48-015** 10 TO 12 DAYS

- 1 + **₹10,962.00**

ADD TO CART

Qty 1-5
₹10,962.00
Qty 6+
₹9,657.00
Volume Pricing
Request Quote

Get Product Downloads

 


Surface Quality:
20-10

Type:
Laser Mirror

Clear Aperture (%):
>80

Durability:

ML-M-13508-C
Back Surface: Ground
Coating Specification: R _{avg} >99% @ 300 - 550nm
Wavelength Range (nm): 300 - 550
Surface Flatness (P-V): λ/10
Irregularity (P-V) @ 632.8nm: λ/20
Coating Type: Dielectric
Coating: Dielectric Mirror (300-550nm)
Diameter (mm): 12.70 +0.0/-0.2
Thickness (mm): 5.00 ±0.1
Angle of Incidence (°): 0-45
Substrate: 
Note: Optical Power: λ/10
Damage Threshold, By Design:  0.3 J/cm ² @ 10ns @ 355nm

Regulatory Compliance

RoHS 2015: Compliant
REACH 201: Compliant
Certificate of Conformance: View