


TECHSPEC® 12.7mm Dia x 100mm FL, Uncoated Imaging Grade PCX Cylinder Lens

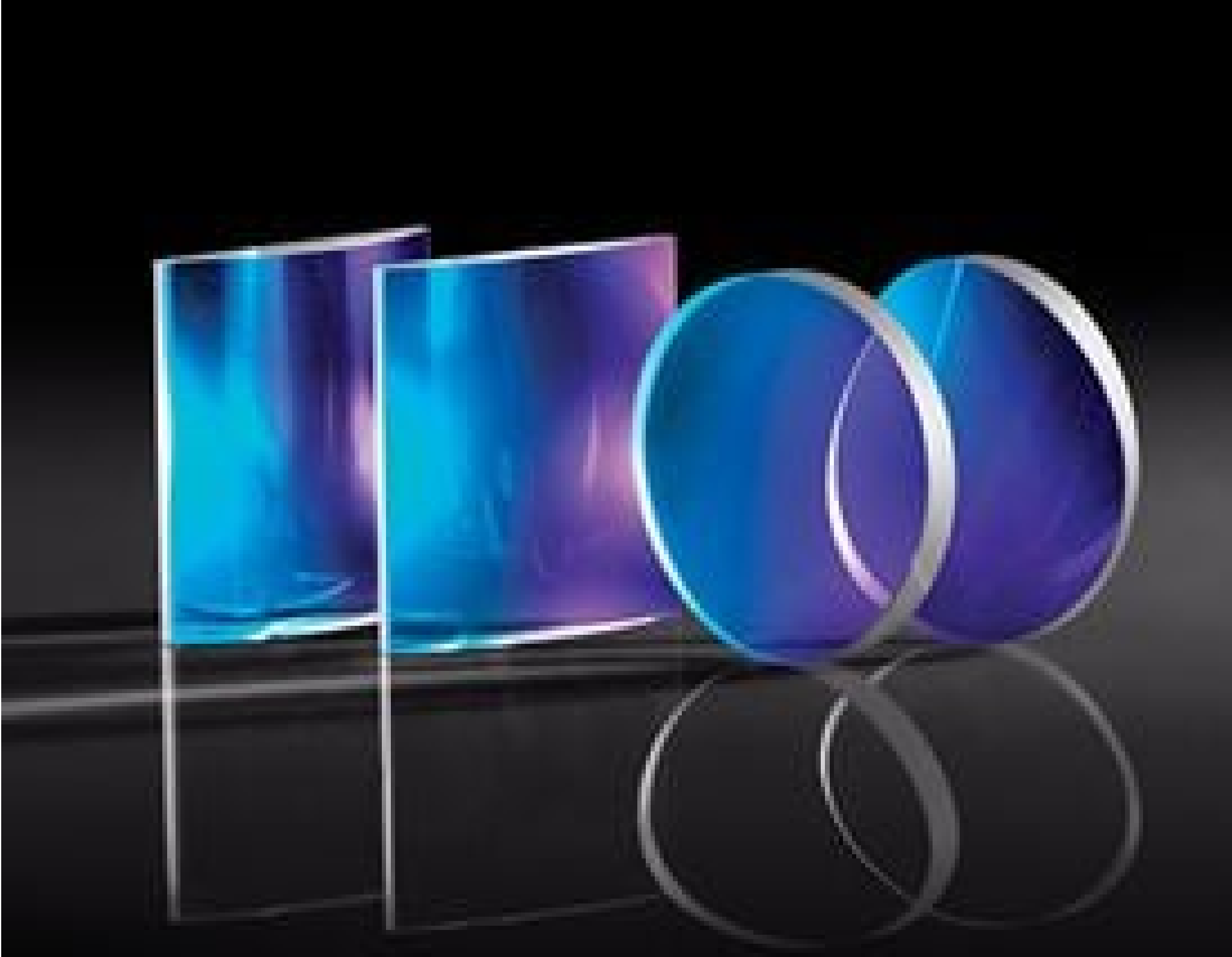

Stock **#34-608** 10 TO 12 DAYS

- 1 + **₹7,308.00**

ADD TO CART

Qty 1-5
₹7,308.00
Qty 6+
₹5,829.00
Volume Pricing
Request Quote

Get Product Downloads



Diameter (mm):
12.70 +0.0/-0.025

Effective Focal Length EFL (mm):
100.00

Substrate: N-BK7
f/#: 6.00
Numerical Aperture NA: 0.06
Coating: Uncoated
Type: Cylinder Lens, Plano-Convex
Wavelength Range (nm): 350 - 2200
Back Focal Length BFL (mm): 98.68
Bevel: Protective bevel as needed
Center Thickness CT (mm): 2.00
Center Thickness Tolerance (mm): ±0.1
Clear Aperture CA (mm): 11.43
Edge Thickness ET (mm): 1.61
Radius R₁ (mm): 51.68
Surface Quality: 40-20
Power (P-V) @ 632.8nm: 1.5λ
Irregularity (P-V) @ 632.8nm: λ/4
Plano Axis Wedge (arcmin): <5
Power Axis Wedge (arcmin): <5

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View