

12X English/ Metric Line Scale & Comparator Set



Stock #02-045 5 In Stock

-

1

+

₹12,510

ADD TO CART

Volume Pricing	
Qty 1+	₹12,510 each
Need More?	Request Quote

Product Downloads

SPECIFICATIONS

General

Type of Optics:

Kellner-Type / AR Coated

Physical & Mechanical Properties

Field of View (inches):

0.625

0.68	Diameter of Included Lens (inches):
27.00	Diameter of Compatible Reticle (mm):
1.25	Height (inches):
Optical Properties	
0.5	Working Distance (inches):
Regulatory Compliance	
View	Certificate of Conformance:

PRODUCT DETAILS

- Clear Base Admits Light
- High Power, Wide Field
- Reticle Included


Excellent for determining paper quality and ink absorption. Ideal for proofreaders. The transparent acrylic base rests directly on work for clear, close-up examinations. Base admits light to subject under view. 12X is Kellner-type, color-corrected, three-element lens system. Twist focus with lock-ring for permanent setting. Contact reticle adapter ring on base accepts all 27mm diameter reticles. Since power increases as field of view decreases, the full reticle pattern of some crowded reticles will not be visible using the 12X comparator. Nylon case ([#36-286](#)) is sold separately.

Reticle Descriptions

Magnetic Ink Scale: An important tool in magnetic ink printing field. Checks character skew, width, coverage, and voids against Accredited Standards Committee X9 specifications. Scales include comparative brackets and linear scales.

English/Metric Line Scale: Versatile measurement, straight line scale with metric and inch scales. Metric top line 0 to 15mm in 0.1mm increments. English bottom line 0 to 0.60" in 0.01" increments.

TECHNICAL INFORMATION

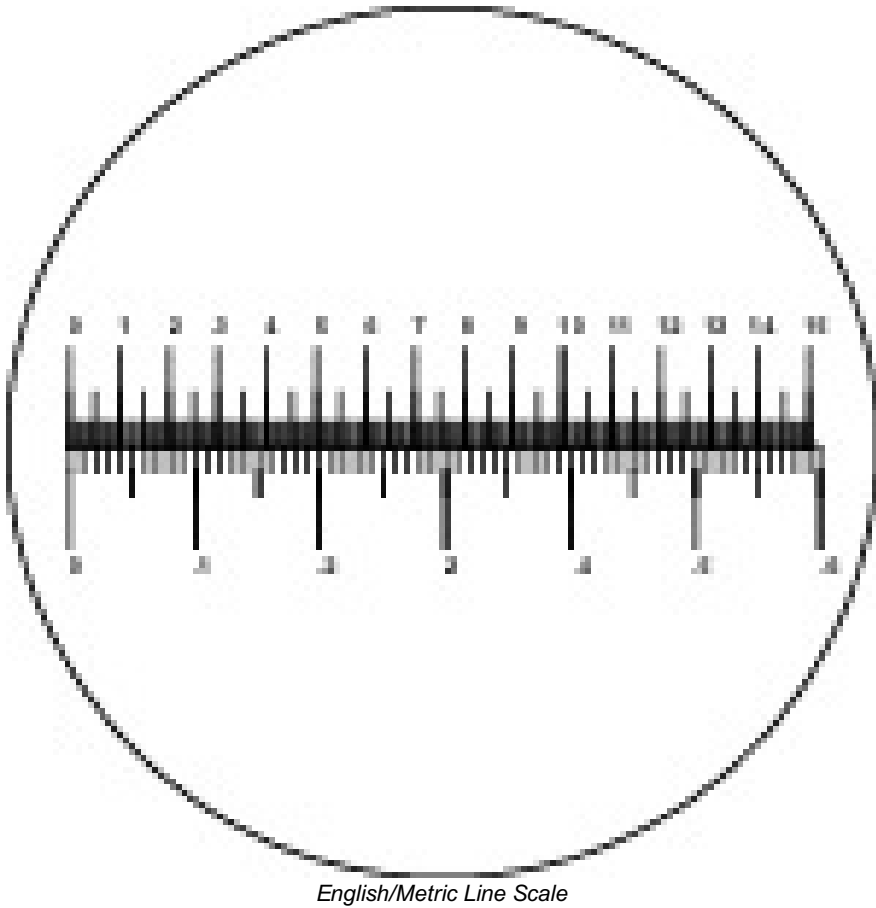

English/Metric Line Scale