


TECHSPEC® 15mm Aluminum Coated Dove Prism

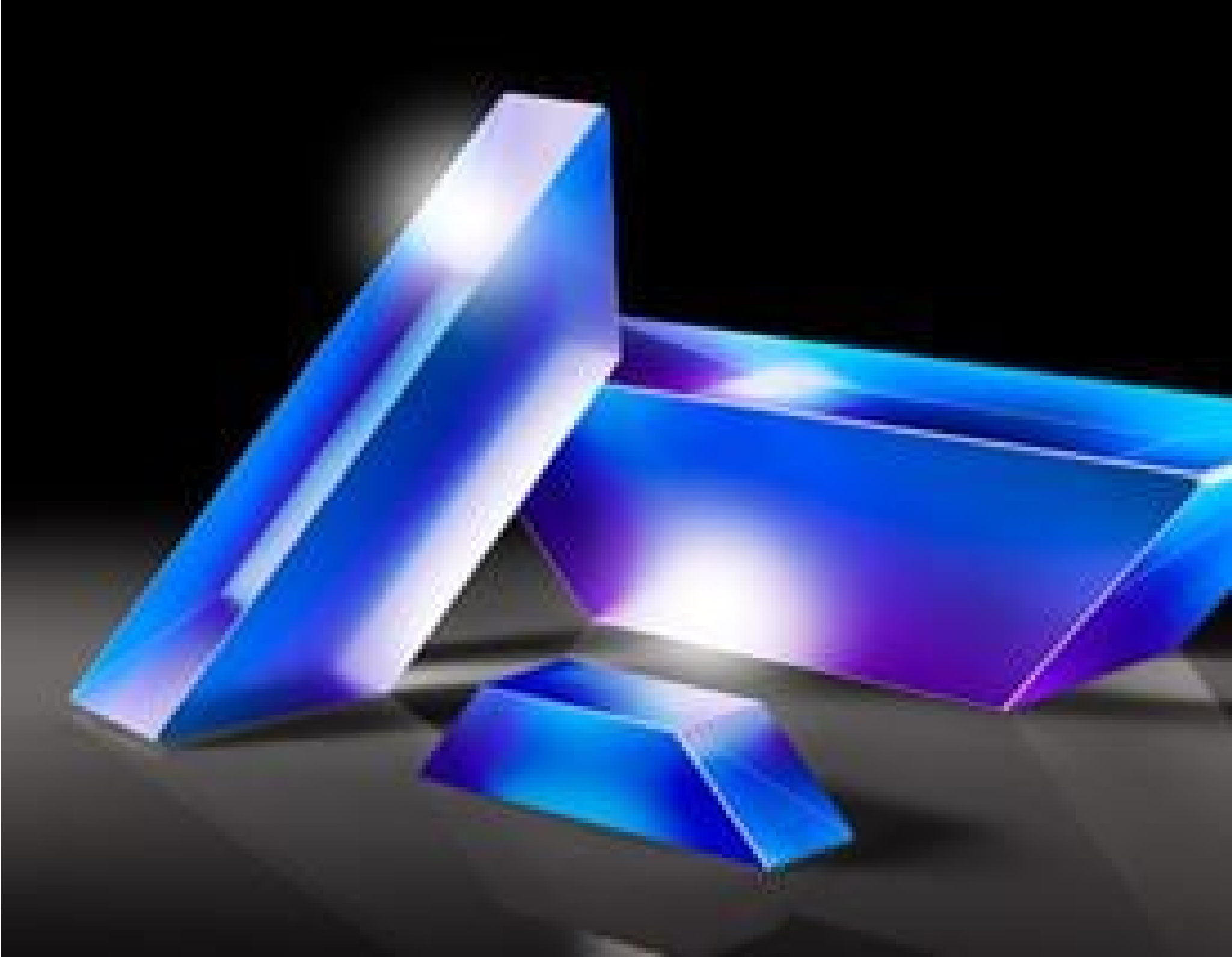

Stock **#45-815** 10 TO 12 DAYS

- 1 + **₹11,136.00**

ADD TO CART

Qty 1-5
₹11,136.00
Qty 6+
₹10,022.00
Volume Pricing
Request Quote

Get Product Downloads



Coating:
Aluminum with protective overcoat

Substrate: □
[N-BK7](#)

Height (mm):
15.0

Length (mm):

62.50
Surface Quality: 60-40
Type: Dove Prism
Dimensional Tolerance (mm): ±0.13 Legs, ±0.25 Length
Angle Tolerance (arcmin): 2
Bevel: Protective bevel as needed
Image Orientation: Right-Handed
Coating Specification: Reflective Surfaces: R _{avg} >85% FROM 400-700nm, @ 45° AOI
Ray Deviation (°): 180
Wavelength Range (nm): 400 - 700
Surface Flatness (P-V): λ/8 (Entrance and Exit Faces)
Damage Threshold, Reference: ☐ 0.3 J/cm² @ 532nm & 1064nm, 10ns

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View