


1" x 1", 50 lp/inch, Opal Glass Ronchi Ruling

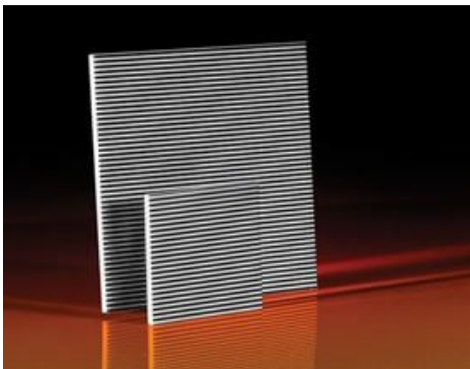

Stock #59-498 [CONTACT US](#)

1 **MRP ₹12,744**

Price inclusive of all taxes

ADD TO CART

Volume Pricing	
Qty 1-4	₹12,744 each
Qty 5+	₹12,245 each
Need More?	Request Quote

Product Downloads

- STEP:step
- PDF Drawing:pdf
- IGES:igs
- eDrawing:eprt
- EO Spec Sheet
- [Download All](#)

General

Type: English	NIST Certification: No
----------------------	-------------------------------

Physical & Mechanical Properties

Dimensional Tolerance (inches): ±0.004	Dimensions (inches): 1 x 1
Thickness (mm): 1.52 ±0.1	Line Width Tolerance (mm): ±0.002
Clear Aperture (%): 95	

Optical Properties

Substrate: Opal Glass	Frequency (lp/inch): 50.00
------------------------------	-----------------------------------

Regulatory Compliance

RoHS 2015: Compliant	Certificate of Conformance: View
---	---

Reach 235: Compliant	
---	--

Country of Origin: United States	Imported By: Edmund Optics India Private Limited 267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038 Phone: +91-80-6845 0000
---	---

Product Details

Opal Glass material has been discontinued by the manufacturer and may be available in limited quantities. [Contact us](#) for more information.


- Chrome on Opal
- High Tolerance
- English and Metric Versions

Frequently Purchased Together



#34-473 - 25mm Dia. White Diffusing Glass
₹3,632

Qty

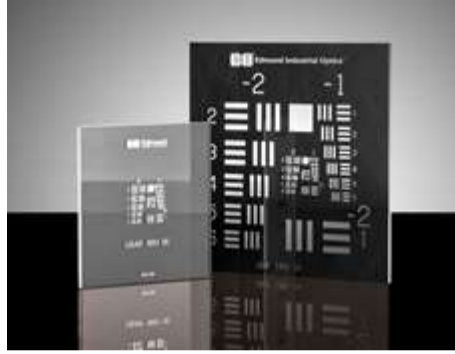


#36-408 - 3" x 3" Negative, USAF 1951 Resolution Target
₹31,541

Qty



#38-710 - USAF Resolution Target Pocket Size
₹1,036

Qty

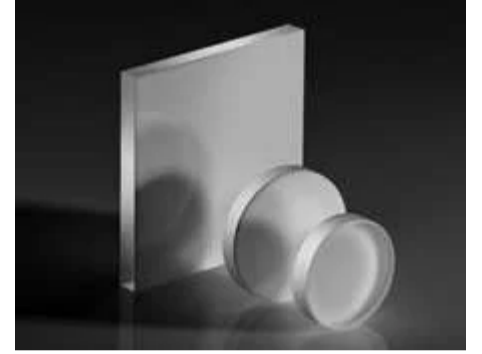

#46-167 - 25 x 25mm Opal Diffusing Glass
₹12,007

Qty



Resources

Media Type

- Video
- FAQ
- Application Note

▶ VIDEO

Wavelength and f#

? FAQ

What is a video micrometer?

? FAQ

What is the cycle length of a Metric Ronchi Rulina?

▶ VIDEO

Lens Types, Resolution, and Sensor Coverage

▶ VIDEO

Axial and Lateral Chromatic Aberration

▶ VIDEO

Best Practice #6 There Can Be Only One

[View More](#)