


TECHSPEC® 20 x 20mm Stabilized Wire Grid Polarizing Film

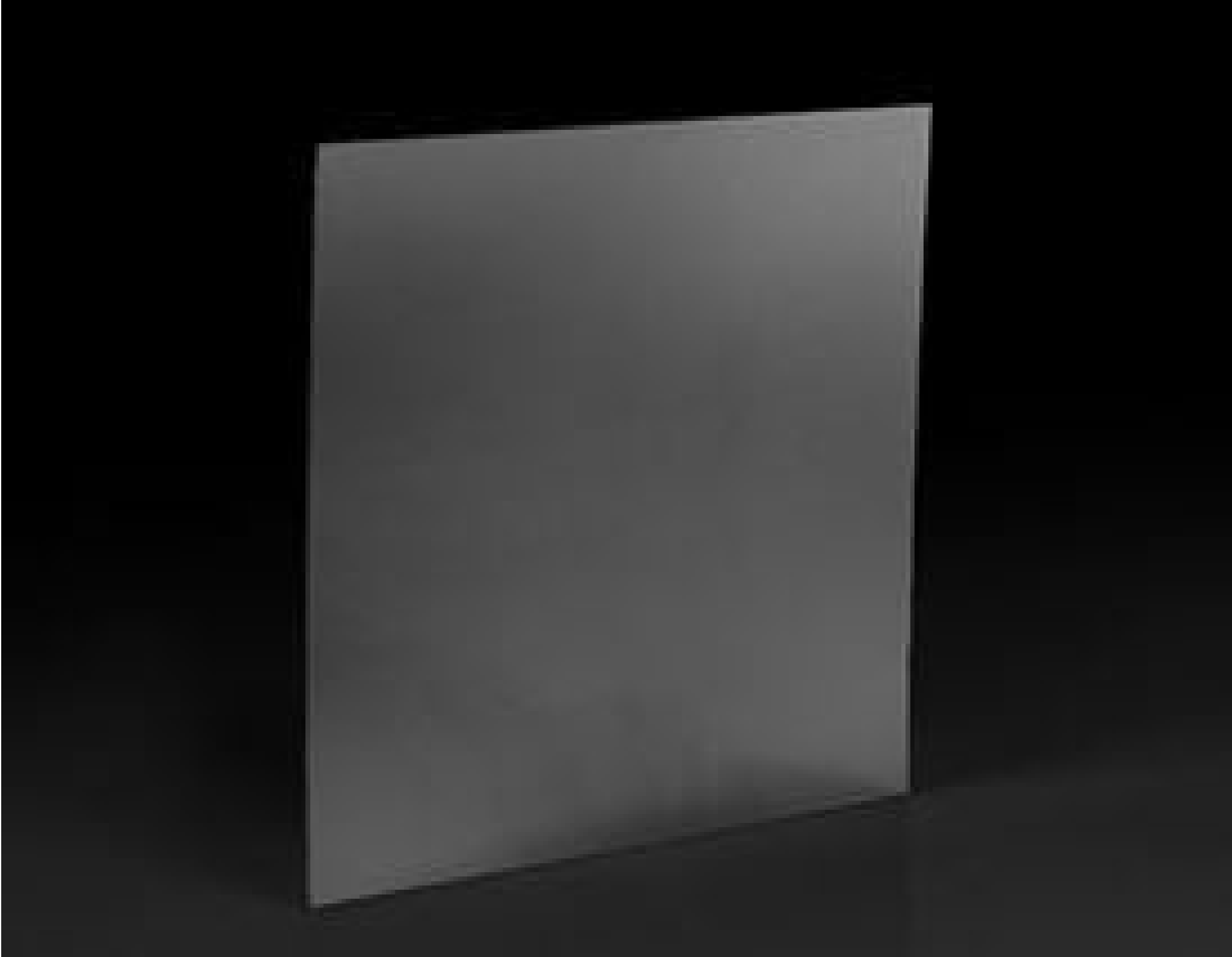

TECHSPEC® Wre Grid Polarizing Film

Stock **#20-233** 10 TO 12 DAYS

- 1 + **₹5,394.00**

ADD TO CART

Qty 1-10

₹5,394.00

Qty 11+

₹4,611.00

Volume Pricing

[Request Quote](#)

Get Product Downloads



Angle of Incidence (°):
0 - 45

Extinction Ratio:
>1415:1 @ 0° AOI, 550nm

Substrate: ☐
Aluminium Wires on COP

Operating Temperature (°C): 60 Max @90% RH 105 in dry conditions
Dimensions (mm): 20 x 20
Thickness (mm): 0.19
Thickness Tolerance (mm): ±0.030
Transmission (%): 84.9 (typical @ 550 nm)
Type: Linear Polarizer
Dimensional Tolerance (mm): ±0.5
Construction: Wire Grid
Wavelength Range (nm): 400 - 1200
Axis Orientation: 0° ± 1.5°, marked by Notch

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant