


TECHSPEC® 20mm VIS 0° Coated Dove Prism

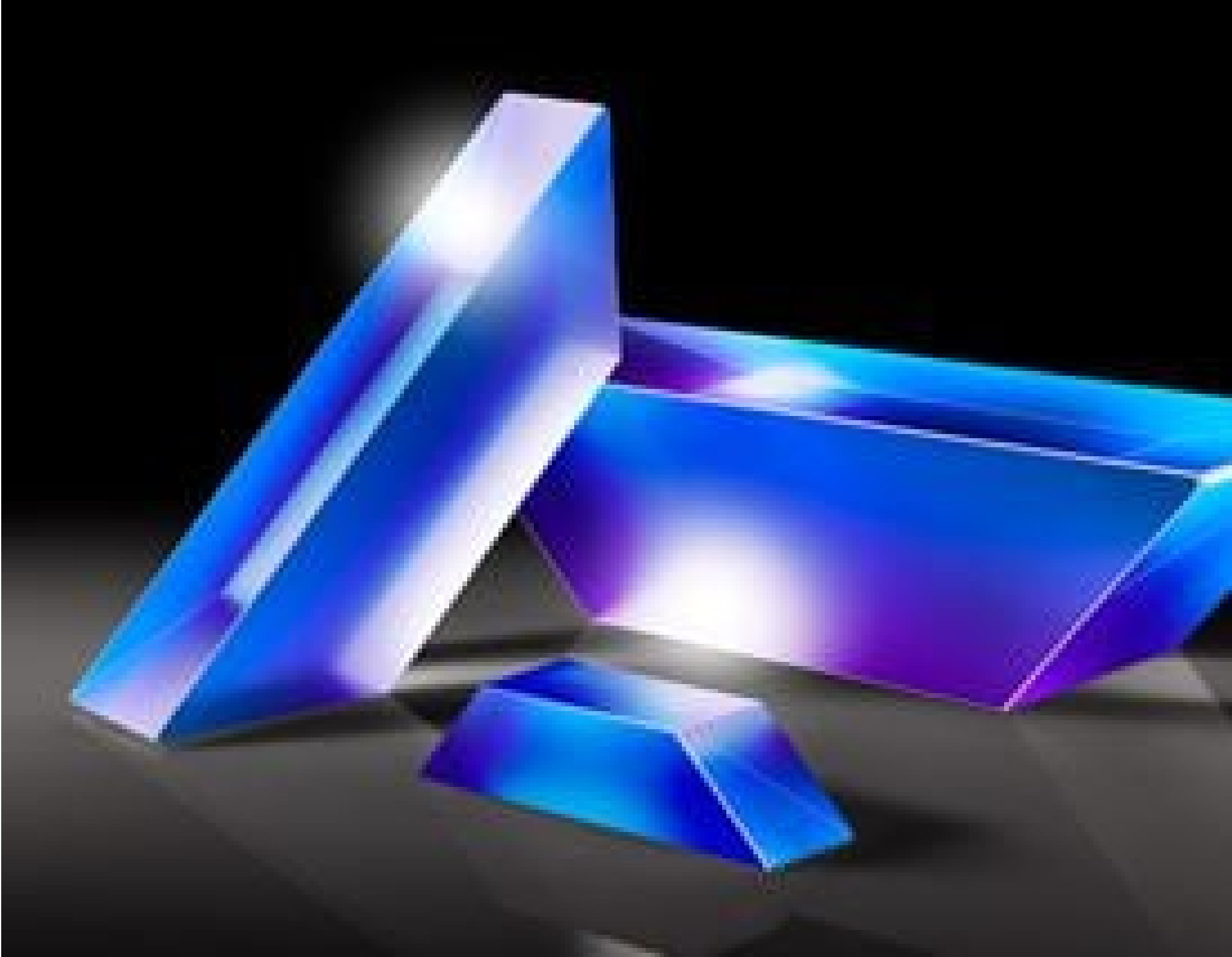

Stock **#49-428** 10 TO 12 DAYS

- 1 + **₹12,528.00**

ADD TO CART

Qty 1-5
₹12,528.00
Qty 6+
₹11,275.00
Volume Pricing
Request Quote

Get Product Downloads



Coating:
VIS 0° (425-675nm)

Substrate: □
[N-BK7](#)

Height (mm):
20.0

Length (mm):

79.80
Surface Quality: 60-40
Type: Dove Prism
Dimensional Tolerance (mm): ±0.13 Legs, ±0.25 Length
Angle Tolerance (arcmin): 2.00
Bevel: Protective bevel as needed
Image Orientation: Left-Handed
Coating Specification: R _{avg} ≤0.4% @ 425 - 675nm
Ray Deviation (°): 0
Wavelength Range (nm): 425 - 675
Surface Flatness (P-V): λ/8 (Entrance and Exit Faces)
Damage Threshold, Reference: ☐ 5 J/cm² @ 532nm, 10ns

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant