 



25 x 25mm, 0.25mm Spacing, Glass Distortion Target

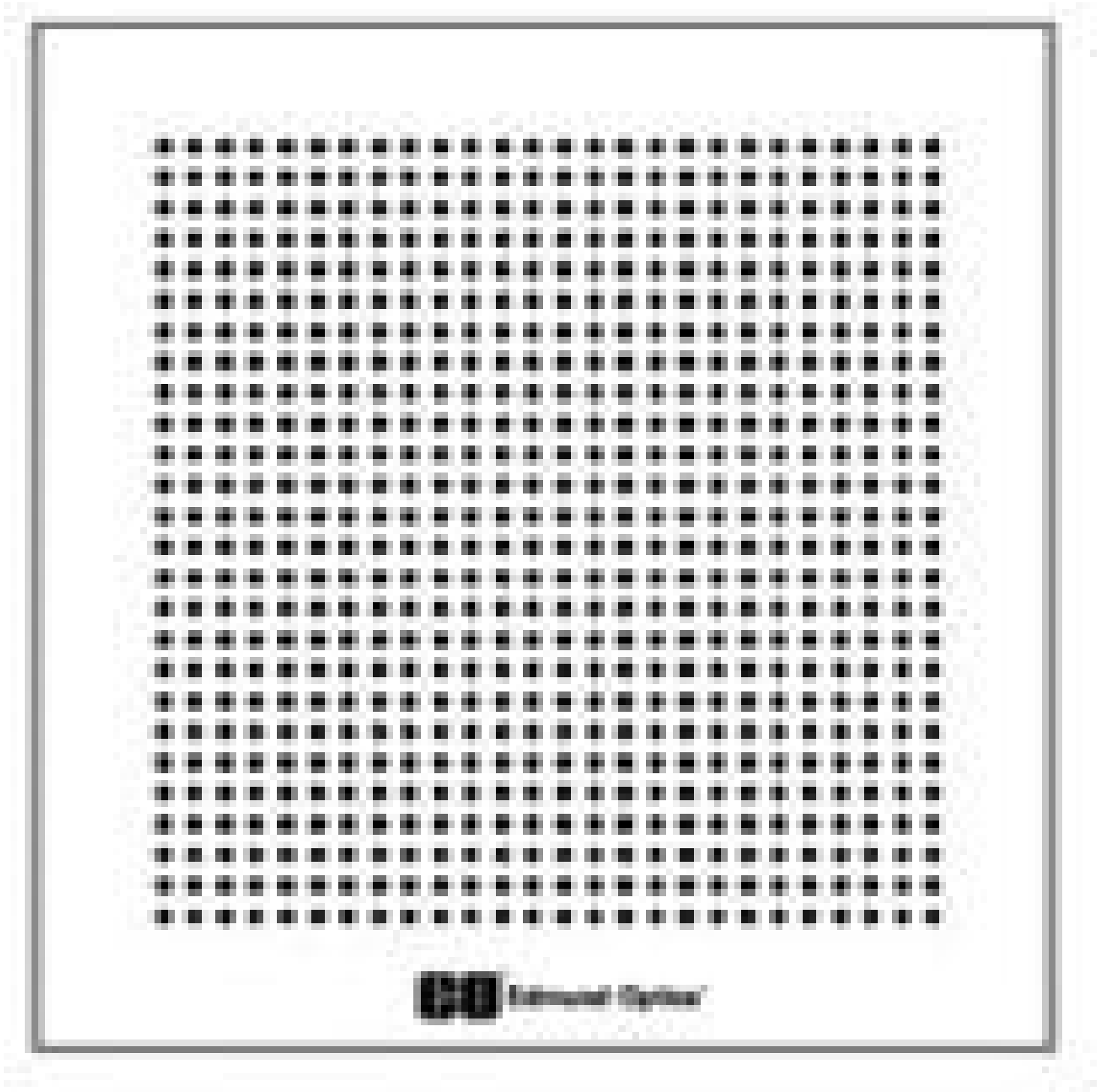

Stock #58-527 10 TO 12 DAYS

-

1

+

₹54,288.00

ADD TO CART

Qty 1-4
₹54,288.00
Qty 5+
₹51,626.00
Volume Pricing
Request Quote

Get Product Downloads
Coating: Reflective First Surface Chromium R _{abs} = 50% ±5% @ 550nm
Dot Diameter (mm): 0.125
Dot Spacing (mm):

0.250
Substrate: Soda Lime Float Glass
Optical Density OD (Average): >3.0
Overall Accuracy (mm): ±0.002
Pattern Size (mm): 25 x 25
Dimensions (inches): 2 x 2
Surface Quality: 40-20
Thickness (mm): 1.50
Type: Chrome on Glass
Dot Diameter Tolerance (mm): ± 0.002
Dot Spacing Tolerance (mm): ± 0.002 Center to Center
NIST Certification: Serialized NIST Traceable Certificate Included
Flatness (inches): 0.001

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View
