


25.4mm Dia. 1064nm 0°, Low Cost Laser Line Mirror

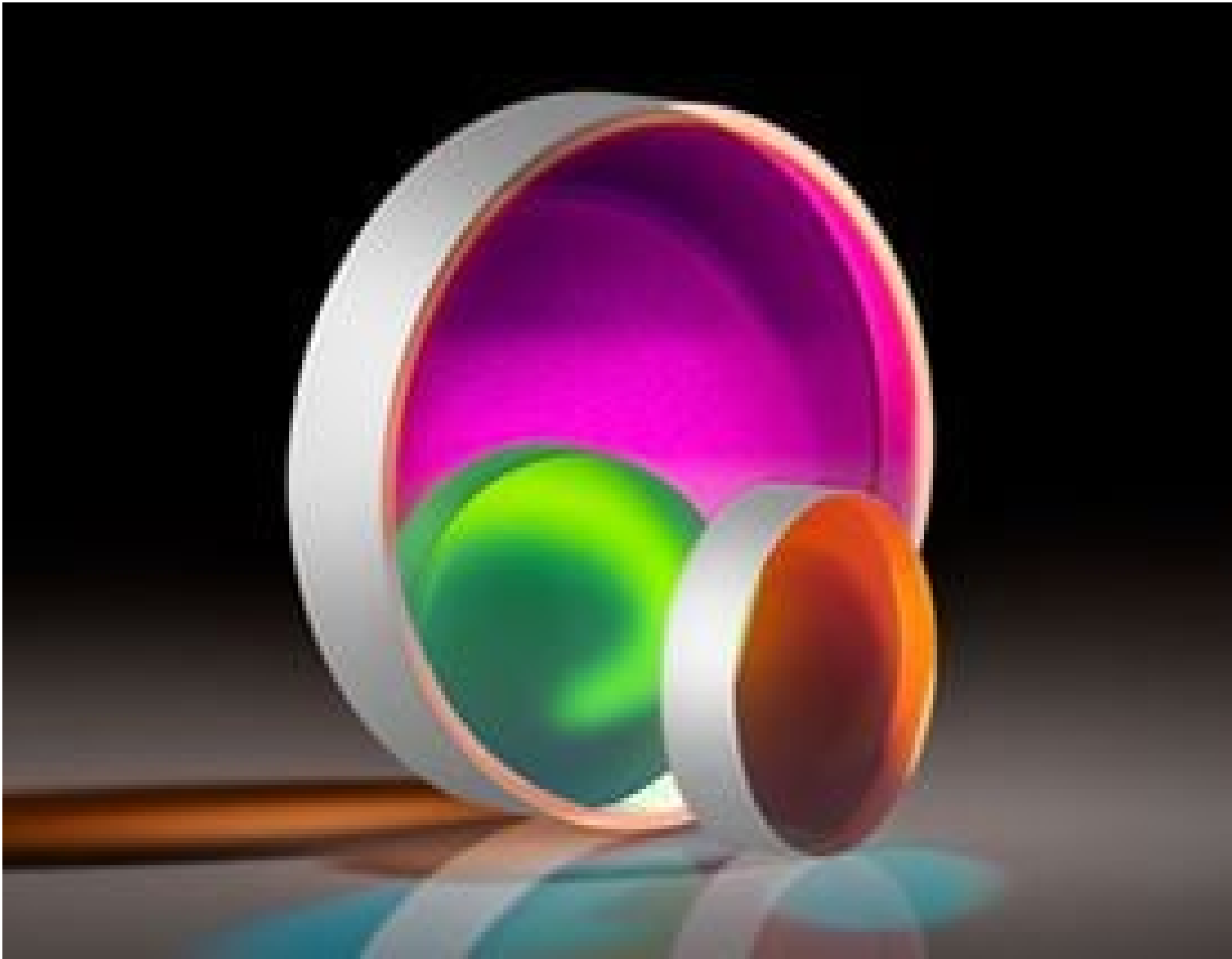

Stock #38-622 10 TO 12 DAYS

-

1

+

₹10,266.00

ADD TO CART

Qty 1-10
₹10,266.00
Qty 11+
₹9,135.00
Volume Pricing
Request Quote

Get Product Downloads



Surface Quality:
20-10

Type:
Laser Mirror

Parallelism (arcmin):
<3

Clear Aperture (%):

>90
Back Surface: Commercial Polish
Reflection at DWL (%): 99
Coating Specification: R _{abs} >99% @ 1064nm
Surface Flatness (P-V): λ/10
Coating Type: Dielectric
Coating: Laser Mirror (1064nm)
Design Wavelength DWL (nm): 1064
Diameter (mm): 25.40 +0.0/-0.1
Thickness (mm): 6.35 ±0.2
Angle of Incidence (°): 0
Substrate: ☐ N-BK7
Damage Threshold, By Design: ☐ 5 J/cm² @ 1064nm, 20ns, 20Hz

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View