


25.4mm Dia. 515nm 0°, Low Cost Laser Line Mirror

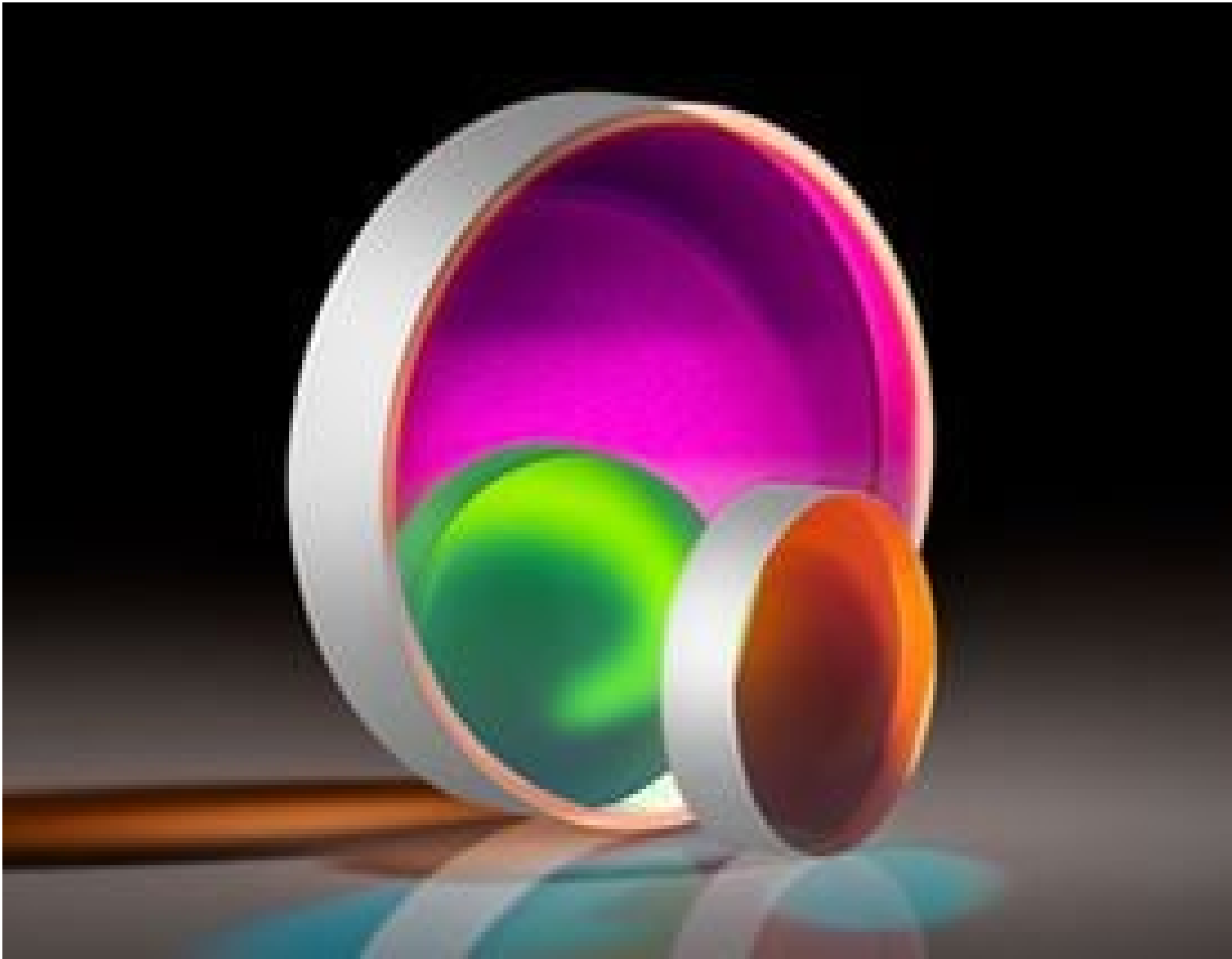

Stock #11-084 10 TO 12 DAYS

- 1 +

₹10,266.00

ADD TO CART

Qty 1-10
₹10,266.00
Qty 11+
₹9,135.00
Volume Pricing
Request Quote

Get Product Downloads



Surface Quality:
20-10

Type:
Laser Mirror

Parallelism (arcmin):
<3

Clear Aperture (%):

Durability:
ML-C-675C

Back Surface:
Commercial Polish

Reflection at DWL (%):
99

Coating Specification:
R_{abs} >99% @515nm

Surface Flatness (P-V):
λ/10

Coating Type:
Dielectric

Coating:
Laser Mirror (515nm)

Design Wavelength DWL (nm):
515

Diameter (mm):
25.40 +0.0/-0.1

Thickness (mm):
6.35 ±0.2

Angle of Incidence (°):
0

Substrate: ☐
[N-BK7](#)

Damage Threshold, By Design: ☐
3 J/cm² @515nm, 20ns, 20Hz

Regulatory Compliance

RoHS 2015:
[Compliant](#)

Reach 223:
[Compliant](#)

Certificate of Conformance:
[View](#)