

**TECHSPEC® 254mm Length, M4 Stud, Steel Post**



Stock #58-958 **CLEARANCE** 4 In Stock

⊖ 1 ⊕ MRP ₹1,270

● Price inclusive of all taxes

**ADD TO CART**

Volume Pricing

Qty 1+	₹1,270 each
Need More?	<a href="#">Request Quote</a>

Product Downloads

**General**

Metric **Type:**

**Note:**  
Adapter #58-984 is included. Additional [thread adapters](#) available separately.

**Physical & Mechanical Properties**

254.00 **Length (mm):**

**Length (inches):**

10.0

12.70

0.5

Diameter (mm):

Diameter (inches):

### Threading & Mounting

Male Thread:

M4 x0.7

### Regulatory Compliance

RoHS 2015:

Compliant

Certificate of Conformance:

[View](#)

REACH 241:

Compliant

Country of Origin:

China

Imported By:


Edmund Optics India Private Limited  
267, Greystone Building, Second Floor,  
6th Cross Rd, Binnamangala,  
Stage 1, Indiranagar, Bengaluru,  
Karnataka, India 560038  
Phone: +91- 80-6845 0000

## Product Details

- Male M4 x0.7 or M6 x 1.0 Stud, Female M6 x1.0 Base
- Posts Include Interchangeable Male Stud and Removable Base S.H.S.S.
- Available in Variety of Lengths
- [English Versions Also Available](#)

TECHSPEC® Metric Stainless Steel Mounting Posts include a 6.35mm long male thread stud adapter that is easily interchangeable with other adapters to ensure compatibility between these posts and any optical mount. Removing the included adapter reveals female M4 threads on the post. Each optical post also has a thru-hole to allow an Allen wrench or other tool to rotate the post easily. Thread values are laser engraved on each post for quick identification and integration. TECHSPEC Metric Stainless Steel Mounting Posts are offered in a variety of lengths. [English versions are also available for purchase.](#)

## Technical Information

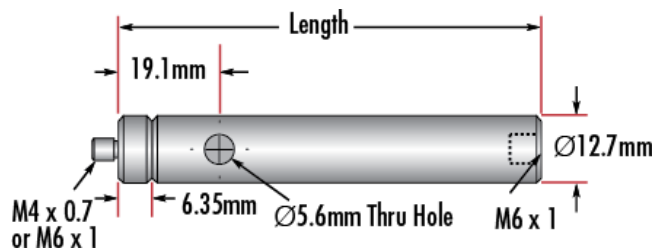

#### #68-231

Stock No.	Description	Qty
<a href="#">#58-950</a>	Steel Post, 25.4mm Length	1
<a href="#">#58-951</a>	Steel Post, 38.1mm Length	1
<a href="#">#58-952</a>	Steel Post, 50.8mm Length	2
<a href="#">#58-954</a>	Steel Post, 76.2mm Length	2
<a href="#">#58-955</a>	Steel Post, 101.6mm Length	2
<a href="#">#58-956</a>	Steel Post, 152.4mm Length	1
<a href="#">#58-957</a>	Steel Post, 203.2mm Length	1

#### #68-232

Stock No.	Description	Qty
<a href="#">#59-757</a>	Steel Post, 25.4mm Length	1
<a href="#">#59-758</a>	Steel Post, 38.1mm Length	1
<a href="#">#59-759</a>	Steel Post, 50.8mm Length	2
<a href="#">#59-761</a>	Steel Post, 76.2mm Length	2
<a href="#">#59-762</a>	Steel Post, 101.6mm Length	2
<a href="#">#59-763</a>	Steel Post, 152.4mm Length	1
<a href="#">#59-764</a>	Steel Post, 203.2mm Length	1

