

25/25.4mm, Mounting Cell



25.4mm, Mounting Cell, #56-760

Stock **#56-760** 20+ In Stock

-

1

+

₹1,870

ADD TO CART

Volume Pricing	
Qty 1-9	₹1,870 each
Qty 10-25	₹1,687 each
Qty 26-49	₹1,599 each
Need More?	Request Quote

Product Downloads

General

Fixed

Type:

Circular

Type of Optics:

Physical & Mechanical Properties

Black Anodized Aluminum

Construction:

3.2	Max. Thickness of Compatible Optics (mm):
30.0	Cell Diameter (mm):
Threading & Mounting	
25.0 - 25.4	Size of Compatible Optics (mm):
5.0	Cell Thickness (mm):
Regulatory Compliance	
Exempt	RoHS 2015:
View	Certificate of Conformance:
Contains SVHC(s)	Reach 247:
Japan	Country of Origin:
Edmund Optics India Private Limited	Imported By:

Product Details

• Allows Stacking of 3 or 5 Filters

• Black Anodized Aluminum

• **Posts** and **Post Holders** Required for Mounting

Fixed/Multiple Filter Mounts are ideal for use with neutral density filters in stacking applications. Mounting cell holds filter with diameter "F" in place with a retainer ring. Mounting cell sits securely in filter holder. Fixed/Multiple Filter Mounts can also hold unmounted filters with diameter "A". A filter holder and filter cell are required for a complete stacking system, such as the one illustrated in the product image. These mounts are constructed of black anodized aluminum and are optimal for mounting 3 or 5 circular optics.


Posts and **Post Holders** are required for mounting to a breadboard.

Technical Information


Stock No.	A	B	C	D	No. of Slots	No. of Cell Slots
#55-006	30mm	50mm	34mm	5mm	4	3
#55-007	50mm	70mm	44mm	5mm	5	5

Stock No.	F	G	H
#56-759	12.7mm	10.2mm	30mm
#55-008	25mm	22.5mm	30mm
#56-760	25.4mm	22.9mm	30mm
#55-009	50mm	47mm	52mm

Multiple Filter Holder

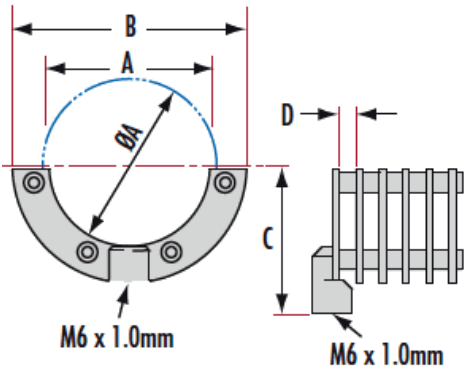

Mounting Cell

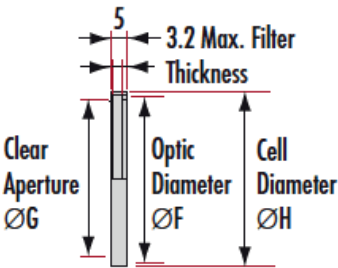

Units: mm

