


25mm Dia., 3mm Thick, Calcium Fluoride (CaF₂) Diffuser

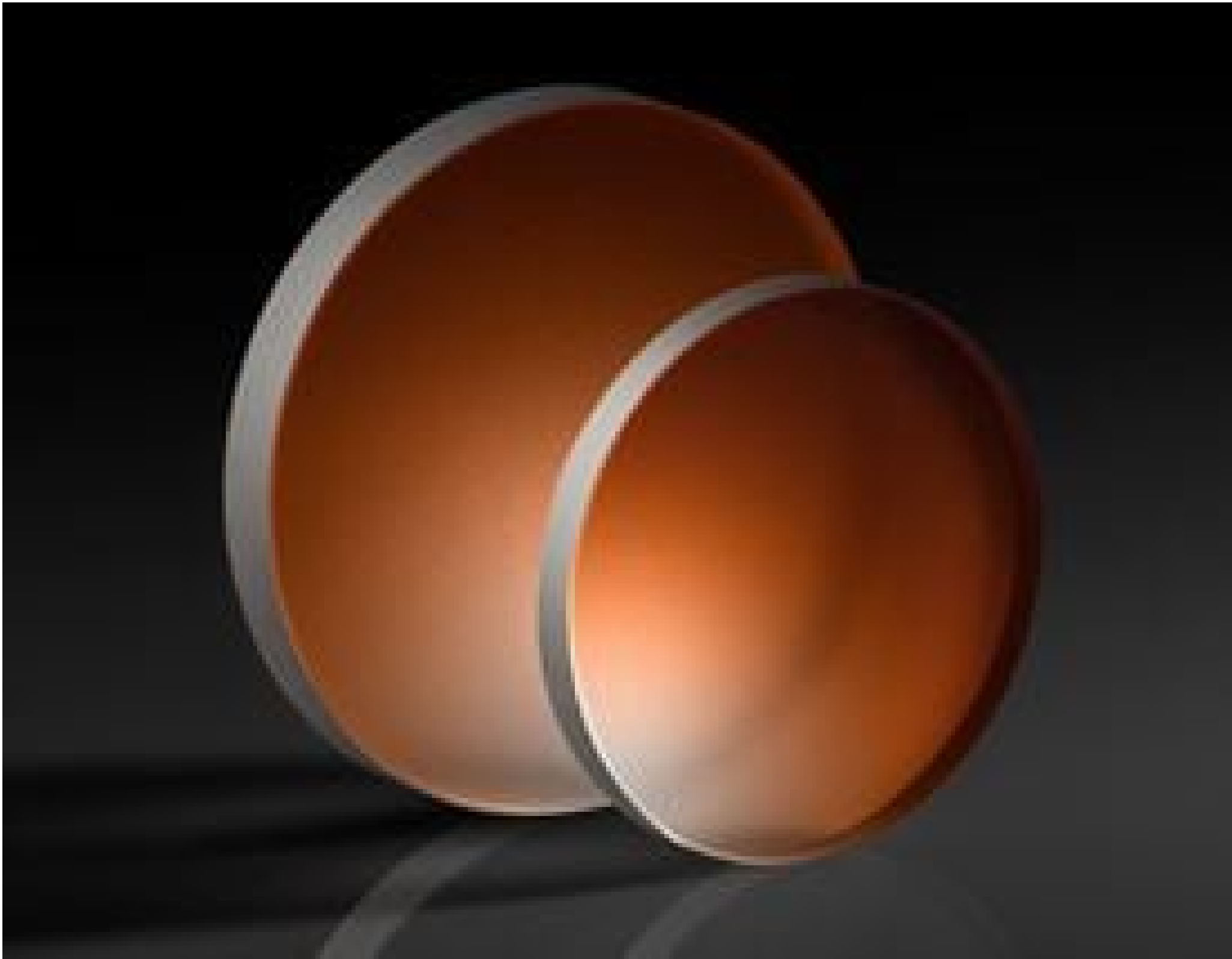

IR Calcium Fluoride (CaF₂) Diffusers

Stock #19-734 10 TO 12 DAYS

- 1 + **₹14,355.00**

ADD TO CART

Qty 1-10
₹14,355.00
Qty 11+
₹12,920.00
Volume Pricing
Request Quote

Get Product Downloads



Diameter (mm):
25.00 +0.00/-0.10

Coating:
Uncoated

Edges:
Fine Grind

Substrate: ☐
Calcium Fluoride (CaF₂)

Thickness (mm):
3.00 ±0.10

Type:
IR Diffuser

Wavelength Range (nm):
300 - 7000

Note:
Fine Grind first surface with a roughness (Ra) of
☐0.75 microns

Regulatory Compliance

RoHS 2015:
[Compliant](#)

Certificate of Conformance:
[View](#)