


## TECHSPEC® 25mm Dia. x 175mm FL VIS-EXT Coated, Double-Convex Lens

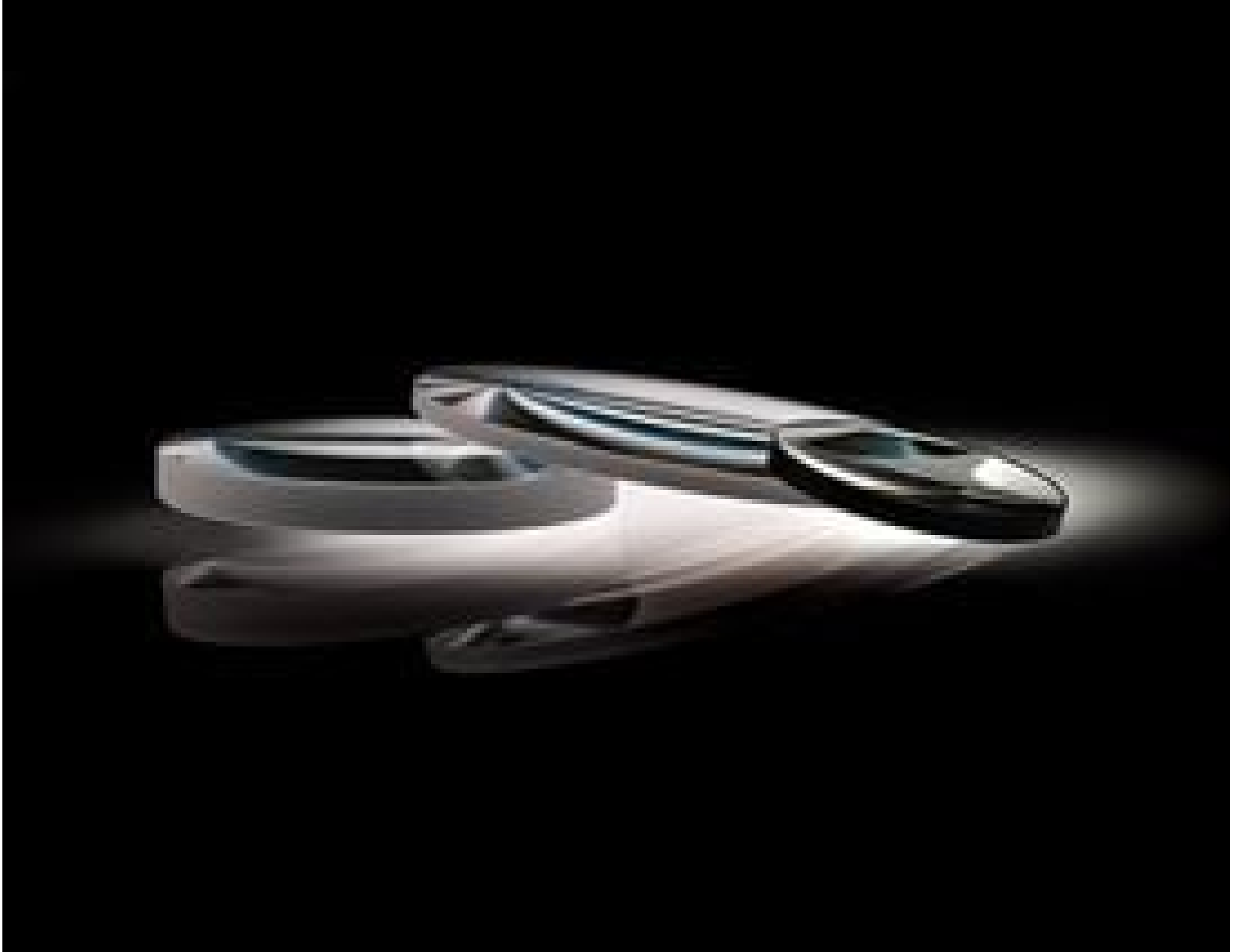

Stock #89-184 10 TO 12 DAYS

[Other Coating Options](#)

⊖ 1 ⊕ **₹4,350**

**ADD TO CART**

Qty 1-9

₹4,350

Qty 10+

₹3,915

Volume Pricing

[Request Quote](#)

Get Product Downloads

**Diameter (mm):**  
25.00 +0.000/-0.025

**Back Focal Length BFL (mm):**  
173.94

**Effective Focal Length EFL (mm):**  
175.00

**Coating:**  
MS-EXT (350-700nm)

**Coating Specification:**  
 $R_{avg} < 0.5\%$  @ 350 - 700nm

**Substrate:**   
[N-BK7](#)

**Surface Quality:**  
40-20

**Power (P-V) @ 632.8nm:**  
1.5λ

**Irregularity (P-V) @ 632.8nm:**  
λ/4

**Centering (arcmin):**  
<1

**Bevel:**  
Protective bevel as needed

**Center Thickness CT (mm):**  
3.20

**Center Thickness Tolerance (mm):**  
±0.10

**Edge Thickness ET (mm):**  
2.33

**Radius  $R_1=R_2$  (mm):**  
180.4

**Clear Aperture CA (mm):**  
24.00

**f#:**  
7.00

**Focal Length Specification Wavelength (nm):**  
587.6

**Focal Length Tolerance (%):**  
±1

**Numerical Aperture NA:**  
0.07

**Type:**  
Double-Convex Lens

**Wavelength Range (nm):**  
350 - 700

## Regulatory Compliance

**RoHS 2015:**  
[Compliant](#)

**Certificate of Conformance:**  
[View](#)

**Reach 235:**  
[Compliant](#)