

[See all 6 Products in Family](#)

## 25mm Dia. x 200mm FL Uncoated, DCX N-K5 Lens



Stock #32-902 CLEARANCE **20+ In Stock**

MRP ₹2,397

Price inclusive of all taxes

**ADD TO CART**

Volume Pricing	
Qty 1+	₹2,397 each
Need More?	<a href="#">Request Quote</a>

### Product Downloads

#### General

Double-Convex Lens **Type:**

#### Physical & Mechanical Properties

25.00 +0.00/-0.10 **Diameter (mm):**

<1 **Centering (arcmin):**

5.00 ±0.10 **Center Thickness CT (mm):**

4.25	<b>Edge Thickness ET (mm):</b>
24	<b>Clear Aperture CA (mm):</b>
Protective as needed	<b>Bevel:</b>
<b>Optical Properties</b>	
200.00 @ 587.6nm	<b>Effective Focal Length EFL (mm):</b>
198.35	<b>Back Focal Length BFL (mm):</b>
Uncoated	<b>Coating:</b>
N-K5	<b>Substrate:</b> <input type="checkbox"/>
40-20	<b>Surface Quality:</b>
1.5λ	<b>Power (P-V) @ 632.8nm:</b>
λ/4	<b>Irregularity (P-V) @ 632.8nm:</b>
±1	<b>Focal Length Tolerance (%):</b>
8.00	<b>f#:</b>
0.06	<b>Numerical Aperture NA:</b>
330 - 2500	<b>Wavelength Range (nm):</b>


## Regulatory Compliance

<a href="#">View</a>	<b>Certificate of Conformance:</b>
Japan	<b>Country of Origin:</b>
Edmund Optics India Private Limited 267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038 Phone: +91- 80-6845 0000	<b>Imported By:</b>

## Product Details

- N-K5 Substrate
  - Various Anti-Reflection (AR) Coatings
  - PCX and DCX Options Available
- N-K5 Lenses are available in various diameters, focal lengths, as well as Plano-Convex and Double-Convex form factors. Anti-reflective coatings covering the VIS to NIR make these ideal for multiple applications.

## Technical Information

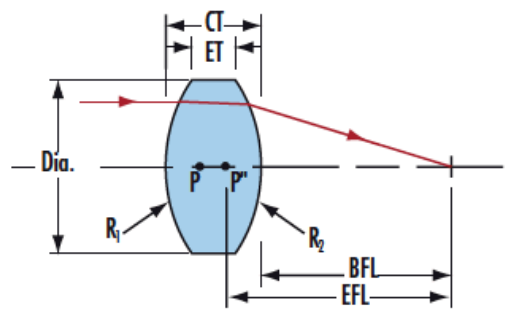

## Compatible Mounts