


TECHSPEC[®] 25mm Dia x 20mm FL Acylinder Lens, Uncoated

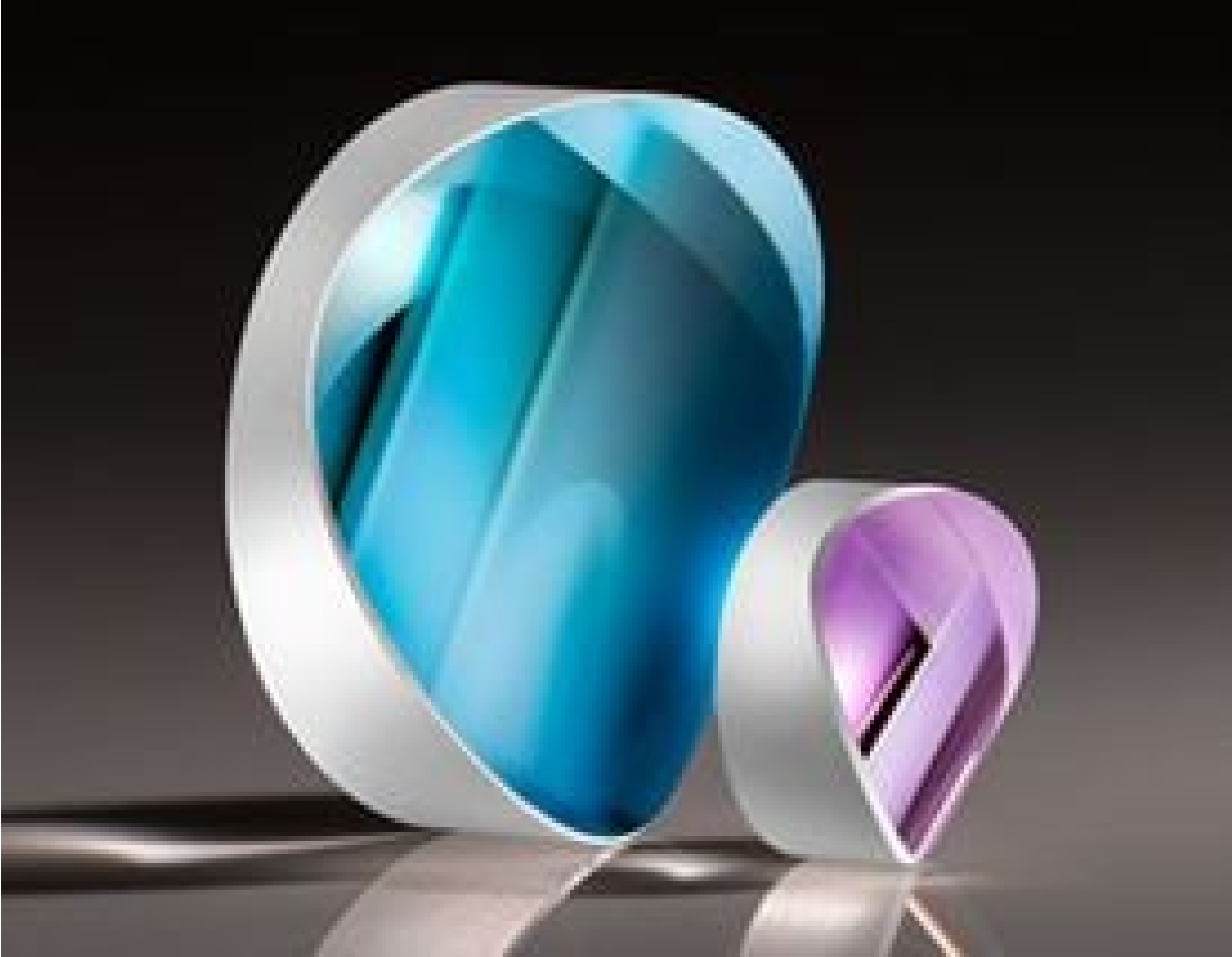

TECHSPEC Acylinder Lenses

Stock #86-032 10 TO 12 DAYS

-

1

+

₹71,775.00

ADD TO CART

Qty 1-5

₹71,775.00

Qty 6+

₹57,420.00

Volume Pricing

[Request Quote](#)

Get Product Downloads

Diameter (mm):
25.00 +0.0/-0.1

Effective Focal Length EFL (mm):
20.00

Substrate:
[N-SF5](#)

f/#:

0.8
Numerical Aperture NA: 0.63
Coating: Uncoated
Type: Acyliner Lens
Wavelength Range (nm): 380 - 2500
Back Focal Length BFL (mm): 14.6
Center Thickness CT (mm): 9.00
Center Thickness Tolerance (mm): ±0.1
Clear Aperture (%): 90.00
Edge Thickness ET (mm): 2.6
Focal Length Specification Wavelength (nm): 587.6
Surface Accuracy, RMS (µm): 1.0
Surface Quality: 60-40

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View
