


TECHSPEC[®] 25mm Dia x 50mm FL Uncoated, Si Aspheric Lens

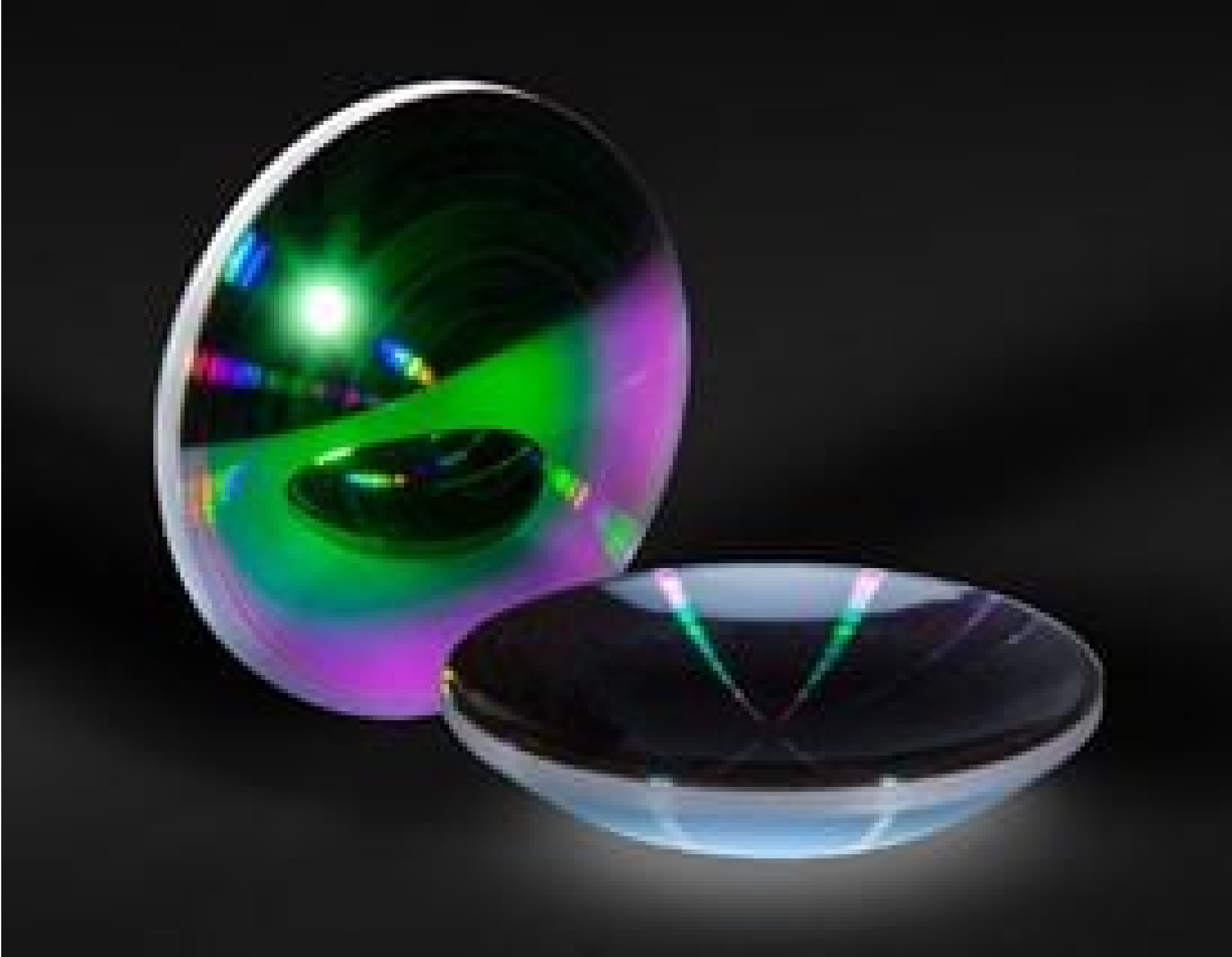

Stock #89-359 10 TO 12 DAYS
[Other Coating Options](#)

-

1

+

₹49,764.00

ADD TO CART

Qty 1-5
₹49,764.00
Qty 6+
₹39,811.00
Volume Pricing
Request Quote

Get Product Downloads

Diameter (mm):
25.00 +0.00/-0.10

Effective Focal Length EFL (mm):
50.00 @ 4000nm

Numerical Aperture NA:
0.25

Back Focal Length BFL (mm):

47.78
Substrate: Silicon (Si)
Aspheric Design Wavelength (nm): 4000
Asphere Figure Error, RMS @ 632.8nm: λ/6
Coating: Uncoated
Surface Accuracy, P-V (μm): <0.3
Centering (arcmin): ≤10
Centering, ETD (μm): <21.8
Surface Quality: 60-40
Clear Aperture CA (mm): 22.5
Edge Thickness ET (mm): 2.3
Center Thickness CT (mm): 3.00 ±0.10
f#: 2.00
Bevel: Protective bevel as needed
Edges: Diamond Turned
Radius R₂ (mm): 75.698
Shape of Back Surface: Concave
Type: Aspheric Lens
Wavelength Range (nm): 1200 - 7000
Conjugate Distance: Infinite

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View