


26mm Diameter, English Hole Gauge, Contact Reticle

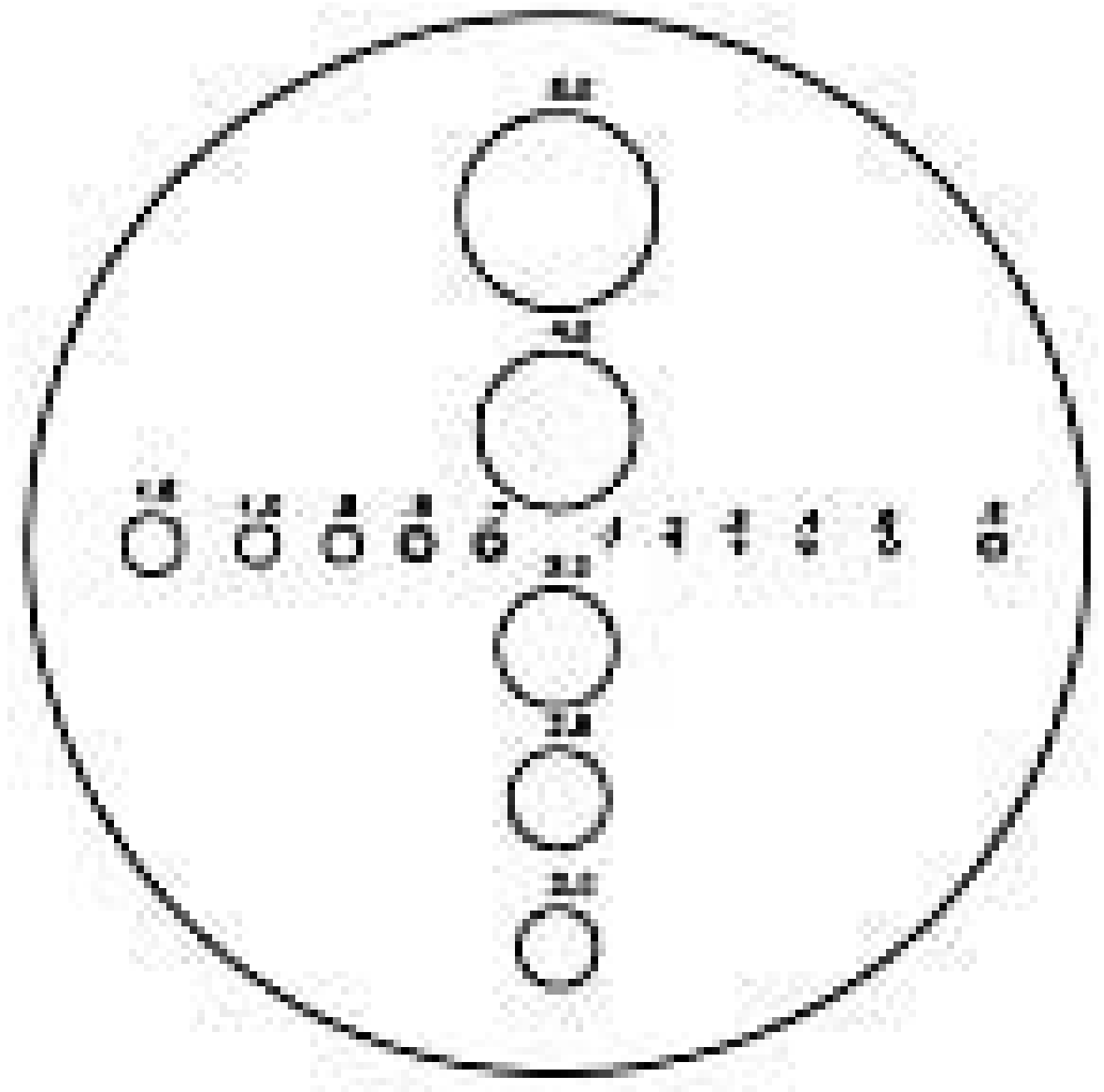

Hole Guage

Stock **#64-853** 10 TO 12 DAYS



1



₹5,829.00

ADD TO CART

Qty 1-4

₹5,829.00

Qty 5+

₹5,472.00

Volume Pricing

[Request Quote](#)

Get Product Downloads

Diameter (mm):
26.00 ±0.125

Angle Tolerance (arcsec):
±1

Line Thickness (µm):
25.00

Surface Quality:

60-40
Thickness (mm): 1.50
Thickness Tolerance (mm): ±0.10
Type: English Hole Gauge
Line to Line Accuracy (µm): ±2
Bevel: Protective bevel as needed
Parallelism (arcsec): <30
Centering (mm): 0.25
Line Thickness Tolerance (µm): ±13
Surface Flatness (P-V): 3 - 4λ

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View