
 


# 300 x 300mm, 1λ Retarder Film (WP560)

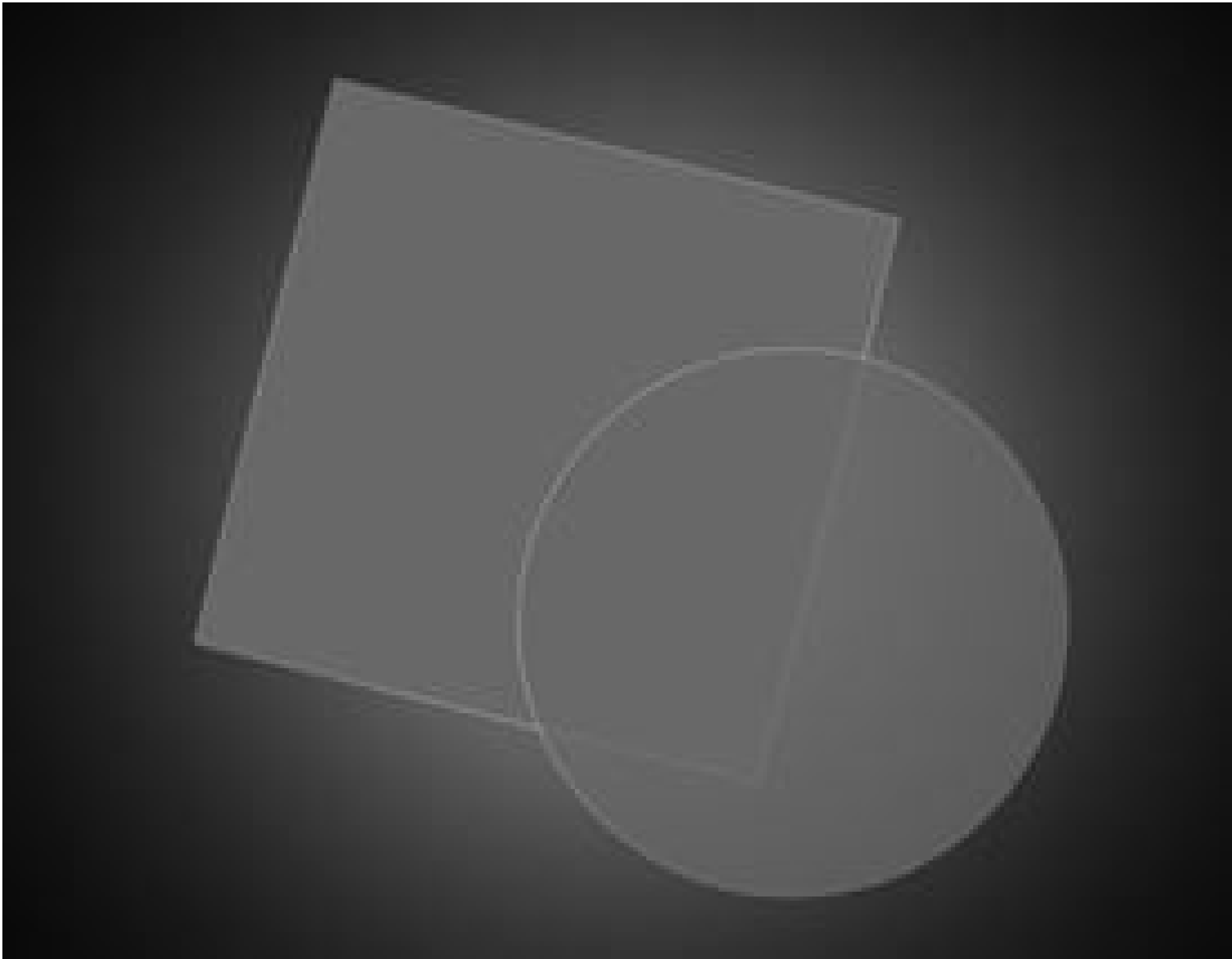

Retarder Film with protective film removed



Stock **#88-259** 10 TO 12 DAYS



1



₹22,359.00

ADD TO CART

|                               |
|-------------------------------|
| Qty 1-10                      |
| ₹22,359.00                    |
| Qty 11+                       |
| ₹20,706.00                    |
| Volume Pricing                |
| <a href="#">Request Quote</a> |

## Get Product Downloads

Design Wavelength DWL (nm):

560

Substrate: ☐

[Polymer Film WP560](#)

Length (mm):

|                                                                                                                          |
|--------------------------------------------------------------------------------------------------------------------------|
| 300.00                                                                                                                   |
| <b>Operating Temperature (°C):</b><br>-20 to +50                                                                         |
| <b>Retardance:</b><br>1λ                                                                                                 |
| <b>Dimensions (mm):</b><br>300.0 x 300.0                                                                                 |
| <b>Thickness (mm):</b><br>0.15 ±0.015                                                                                    |
| <b>Transmission (%):</b><br>>89                                                                                          |
| <b>Type:</b><br>Retarder Film                                                                                            |
| <b>Dimensional Tolerance (mm):</b><br>+0.0/-2.0                                                                          |
| <b>Construction:</b><br>Polarizing Film                                                                                  |
| <b>Phase Shift (°):</b><br>360.00                                                                                        |
| <b>Haze (%):</b><br><1                                                                                                   |
| <b>Note:</b><br>Fast axis is indicated by a black stripe on the protective film. This film should be removed before use. |
| <b>Wavelength Range (nm):</b><br>400 - 700                                                                               |
| <b>Heat Resistance (°C x Hours):</b><br>80 x 1000                                                                        |
| <b>Width (mm):</b><br>300.00                                                                                             |
| <b>Retardation (nm):</b><br>560 ±10                                                                                      |

Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |
| <b>Reach 235:</b><br><a href="#">Compliant</a>             |

---