


32mm Dia. x 3mm Thickness Uncoated, Sodium Chloride Window

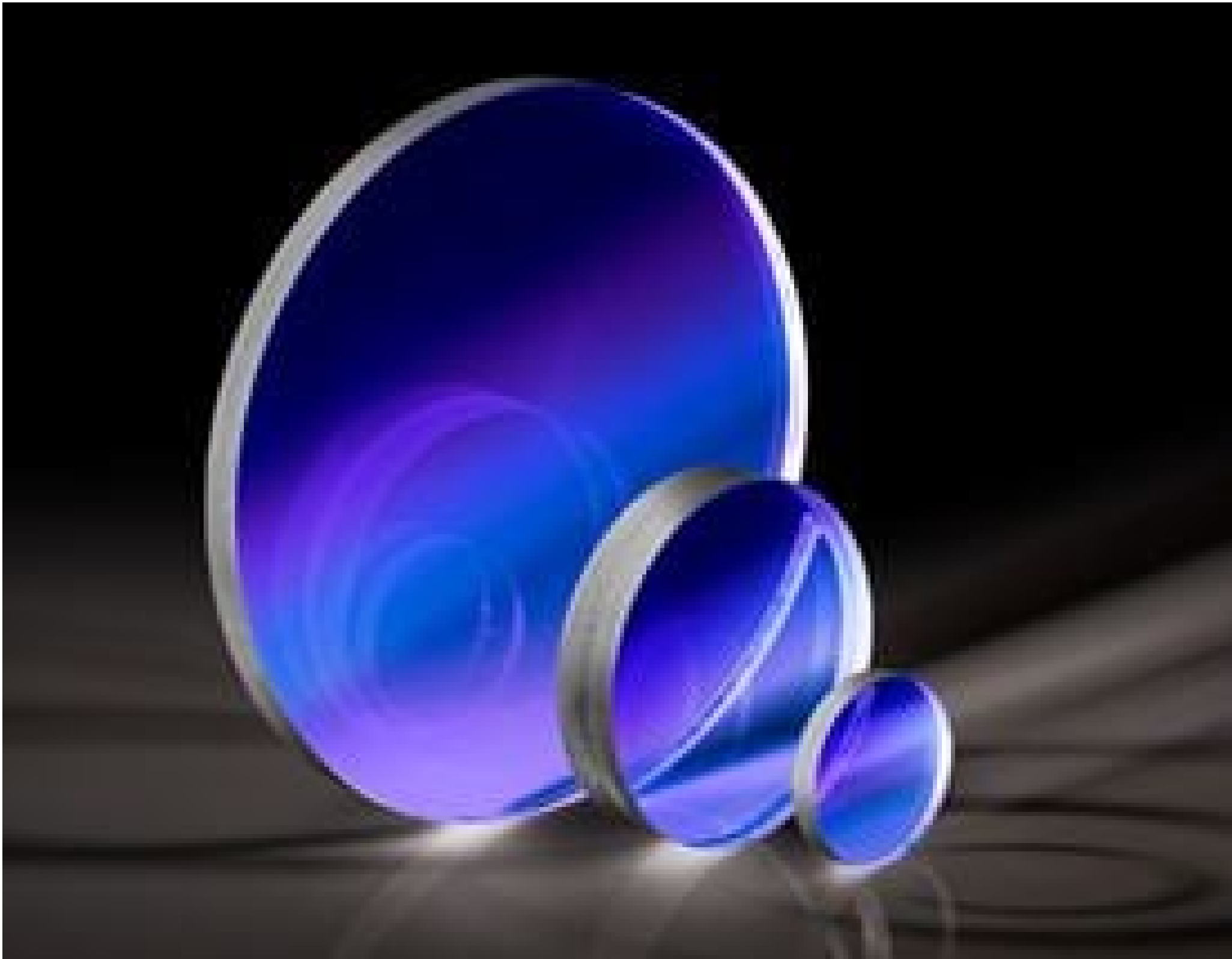

Stock #68-818 10 TO 12 DAYS

-

1

+

₹6,525.00

ADD TO CART

Qty 1-10
₹6,525.00
Qty 11+
₹5,873.00
Volume Pricing
Request Quote

Get Product Downloads



Abbe Number (v_d):
42.89

Bevel:
Protective as needed

Diameter (mm):
32.00 ±0.50

Thickness (mm): 3.00 ±0.50
Coating: Uncoated
Coefficient of Thermal Expansion CTE (10⁻⁶/°C): 44
Density (g/cm³): 2.17
Edges: Fine Ground
Index of Refraction n_d: 1.544
Knoop Hardness (kg/mm²): 18.2
Poisson's Ratio: 0.252
Solubility, in 100g of H₂O @ 273K (g): 35.70
Substrate: Sodium Chloride (NaCl)
Surface Quality: 60-40
Type: Protective Window
Wavelength Range (nm): 250 - 16000
Young's Modulus (GPa): 39.98

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View