


34mm² DUV Photodiode with Ceramic Housing

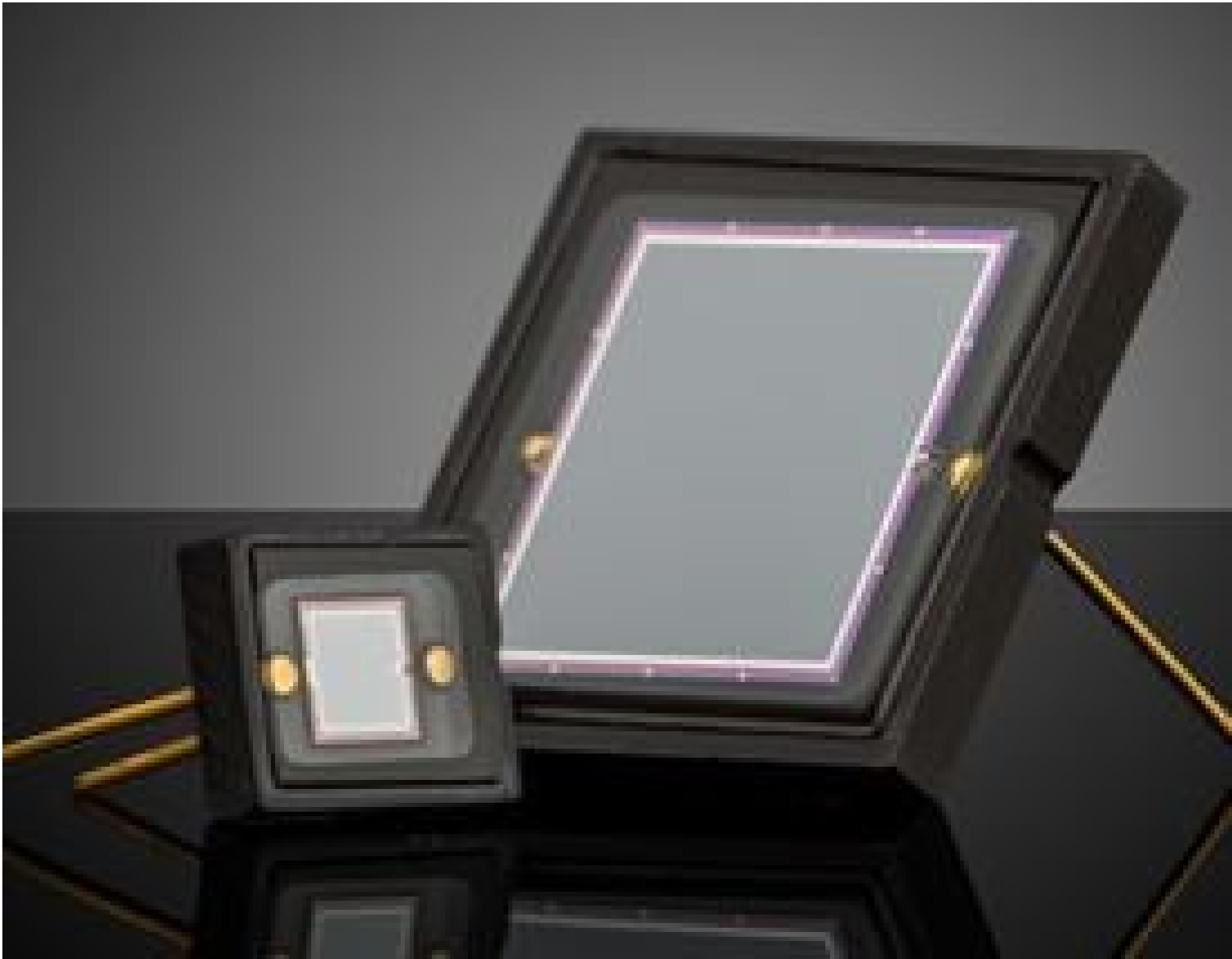

DUV Photodiodes

Stock **#84-985** 10 TO 12 DAYS

-

1

+

₹10,440.00

ADD TO CART

Qty 1-4
₹10,440.00
Qty 5+
₹9,344.00
Volume Pricing
Request Quote

Get Product Downloads

Operating Temperature (°C): -20 to +60
Size of Active Area (mm): 5.8 x 5.8
Storage Temperature (°C): -20 to +80
Rise Time (µs):

1 @ 0 V, 1 kΩ
Responsivity @ 980nm (AW): 0.5
Shunt Resistance @ V=-10mV (GΩ): Minimum: 0.1 Typical: 0.4
Responsivity @ 633nm (AW): 0.34
Responsivity @ 200nm (AW): 0.12
Capacitance @ V_R=0V (pF): 380.00
Active Area (mm²): 34.0
Noise Equivalent Power NEP (W/ Hz^{1/2}): 5.8 x 10 ⁻¹⁴ @ 0 V, 200nm
Maximum Reverse Voltage (V): 5.00
Connector: Ceramic
Peak Response Wavelength (nm): 980.00

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View