


3.5 OD 12.5mm Dia, Absorptive ND Filter

See More by [Hoya](#)

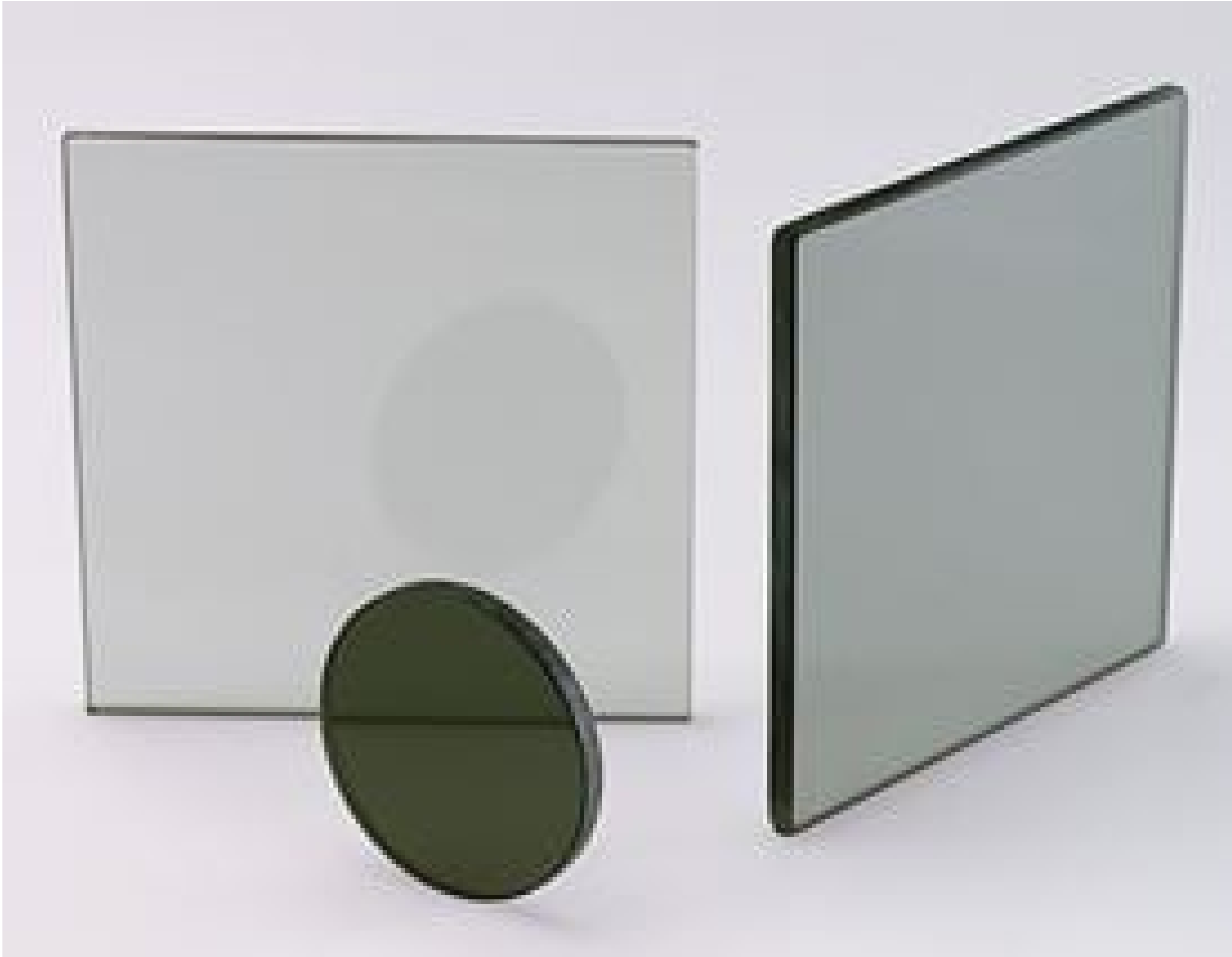

Stock **#36-268** 10 TO 12 DAYS

- 1 +

₹2,697.00

ADD TO CART

Qty 1-10
₹2,697.00
Qty 11+
₹2,436.00
Volume Pricing
Request Quote

Get Product Downloads



Diameter (mm):
12.50

Optical Density OD (Average):
3.5 ±0.2

Glass/Filter Number: Hoya ND-006
Substrate: ☐ ND Filter Glass
Coating: Uncoated
Index of Refraction n_d: 1.531
Surface Quality: 80-50
Transformation Temperature (°C): 542.00
Thickness (mm): 2.50
Thickness Tolerance (mm): ±0.5
Transmission (%): 0.03 (average)
Type: Neutral Density Filter
Blocking Wavelength Range (nm): 400 - 700
Dimensional Tolerance (mm): ±0.1
Parallelism (mm): <0.02

Regulatory Compliance

RoHS 2015: Compliant
REACH 201: Compliant
Certificate of Conformance: View