


**TECHSPEC® 38.1 x 38.1mm Protected Silver, 4-6λ Mirror**

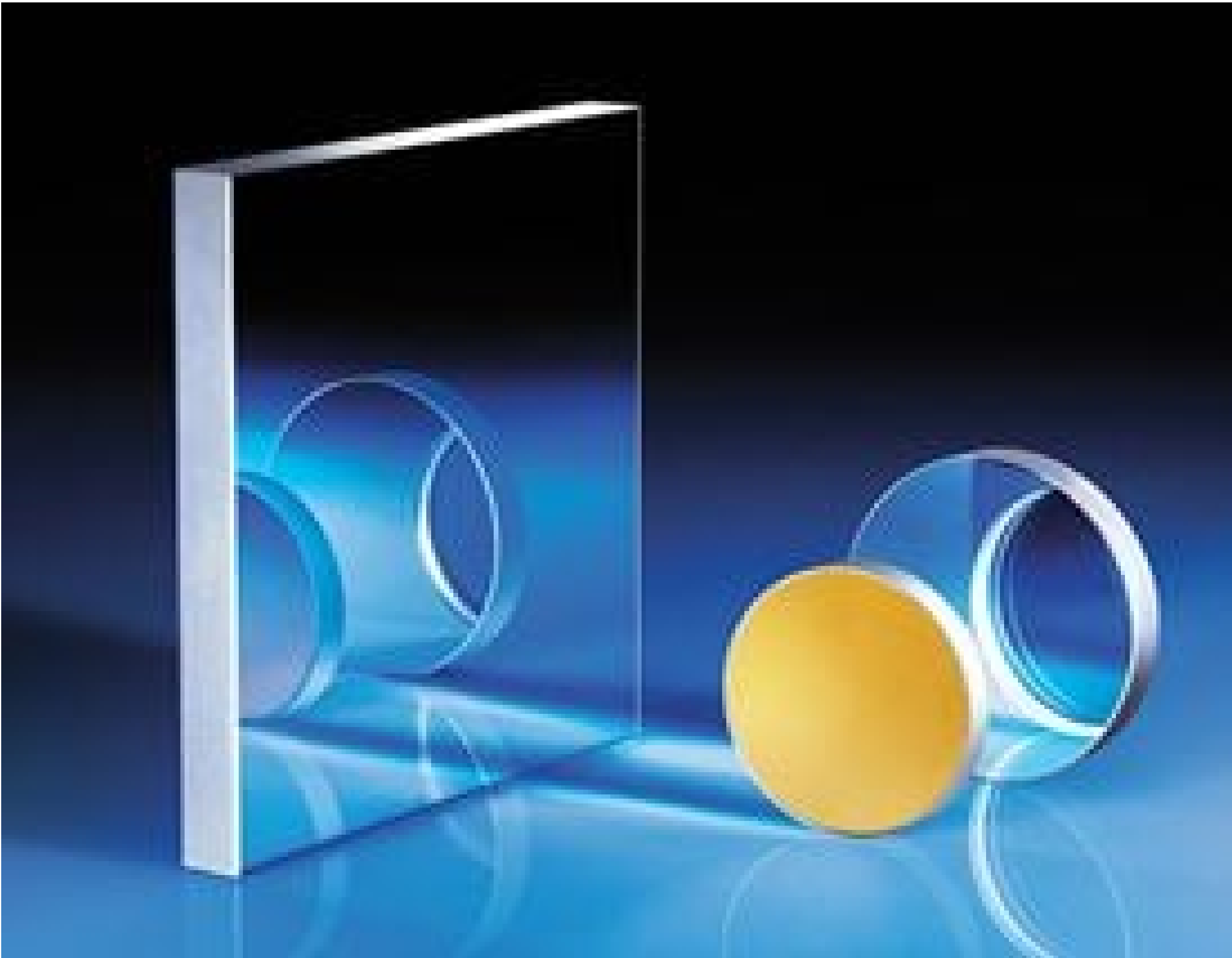

Stock **#36-046** 10 TO 12 DAYS

- 1 +

**₹3,132.00**

ADD TO CART

|                               |
|-------------------------------|
| Qty 1-5                       |
| ₹3,132.00                     |
| Qty 6+                        |
| ₹2,393.00                     |
| Volume Pricing                |
| <a href="#">Request Quote</a> |

Get Product Downloads

Surface Flatness (P-V):  
4 - 6λ

Substrate: ☐  
Float Glass

Surface Quality:  
60-40

Dimensions (mm):  
38.1 x 38.1

|                                                                                                                |
|----------------------------------------------------------------------------------------------------------------|
| <b>Dimensional Tolerance (mm):</b><br>±0.25                                                                    |
| <b>Coating Specification:</b><br>R <sub>avg</sub> >98% @450 - 2000nm<br>R <sub>avg</sub> >98% @2000 - 10,000nm |
| <b>Coating:</b><br>Protected Silver (450-10000nm)                                                              |
| <b>Coating Type:</b><br>Metal                                                                                  |
| <b>Clear Aperture CA (mm):</b><br>36.20 x 36.20                                                                |
| <b>Edges:</b><br>Seamed, 0.5mm Maximum Edge Chip                                                               |
| <b>Thickness (mm):</b><br>3.00                                                                                 |
| <b>Type:</b><br>Flat Mirror                                                                                    |
| <b>Wavelength Range (nm):</b><br>450 - 10000                                                                   |
| <b>Length (mm):</b><br>38.10                                                                                   |
| <b>Width (mm):</b><br>38.10                                                                                    |
| <b>Damage Threshold, By Design:</b> <input type="checkbox"/><br>0.5 J/cm <sup>2</sup> @ 532nm & 1064nm, 10ns   |

## Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |
| <b>Reach 233:</b><br><a href="#">Compliant</a>             |