

[See all 6 Products in Family](#)

## 40mm Dia. x 100mm FL Uncoated, DCX N-K5 Lens



Stock #32-908 CLEARANCE 20+ In Stock

MRP ₹2,270

Price inclusive of all taxes

ADD TO CART

Volume Pricing	
Qty 1+	₹2,270 each
Need More?	<a href="#">Request Quote</a>

### Product Downloads

#### General

Double-Convex Lens Type:

#### Physical & Mechanical Properties

40.00 +0.00/-0.10 Diameter (mm):

<1 Centering (arcmin):

8.00 ±0.10 Center Thickness CT (mm):

4.09	<b>Edge Thickness ET (mm):</b>
39	<b>Clear Aperture CA (mm):</b>
Protective as needed	<b>Bevel:</b>
<b>Optical Properties</b>	
100.00 @ 587.6nm	<b>Effective Focal Length EFL (mm):</b>
97.34	<b>Back Focal Length BFL (mm):</b>
Uncoated	<b>Coating:</b>
N-K5	<b>Substrate:</b> <input type="checkbox"/>
40-20	<b>Surface Quality:</b>
1.5λ	<b>Power (P-V) @ 632.8nm:</b>
λ/4	<b>Irregularity (P-V) @ 632.8nm:</b>
±1	<b>Focal Length Tolerance (%):</b>
2.5	<b>f#:</b>
0.20	<b>Numerical Aperture NA:</b>
330 - 2500	<b>Wavelength Range (nm):</b>


## Regulatory Compliance

<a href="#">View</a>	<b>Certificate of Conformance:</b>
Japan	<b>Country of Origin:</b>
Edmund Optics India Private Limited 267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038 Phone: +91- 80-6845 0000	<b>Imported By:</b>

## Product Details

- N-K5 Substrate
  - Various Anti-Reflection (AR) Coatings
  - PCX and DCX Options Available
- N-K5 Lenses are available in various diameters, focal lengths, as well as Plano-Convex and Double-Convex form factors. Anti-reflective coatings covering the VIS to NIR make these ideal for multiple applications.

## Technical Information

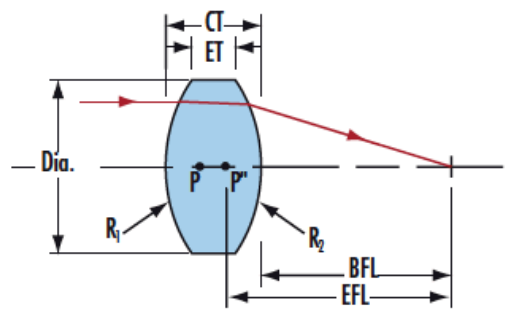

## Compatible Mounts