


TECHSPEC® 4.0mm Diameter x 5.0mm Length, N-BK7 Drum Lens

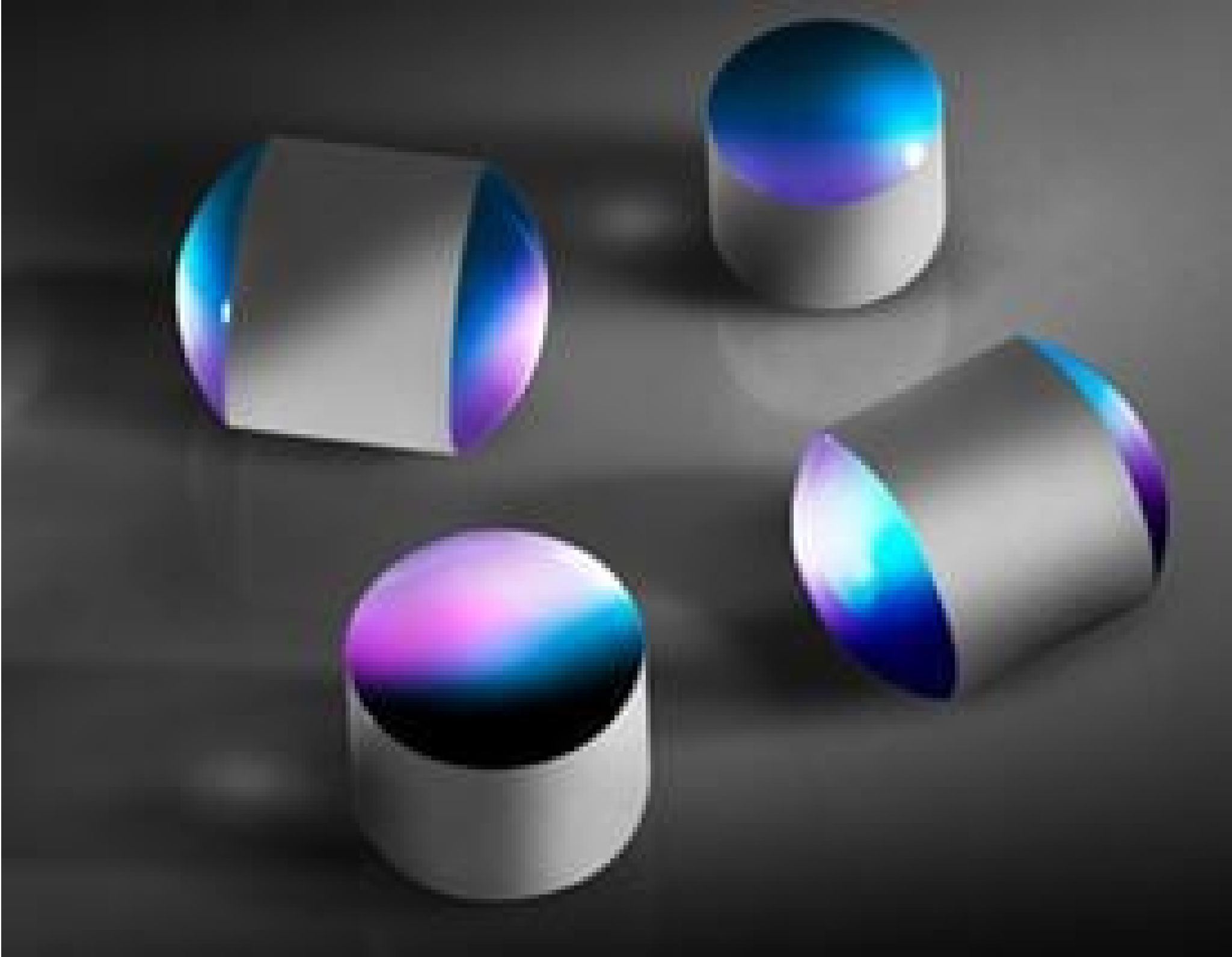

Stock #45-551 CLEARANCE 10 TO 12 DAYS

- 1 + **₹1,736.00**

ADD TO CART

Qty 1+
₹1,736.00

Volume Pricing
Request Quote

Get Product Downloads



Diameter (mm):
4.00

Substrate: ☐
[N-BK7](#)

Coating:
Uncoated

Type:
Drum Lens

Wavelength Range (nm):
350 - 2200

Index of Refraction n_d: 1.517
Length (mm): 5.00
Length Tolerance (μm): ± 3
Radius R (mm): 2.50
Radius Tolerance (μm): +0/-1.5
Surface Quality: 40-20
Diameter Tolerance (μm): +0/-50

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View