


41 x 63.5mm AR Coated Float Glass Window

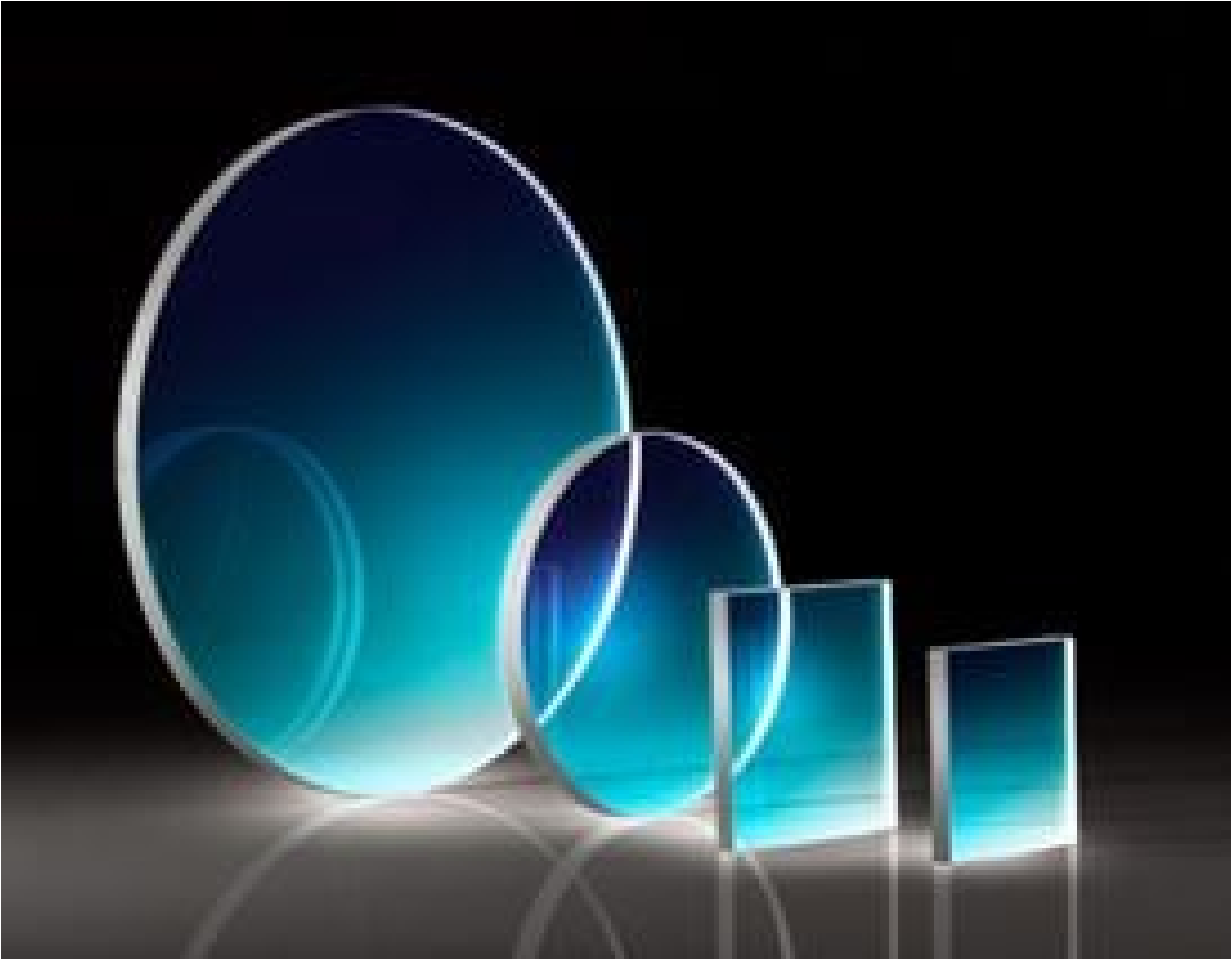

Stock **#32-740** 13 In Stock

-

1

+

MRP ₹2,120

 Price inclusive of all taxes

ADD TO CART

Volume Pricing	
Qty 1-5	₹2,120 each
Qty 6-49	₹1,905 each
Qty 50-99	₹1,796 each
Need More?	Request Quote

Product Downloads

General	
Protective Window	Type:
Glass	Type of Window:
Physical & Mechanical Properties	
41.00 x63.50	Dimensions (mm):

3.00 (nominal)	Thickness (mm):
63.50	Length (mm):
41.00	Width (mm):

Fine Ground	Edges:
-------------	--------

Optical Properties

BBAR (400-700nm)	Coating:
------------------	----------

Float Glass	Substrate: ☐
-------------	-------------------------------------

80-50	Surface Quality:
-------	------------------

400 - 700	Wavelength Range (nm):
-----------	------------------------

4 - 6λ	Surface Flatness (P-V):
--------	-------------------------

Regulatory Compliance

Compliant	RoHS 2015:
-----------	------------

View	Certificate of Conformance:
------	-----------------------------

Compliant	Reach 247:
-----------	------------

United States	Country of Origin:
---------------	--------------------

Edmund Optics India Private Limited 267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038 Phone: +91- 80-6845 0000	Imported By:
---	--------------

Product Details

- Transmits Visible and Near Infrared Wavelengths
- Available Uncoated or with an Anti-Reflection Coating
- Variety of Sizes Available

Float Glass Optical Windows are optical glass with polished faces that are relatively parallel and are typically used as a protective element between two environments. Float glass readily transmits visible and near-infrared wavelengths and can be used in a wide variety of applications. Float Glass Optical Windows are versatile products offered in circular and rectangular options. They are available uncoated or with BBAR (Broadband Anti-Reflective) 400-700nm coating.

Compatible Mounts