


41 x 63.5mm AR Coated Float Glass Window

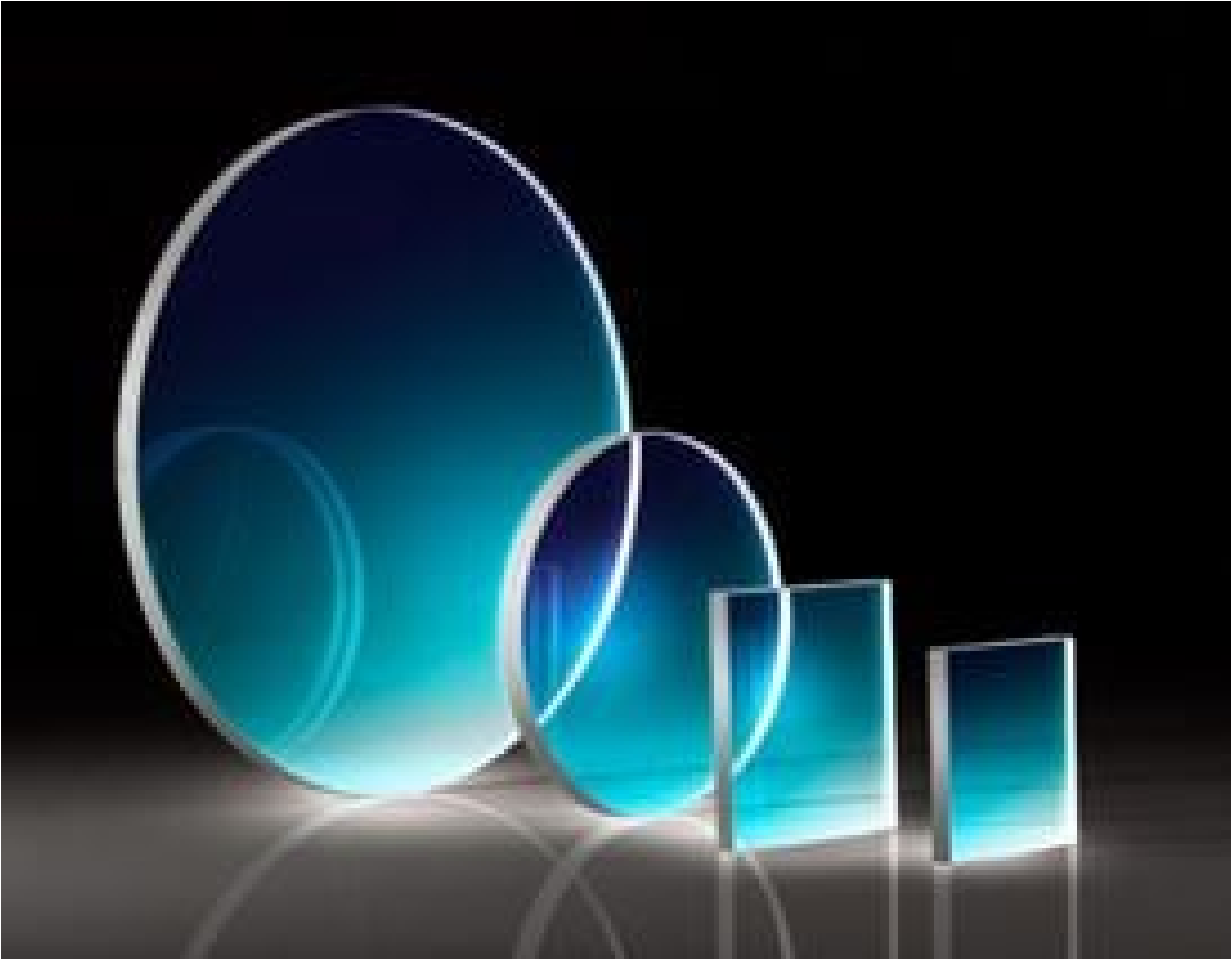

Stock **#32-740** 20+ In Stock

-

1

+

₹1,797

ADD TO CART

Volume Pricing	
Qty 1-5	₹1,797 each
Qty 6-49	₹1,614 each
Qty 50-99	₹1,522 each
Need More?	Request Quote

Product Downloads

General

Protective Window

Type:

Physical & Mechanical Properties

41.00 x 63.50

Dimensions (mm):

3.00 (nominal)

Thickness (mm):

63.50	Length (mm):
41.00	Width (mm):
Fine Ground	Edges:
Optical Properties	
BBAR (400-700nm)	Coating:
Float Glass	Substrate: ☐
80-50	Surface Quality:
400 - 700	Wavelength Range (nm):
4 - 6λ	Surface Flatness (P-V):
Regulatory Compliance	
Compliant	RoHS 2015:
View	Certificate of Conformance:
Compliant	Reach 247:
United States	Country of Origin:
Edmund Optics India Private Limited	Imported By:

Product Details

- Transmits Visible and Near Infrared Wavelengths
- Available Uncoated or with an Anti-Reflection Coating
- Variety of Sizes Available

Float Glass Optical Windows are optical glass with polished faces that are relatively parallel and are typically used as a protective element between two environments. Float glass readily transmits visible and near-infrared wavelengths and can be used in a wide variety of applications. Float Glass Optical Windows are versatile products offered in circular and rectangular options. They are available uncoated or with BBAR (Broadband Anti-Reflective) 400-700nm coating.

Compatible Mounts