


[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Specialty Mirrors](#) / [Cold Mirrors](#)

[See all 5 Products in Family](#)

45° AOI 12.5mm Sq, Cold Mirror

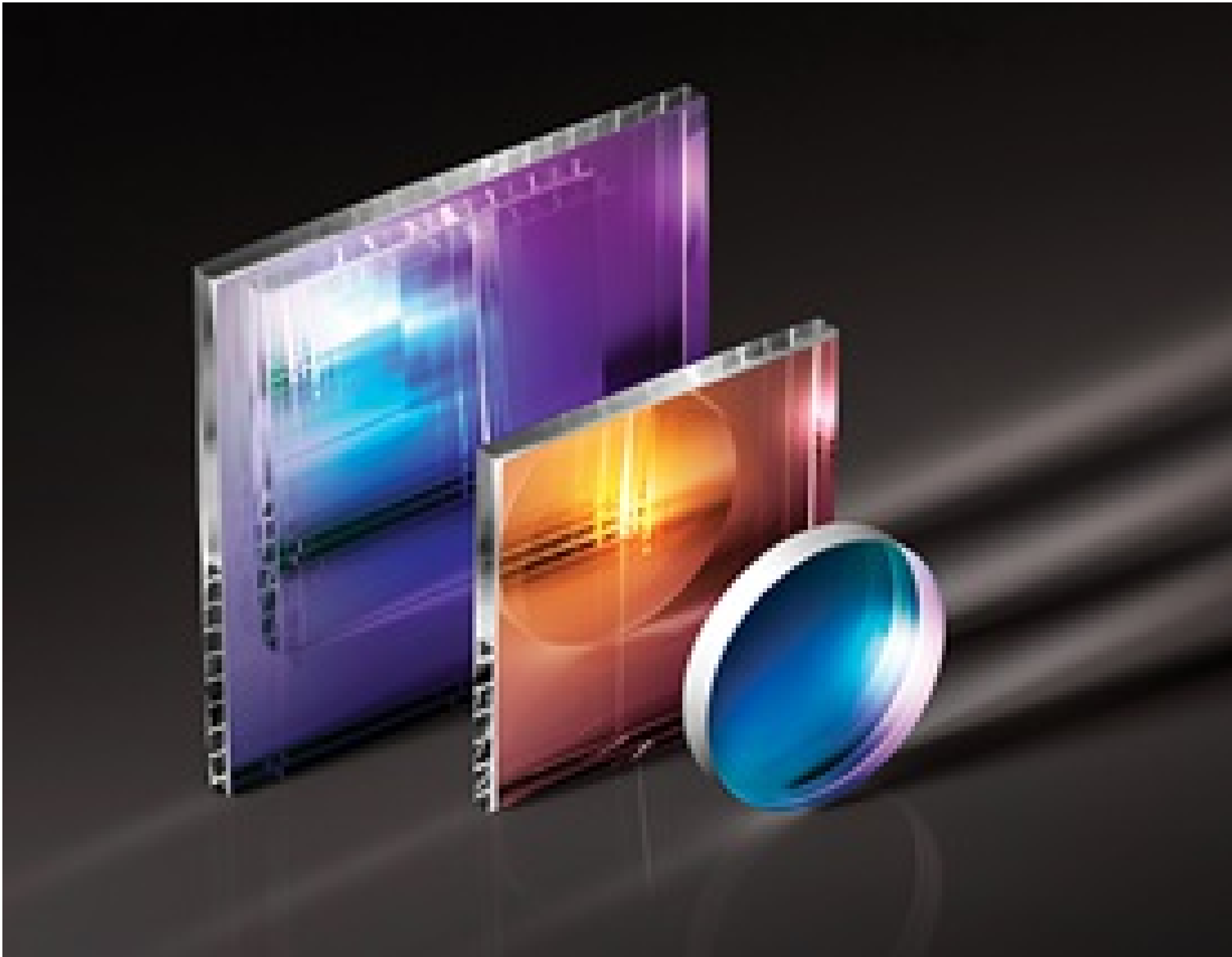

Stock **#62-634** CLEARANCE 10 TO 12 DAYS

- 1 +

₹952.65

ADD TO CART

Qty 1+
₹952.65

Volume Pricing
Request Quote

Get Product Downloads

Angle of Incidence (°):
45.00

Coating:
Cold Mirror, 45°

Substrate: ☐
[BOROFLOAT®](#)

Dimensions (mm):
12.5 x 12.5

Surface Quality:
80-50

Thickness (mm): 1.10
Type: Cold Mirror
Dimensional Tolerance (mm): ±0.5
Coating Specification: R_{avg} >90% @425 - 650nm T_{avg} >85% @ 800 - 1200nm
Wavelength Range (nm): 425 - 1200
Surface Flatness (P-V): 4 - 6λ
Coating Type: Dielectric

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View
