


TECHSPEC®

470nm CWL, 50mm Dia., Hard Coated OD 4.0 10nm Bandpass Filter

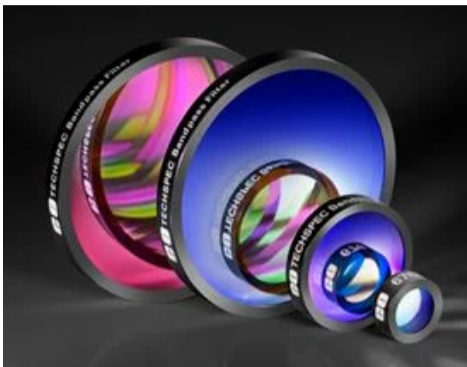

Stock #65-205 **1 In Stock**

 
- 1 +

MRP ₹68,505

Price inclusive of all taxes

ADD TO CART

TECHSPEC Hard Coated OD 4.0 10nm Bandpass Filters



Volume Pricing	
Qty 1-5	₹68,505 each
Qty 6-25	₹54,784 each
Qty 26-49	₹51,378 each
Need More?	Request Quote

Product Downloads

- STEP:step
- Curve:pdf
- PDF Drawing:pdf
- IGES:igs
- eDrawing:easm
- EO Spec Sheet
- [Download All](#)

General

Type: Bandpass Filter

Typical Applications: Acridine Yellow

Physical & Mechanical Properties

Diameter (mm): 50.00 +0.0/-0.1

Clear Aperture CA (mm): 45

Construction: Mounted in Black Anodized Ring

Physical Durability: Adhesion per MIL-PRF-13830B, Section C.4.5.12
Moderate abrasion per MIL-PRF-13830B, Section C.4.5.11
Cleaning per MIL-C-48497A Section 4.5.4.2

Substrate Thickness (mm): 3.5 ±0.5 typical

Optical Properties

Angle of Incidence (°): 0

Optical Density OD (Average): ≥4.0

Center Wavelength CWL (nm): 470.00 ±2.0

Full Width-Half Max FWHM (nm): 10.00 ±2.0

Full Width-Half Max FWHM Tolerance (nm): ±2.0

Substrate: Optical Glass

Minimum Transmission (%):	≥85	Coating:	Hard Coated
Surface Quality:	80-50	Blocking Wavelength Range (nm):	200 - 1200
Threading & Mounting			
Mount Thickness (mm):	5.0 ±0.1		
Environmental & Durability Factors			
Environmental Durability:	Humidity per MIL-STD-810H, Section 507.6 Temperature per MIL-STD-810H, Section 501.7 and 502.7		
Regulatory Compliance			
RoHS 2015:	Compliant	Certificate of Conformance:	View
Reach 247:	Compliant		
Country of Origin:	United States	Imported By:	Edmund Optics India Private Limited 267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038 Phone: +91-80-6845 0000

Need different specs or modifications?

Edmund Optics offers comprehensive custom manufacturing services for optical and imaging components tailored to your specific application requirements. Whether in the prototyping phase or preparing for full-scale production, we provide flexible solutions to meet your needs. Our experienced engineers are here to assist—from concept to completion.

Our capabilities include:

- Custom dimensions, materials, coatings, and more
- High-precision surface quality and flatness
- Tight tolerances and complex geometries
- Scalable production—from prototype to volume

Learn more about our [custom manufacturing capabilities](#) or submit an inquiry [here](#).

Product Details

- Ideal for Life Sciences or Chemical Analysis
- Available in UV, VIS, and IR Center Wavelengths
- Feature High Performance Hard Coatings
- Hard Coated OD 4.0 **5nm**, **25nm**, and **50nm** Bandpass Filters Also Available

TECHSPEC® Hard Coated OD 4.0 10nm Bandpass Filters are narrowband filters used extensively in applications including flame photometry, elemental or laser line separation, fluorescence, laser diode cleanup, or chemical detection or analysis. These optical filters offer steep slopes with deep blocking to achieve high performance in demanding applications. TECHSPEC Hard Coated OD 4.0 10nm Bandpass Filters feature durable hard coatings to minimize filter degradation while increasing transmission. The bandpass filters are available in UV, VIS, and IR center wavelengths.

Note: These filters are optimized for high spectral performance rather than high Laser Induced Damage Thresholds (LIDT). A typical LIDT for these filters is 1 J/cm² @ 532nm, 10ns. Please [contact us](#) if you require a filter with a higher LIDT value.


Technical Information

Accessories

Note: Compatible accessories for individual stock numbers may vary. If unsure about which accessories work with your products, please contact us [here](#).

	Title	Compare	Stock Number	Price	Buy
MORE+	12.5mm Dia., Nd:YAG Hard Coated OD 4.0 10nm Bandpass Filter Kit (4 Filters)		#15-097	₹70,623 Request Quote	CONTACT US 1
MORE+	25mm Dia., Nd:YAG Hard Coated OD 4.0 10nm Bandpass Filter Kit (4 Filters)		#15-098	₹1,13,502 Request Quote	CONTACT US 1
MORE+	50mm Dia., Nd:YAG Hard Coated OD 4.0 10nm Bandpass Filter Kit (4 Filters)		#15-099	₹2,78,456 Request Quote	CONTACT US 1

Related Products

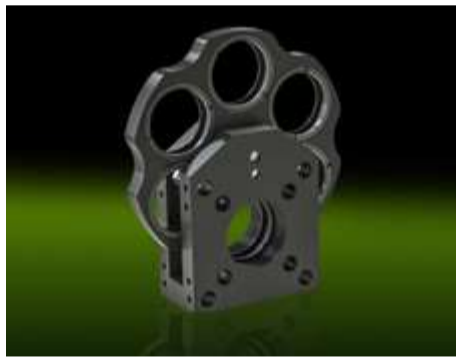

Manual Cage Filter Wheel



C, S, and T-Mount Circular
Optic Mounts



Cotton-Tipped Swab Applicators



Hard Coated OD 4.0 5nm
Bandpass Filters

Frequently Purchased Together



#59-446 - M55 x 0.75 Male to M52
x 0.75 Female Step-Down Adapter
₹3,456

Qty



#65-198 - 430nm CWL, 50mm Dia.,
Hard Coated OD 4.0 10nm
Bandpass Filter
₹68,505

Qty



#34-507 - 505nm CWL, 50mm Dia.,
Hard Coated OD 4.0 10nm
Bandpass Filter
₹68,505

Qty


































 






















#65-194 - 405nm CWL, 50mm Dia.,
Hard Coated OD 4.0 10nm
Bandpass Filter
₹68,505

Qty

Compatible Mounts

	Title	Type	Compare	Stock Number	Price	Buy
MORE+	50.0mm Optic Dia., Optic Mount	Fixed		#64-567	₹4,969 Request Quote	4 In Stock 1
MORE+	50.0mm Optic Dia., Optic Mount	Fixed		#64-568	₹4,969 Request Quote	7 In Stock 1

	Title	Type	Compare	Stock Number	Price	Buy
 	9.5 - 73.0mm Optic Dia., Three-Screw Adjustable Ring Mount	Fixed		#36-605	₹8,374 Request Quote	CONTACT US <input type="text" value="1"/> 
 	50.0/50.8mm Optic Dia., E-Series Kinematic Mount	Adjustable - Tip-Tilt		#15-867	₹9,685 Request Quote	CONTACT US <input type="text" value="1"/> 
 	10.0 - 60.0mm Optic Height, Metric Bar-Type Optic Holder	Fixed		#55-530	₹10,896 Request Quote	CONTACT US <input type="text" value="1"/> 
 	19.5 - 108.0mm Optic Dia., Three-Screw Adjustable Ring Mount	Fixed		#03-670	₹11,501 Request Quote	1 In Stock <input type="text" value="1"/> 
 	7.0 - 67.0 Optic Height, English Bar-Type Optic Holder	Fixed		#03-669	₹11,703 Request Quote	6 In Stock <input type="text" value="1"/> 
 	8.0 - 118.0 Optic Height, English Bar-Type Optic Holder	Fixed		#03-666	₹12,107 Request Quote	10 In Stock <input type="text" value="1"/> 
 	50.0/50.8mm Optic Dia., Optical Cell Assembly	Fixed		#36-465 CLEARANCE	₹12,739 Request Quote	2 In Stock <input type="text" value="1"/> 
 	50.0/50.8mm Optic Dia., Kinematic Mount, 2-Screws	Adjustable - Tip-Tilt		#58-852	₹13,621 Request Quote	5 In Stock <input type="text" value="1"/> 
 	50.0/50.8mm Optic Dia., Kinematic Mount, 3-Screws	Adjustable - Tip-Tilt		#58-855	₹15,840 Request Quote	20+ In Stock <input type="text" value="1"/> 
 	50.0/50.8mm Optic Dia., Stainless Steel Kinematic Mount, 2-Screws	Adjustable - Tip-Tilt		#26-816	₹24,819 Request Quote	12 In Stock <input type="text" value="1"/> 
 	50.0/50.8mm Optic Dia., Stainless Steel Kinematic Mount, 3-Screws	Adjustable - Tip-Tilt		#26-819	₹27,039 Request Quote	CONTACT US <input type="text" value="1"/> 
 	50.0/50.8mm Optic Dia., X-Y Translating Optic Mount	Adjustable - Linear (XY)		#62-957	₹31,074 Request Quote	1 In Stock <input type="text" value="1"/> 
 	50.0/50.8mm Optic Dia., Kinematic Mirror Mount	Adjustable - Tip-Tilt		#55-005	₹36,422 Request Quote	6 In Stock <input type="text" value="1"/> 
 	50.0/50.8mm Optic Dia., Kinematic Mirror Mount with Micrometer	Adjustable - Tip-Tilt		#56-326	₹39,045 Request Quote	CONTACT US <input type="text" value="1"/> 
 	5.0 - 100.0mm Optic Dia., Self-Centering Jaw Clamp	Fixed		#16-078	₹41,365 Request Quote	CONTACT US <input type="text" value="1"/> 
 	50.0/50.8mm Optic Dia., Precision Gimbal Mount	Adjustable - Gimbal		#55-000	₹51,454 Request Quote	7 In Stock <input type="text" value="1"/> 

	Title	Type	Compare	Stock Number	Price	Buy
 	50.0/50.8mm Optic Dia., X-Y-Z Translating Optic Mount	Adjustable - Linear (XYZ)		#62-960	₹61,039 Request Quote	20+ In Stock <input type="text" value="1"/> 
 	50.0/50.8mm Optic Dia., 5 Axes Optical Mount	Adjustable - Linear (XYZ) & Tip-Tilt		#13-778	₹84,748 Request Quote	10 In Stock <input type="text" value="1"/> 

Check out our full selection of mounts [here](#).

Resources

Media Type

- Application Note
- Video
- Published Article
- FAQ
- Glossary
- Trending in Optics

APPLICATION NOTE

The Importance of Optical Filter Orientation...

APPLICATION NOTE

Custom Bandpass Filter using Shortpass an...

VIDEO

Optical Filters Review

VIDEO

Optical Filter Coatings: Comparison of Traditional a...

PUBLISHED ARTICLE

Selecting Color Filter Glass for Life Science Applications

FAQ

What type of material should I look for in a filter?

[View More](#)