


51.5mm Diameter Float Glass Window

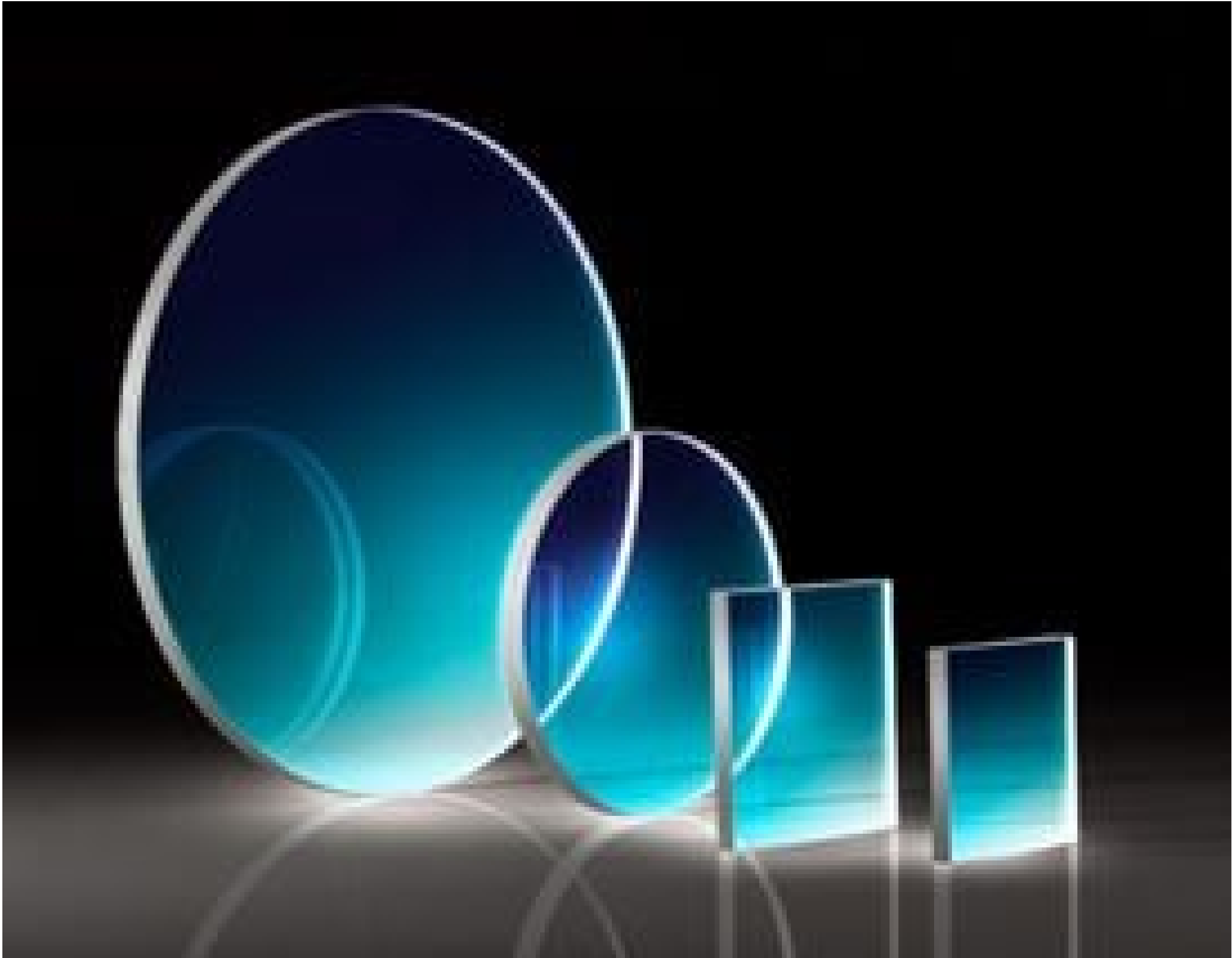

Stock **#44-063** 20+ In Stock

-

1

+

₹1,229

ADD TO CART

Volume Pricing	
Qty 1-5	₹1,229 each
Qty 6-49	₹1,100 each
Qty 50-99	₹1,027 each
Need More?	Request Quote

Product Downloads

General	
Protective Window	Type:
Physical & Mechanical Properties	
Protective as needed	Bevel:
51.50	Diameter (mm):

1.50	Thickness (mm):
Fine Ground	Edges:
Optical Properties	
Uncoated	Coating:
Float Glass	Substrate:
4 - 6λ	Surface Flatness (P-V):
80-50	Surface Quality:
350 - 2000	Wavelength Range (nm):
Regulatory Compliance	
Compliant	RoHS 2015:
View	Certificate of Conformance:
Compliant	Reach 247:
United States	Country of Origin:
Edmund Optics India Private Limited	Importer:

Product Details

- Transmits Visible and Near Infrared Wavelengths
- Available Uncoated or with an Anti-Reflection Coating
- Variety of Sizes Available

Float Glass Optical Windows are optical glass with polished faces that are relatively parallel and are typically used as a protective element between two environments. Float glass readily transmits visible and near-infrared wavelengths and can be used in a wide variety of applications. Float Glass Optical Windows are versatile products offered in circular and rectangular options. They are available uncoated or with BBAR (Broadband Anti-Reflective) 400-700nm coating.

Compatible Mounts

