


55mm Dia. Uncoated Laser Debris Shield

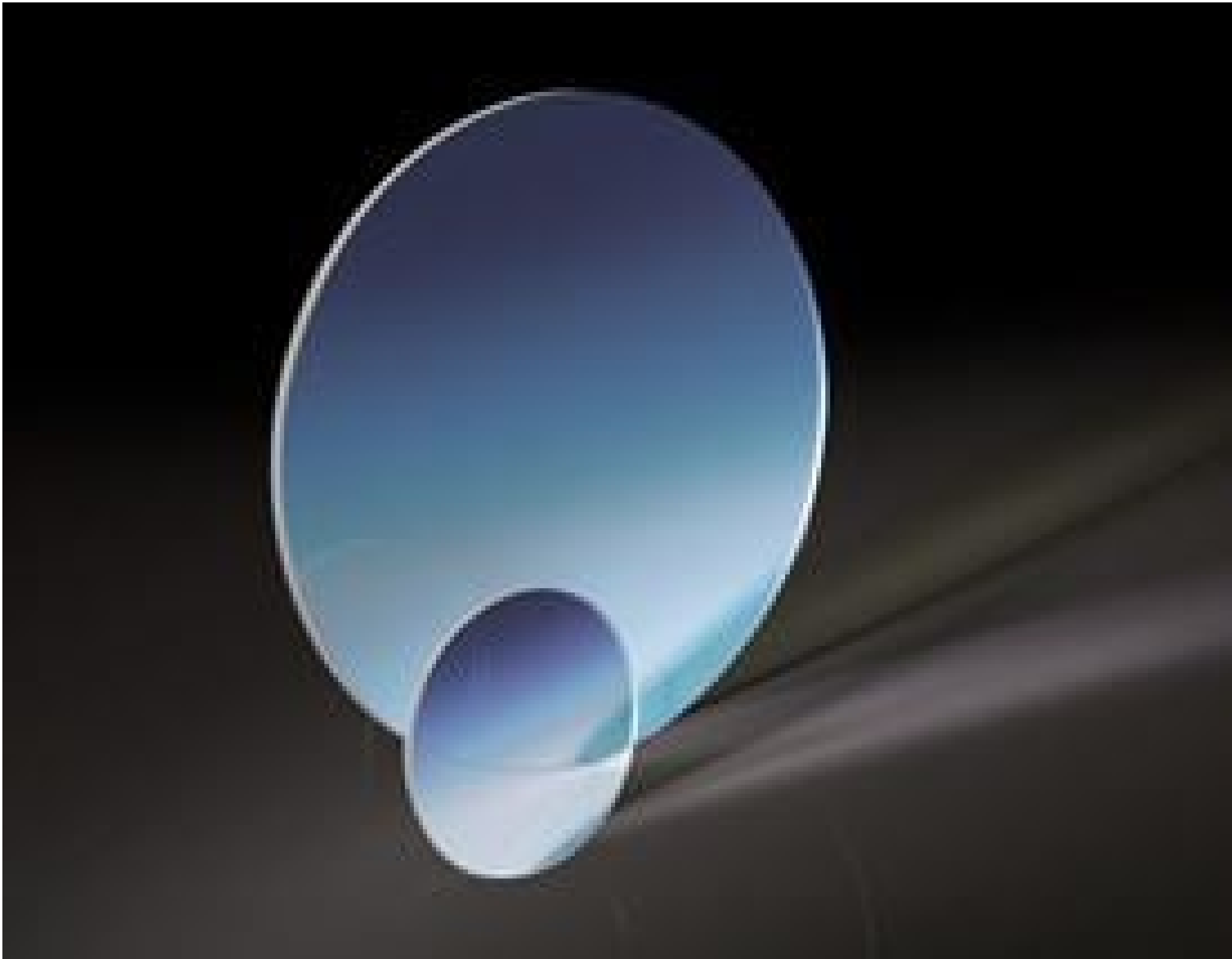

Laser Debris Shields

Stock **#37-667** 10 TO 12 DAYS



1



₹5,438.00

ADD TO CART

Qty 1-5

₹5,438.00

Qty 6+

₹4,633.00

Volume Pricing

[Request Quote](#)

Get Product Downloads



Clear Aperture CA (mm):
46.75

Coating:
Uncoated

Diameter (mm):
55.00 ±0.1

Substrate: Fused Quartz
Index of Refraction n_d: 1.458
Surface Quality: 40-20
Thickness (mm): 1.50 +0.15/-0.00
Type: Protective Window
Parallelism (arcmin): <45
Bevel: Break Edges
Clear Aperture (%): 85
Transmitted Wavefront, P-V: $\lambda/2$ (70% of Dia.)
Abbe Number (v_d): 67.8
Wavelength Range (nm): 200 - 2200
Edges: Fine Ground
Type of Window: Glass

Regulatory Compliance

RoHS 2015: Compliant
Reach 211: Compliant
Certificate of Conformance: View