


5mm Dia/10 Div, 19mm Dia. Microscope Eyepiece Reticle

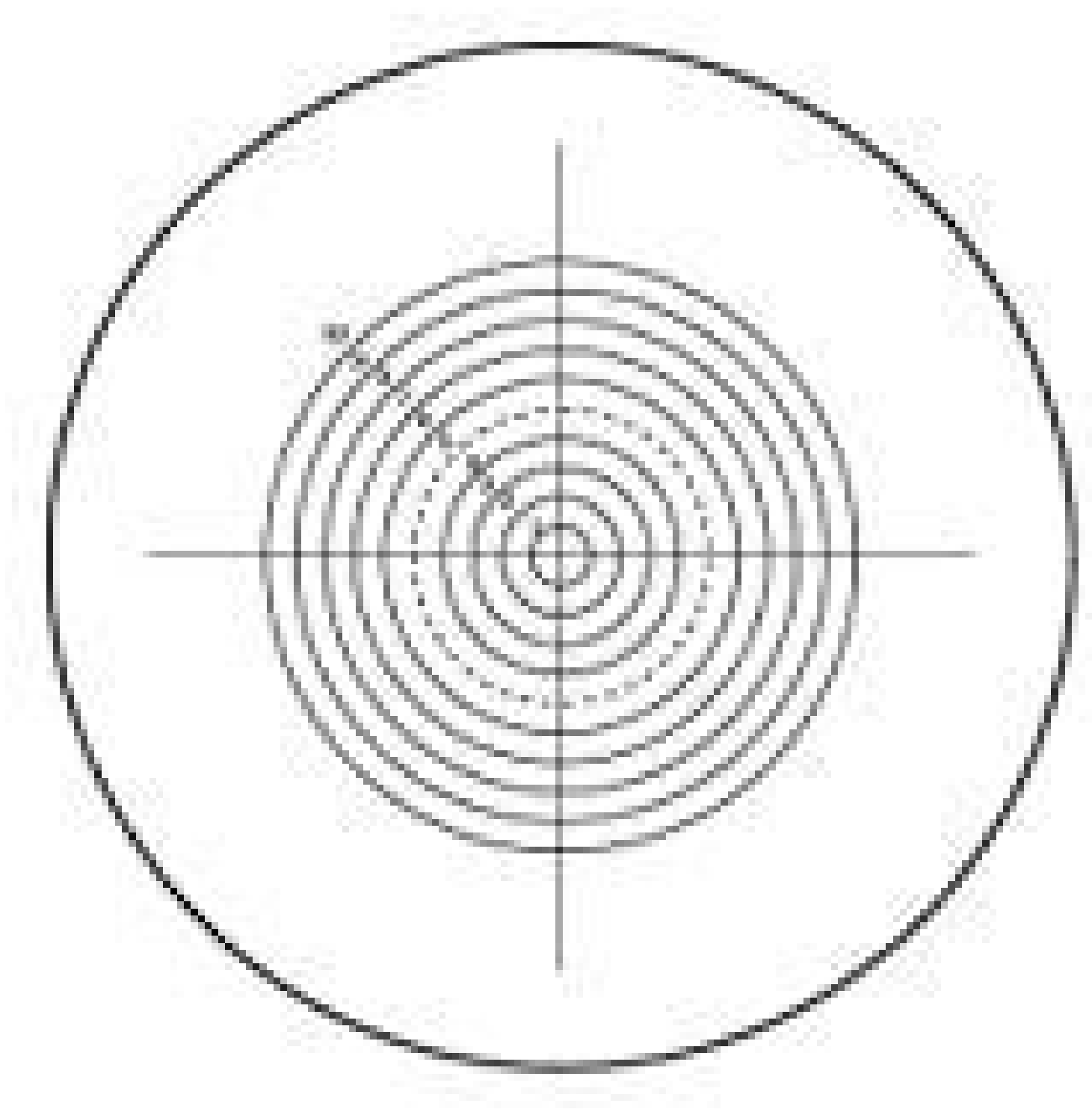

Stock **#54-423** 20+ In Stock

-

1

+

₹18,054

Price inclusive of all taxes

ADD TO CART

Volume Pricing	
Qty 1-4	₹18,054 each
Qty 5+	₹17,268 each
Need More?	Request Quote

Product Downloads

General

No

NIST Certification:

Physical & Mechanical Properties

19.00 +0.0/-0.1

Diameter (mm):

±5

Overall Accuracy (µm):

Thickness (mm):

1.50 ±0.1	
	Line Width (mm):
0.008	
	Centering (mm):
0.1	
	Line Width Tolerance (mm):
± 0.002	

Optical Properties

	Substrate: 
B270	

Regulatory Compliance

	RoHS 2015:
Compliant	
	Reach 209:
Compliant	

	Certificate of Conformance:
View	

	Country of Origin:
United Kingdom	
	Imported By:
Edmund Optics India Private Limited 267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038 Phone: +91- 80-6845 0000	

Product Details

- Designed for 1XObjective Power
- Concentric Circle Pattern
- B270 Substrate

Reticles are clear glass discs marked with scales or patterns, which fit into microscope eyepieces at the internal real image plane. This is the intermediate image of the specimen/object under inspection produced bythe objective lens of the microscope. Byplacing the reticle at this position, the scale/pattern is superimposed on the image and both are in simultaneous focus. These reticles are all designed for an objective power of 1X. They are numbered 1-10, with dashed circle at 5mm and a 12.5mm crossline.