


600 Grooves, 12.7mm Square, 1600nm NIR Ruled Grating

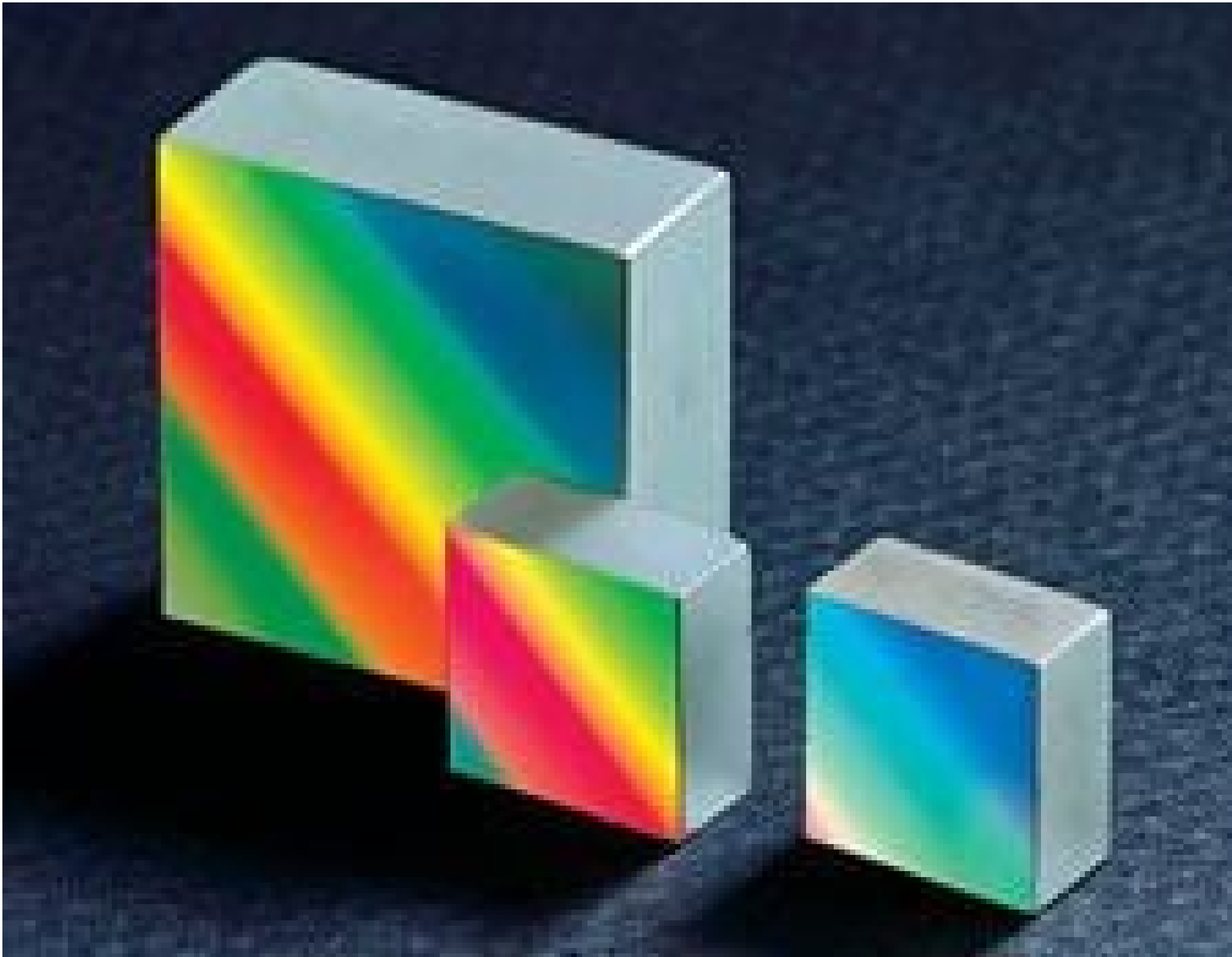

Stock #54-850 10 TO 12 DAYS

-

1

+

₹11,745.00

ADD TO CART

Qty 1+
₹11,745.00

Volume Pricing
Request Quote

Get Product Downloads



Groove Density (grooves/mm):
600

Wavelength Range (nm):
700 - 3000

Blaze Wavelength (nm):
1600

Blaze Angle (°):
28.68

Dimensions (mm):

12.7 x 12.7 ±0.5
Clear Aperture (%) : 90
Coating : Bare Gold
Construction : Ruled Grating
Direction of Grooves : Parallel to Short Dimension
Length (mm) : 12.70
Substrate :  Float Glass
Thickness (mm) : 6.00 ±0.5
Type : Reflective Diffraction Grating
Width (mm) : 12.70
Alignment of Grooves to Edge (°) : ±0.5

Regulatory Compliance

RoHS 2015 : Compliant
Reach 219 : Compliant
Certificate of Conformance : View