


830 Grooves, 12.7mm Square, 1250nm NIR Ruled Grating

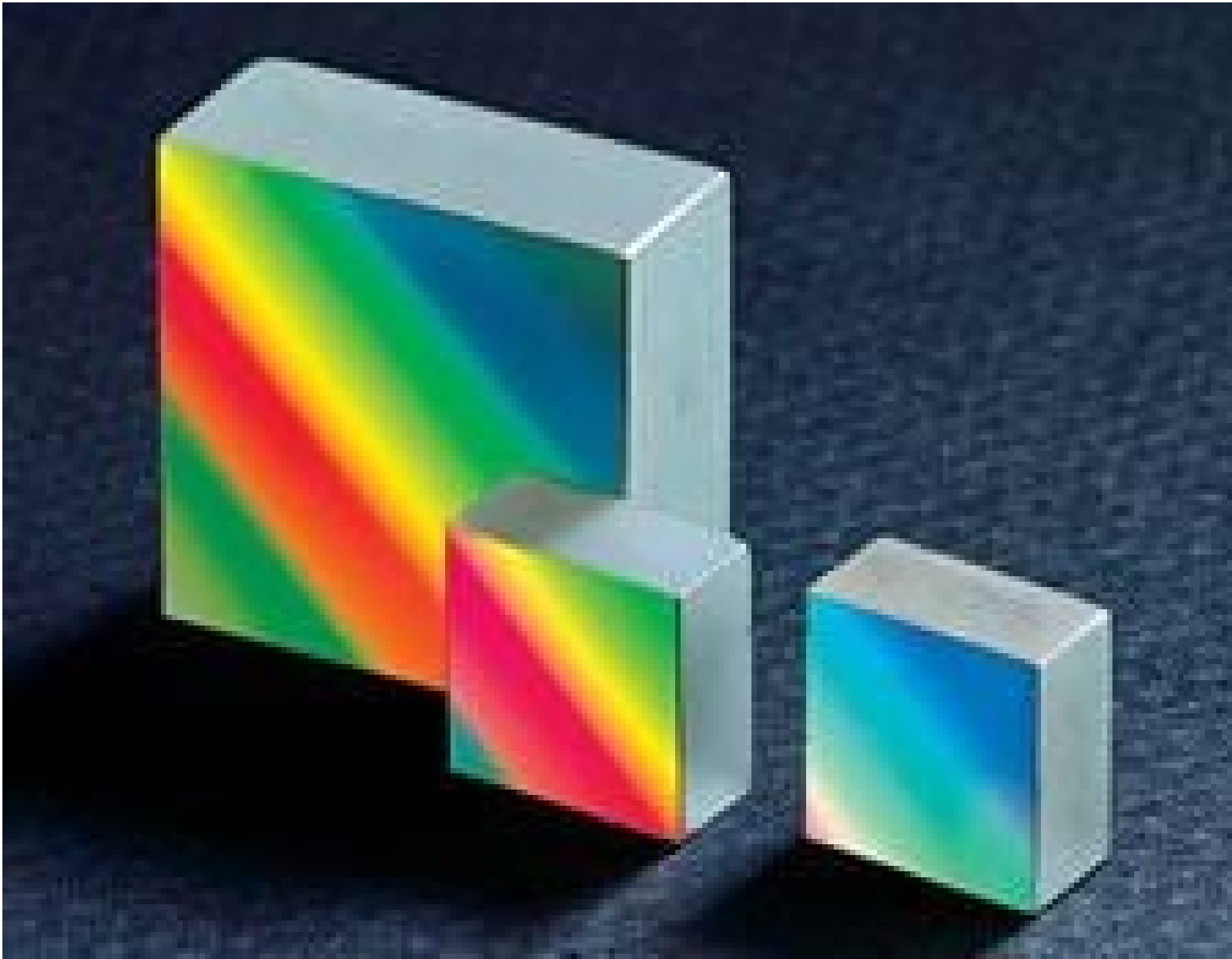

Stock #46-079 10 TO 12 DAYS

- 1 + ₹11,745.00

ADD TO CART

Qty 1+
₹11,745.00

Volume Pricing
Request Quote

Get Product Downloads



Groove Density (grooves/mm):
830

Wavelength Range (nm):
700 - 3000

Blaze Wavelength (nm):
1200

Blaze Angle (°):
29.87

Dimensions (mm):

12.7 x 12.7 ±0.5
Clear Aperture (%) : 90
Coating: Bare Gold
Construction: Ruled Grating
Direction of Grooves: Parallel to Short Dimension
Length (mm): 12.70
Substrate:  Float Glass
Thickness (mm): 6.00 ±0.5
Type: Reflective Diffraction Grating
Width (mm): 12.70
Alignment of Grooves to Edge (°): ±0.5

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View