


830 Grooves, 25mm Square, 1250nm NIR Ruled Grating

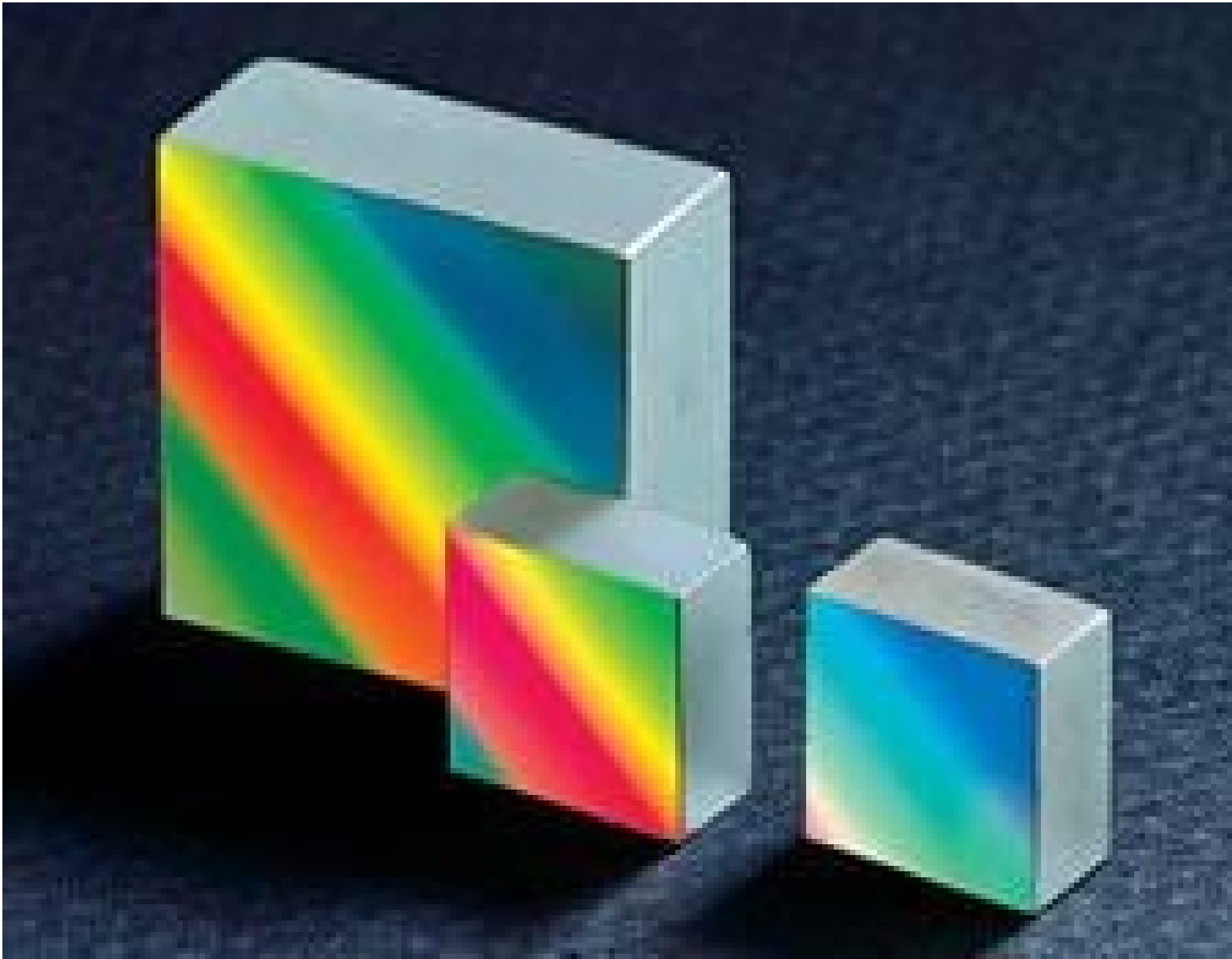

Stock #46-080 10 TO 12 DAYS

-

1

+

₹13,920.00

ADD TO CART

Qty 1+
₹13,920.00

Volume Pricing
Request Quote

Get Product Downloads



Groove Density (grooves/mm):
830

Wavelength Range (nm):
700 - 3000

Blaze Wavelength (nm):
1200

Blaze Angle (°):
29.87

Dimensions (mm):

25.0 x 25.0 ±0.5
Clear Aperture (%) : 90
Coating: Bare Gold
Construction: Ruled Grating
Direction of Grooves: Parallel to Short Dimension
Length (mm): 25.00
Substrate:  Float Glass
Thickness (mm): 9.50 ±0.5
Type: Reflective Diffraction Grating
Width (mm): 25.00
Alignment of Grooves to Edge (°): ±0.5

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View