 



Hoya B460 (UV-VIS) 25.4mm Dia., Colored Glass Bandpass Filter

See More by [Hoya](#)



Stock **#34-445** 10 TO 12 DAYS

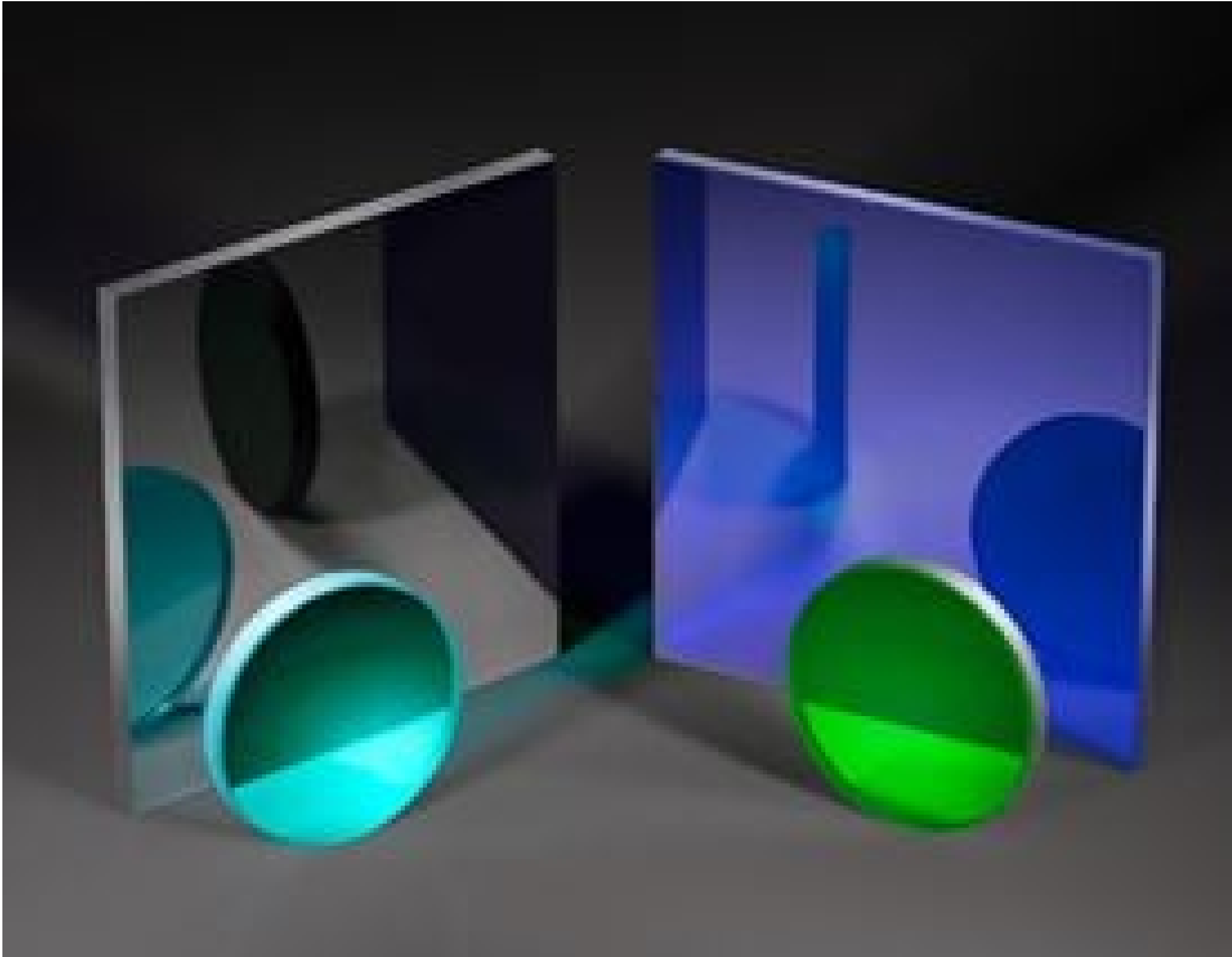

1



₹5,481.00

ADD TO CART

Qty 1-10

₹5,481.00

Qty 11+

₹4,872.00

Volume Pricing

[Request Quote](#)

Get Product Downloads



Diameter (mm):
25.40

Center Wavelength CWL (nm):
460.00

Density (g/cm³): 2.60
Full Width-Half Max FWHM (nm): 200.00
Glass/Filter Number: Hoya B460
Substrate: ☐ Colored Glass
Coating: Uncoated
Color: Blue-Green
Surface Quality: 80-50
Thickness (mm): 2.50
Thickness Tolerance (mm): ±0.2
Type: Bandpass Filter
Wavelength: UV-Vis
Parallelism (arcmin): ≤1
Dimensional Tolerance (mm): +0/-0.25

Regulatory Compliance

RoHS 2015: Exempt
Reach 224: Compliant
Certificate of Conformance: View