


Blue, 0.315" LED Spot Light

See More by [Advanced Illumination](#)

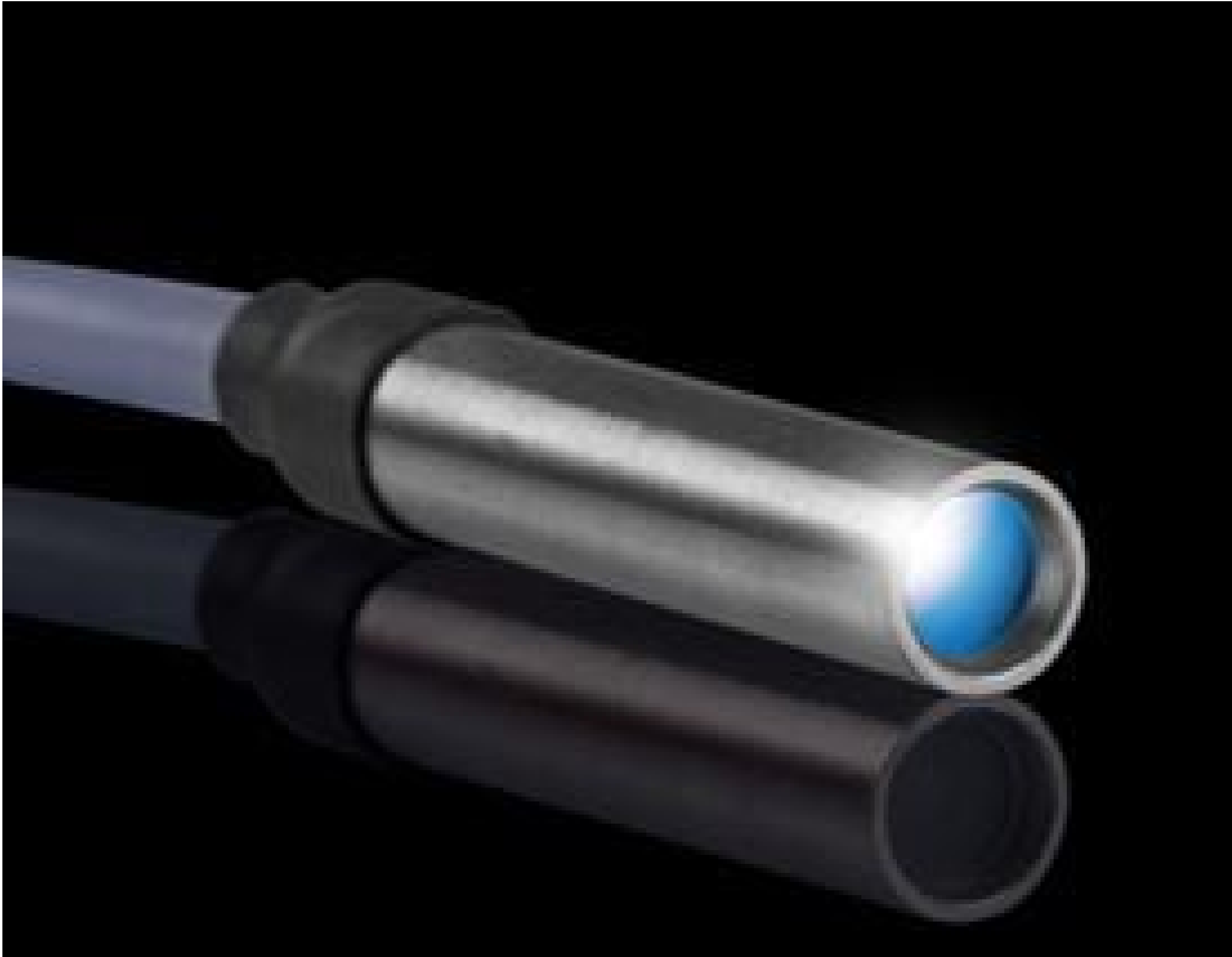

Stock #87-542 10 TO 12 DAYS

-

1

+

₹16,704.00

ADD TO CART

Qty 1+
₹16,704.00

Volume Pricing
Request Quote

Note: This item requires accessories for use | [Learn More](#)

Get Product Downloads

Color: Blue
Diameter (mm): 7.90
Fiber Bundle Diameter (inches): ¼
Model Number: SL-4301A-470-IC

Length (mm): 38.10
Outer Diameter (inches): 0.312
Wavelength (nm): 470.00
LED Lifetime (hours): 50,000
Power Supply: Power Supply Required and Sold Separately. USA: #66-855 Europe: #66-855 Japan: #66-855 Korea: #33-773 China: #66-855
Length of Cable (m): 1.5
Type of Illumination: LED Illuminator
Manufacturer: Advanced Illumination
Geometry: Spot Light
Illumination Mode: Constant

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Contains SVHC(s)