

[See all 12 Products in Family](#)

Flea®3 FL3-U3-13E4C-C 1/1.8" Color USB 3.0 Camera

See More by [Teledyne FLIR](#)



Stock **#87-432** **4 In Stock**

-

1

+

MRP ₹95,580

 Price inclusive of all taxes

ADD TO CART

Volume Pricing	
Qty 1+	₹95,580 each
Need More?	Request Quote

Note: This item requires accessories for use | [Learn More](#)

Product Downloads

Color	Spectrum:
General	
Color Camera	Type:
	Model Number:

FL3-U3-13E4C-C	
FLIR	Manufacturer:
Flea@3	Camera Series:
Physical & Mechanical Properties	
29 x 29 x 30 (excludes connectors and lens mount)	Dimensions (mm):
41	Weight (g):
Full	Housing:
Sensor	
32MB	Image Buffer:
1/1.8"	Sensor Format:
1.30	Resolution (Megapixels):
60.00	Frame Rate (fps):
1,280 x 1,024	Pixels (H x V):
5.3 x 5.3	Pixel Size, H x V (µm):
6.78 x 5.43	Sensing Area, H x V (mm):
e2v EV76C560	Imaging Sensor:
Progressive Scan CMOS	Type of Sensor:
Global	Shutter Type:
10 bit	Pixel Depth:
16µs - 1s	Exposure Time:
46.61	Dynamic Range (dB):
USB3 Vision v1.0	Machine Vision Standard:
Electrical	
<3	Power Consumption (W):
Hardware & Interface Connectivity	
USB 3.0	Interface:
USB 3.0, Micro-B with Screw Locks	Connector:
Power over USB or via GPIO with #86-784	Power Supply:
1 opto-isolated input, 2 opto-isolated outputs, 2 non-isolated bi-directional ports	GPIOs:
Hardware Trigger (GPIO) or Software Trigger	Synchronization:
Back Panel	Interface Port Orientation:
8-pin Hirose (HR25)	GPIO Connector Type:
5.00	Transfer Speed (Gbit/s):
Threading & Mounting	
C-Mount	Mount:
1/4-20 with Tripod Mount Adapter #88-210	Mounting Threads:
Environmental & Durability Factors	
	Operating Temperature (°C):

0 to +45	
	Storage Temperature (°C):
-30 to +60	

Regulatory Compliance

Exempt	RoHS 2015:
View	Certificate of Conformance:

Contains SVHC(s)

Reach 240:

Canada	Country of Origin:
Edmund Optics India Private Limited 267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038 Phone: +91- 80-6845 0000	Imported By:

Product Details

USB 3.0 cable (#86-770) is required for operation. Software available for [download](#).


- Compact 29 x 29 x 30mm Design
- Captures Images at up to 150fps
- Image Capture Software and 1/4-20 Tripod Adapter are Included
- [GigE Models](#) Also Available




FLIR Flea®3 USB 3.0 Cameras are ideal for applications requiring low-cost, high-speed cameras with compact designs. The use of USB 3.0 provides transfer rates of up to 5Gbits/s. To ease integration, image capture software is included for optional download. FLIR Flea®3 USB 3.0 Cameras are capable of capturing images at up to 150fps at 1.3MP resolution. The compact 29 x 29 x 30mm cameras are offered in monochrome or color.

Note: USB 3.0 cable (#86-770) is required for operation. Software available for [download](#). FLIR was previously known as Point Grey.

Technical Information

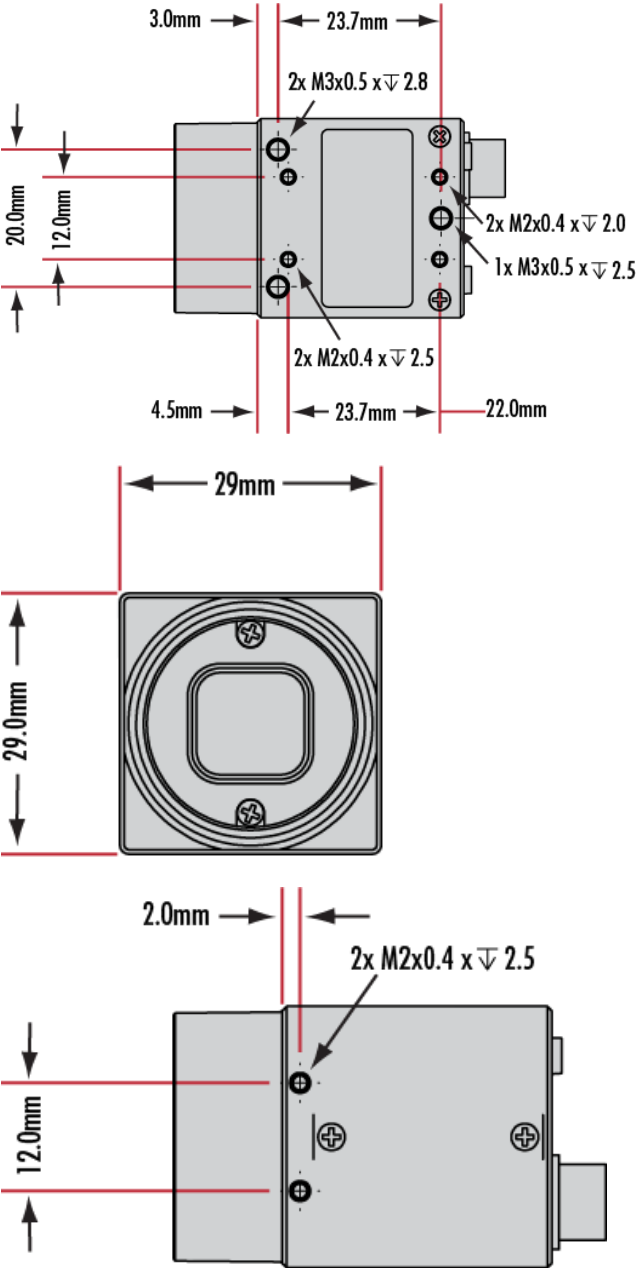

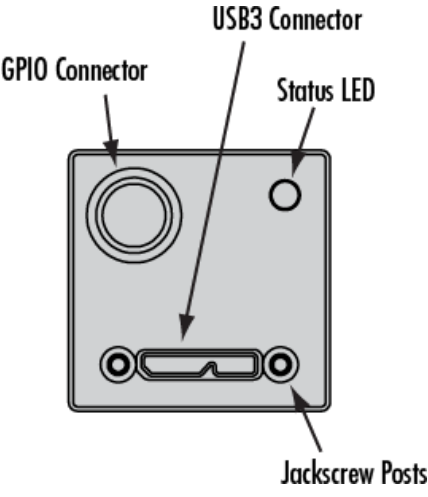

;