


Glan-Thompson Polarizer 350 - 2200nm, 10mm

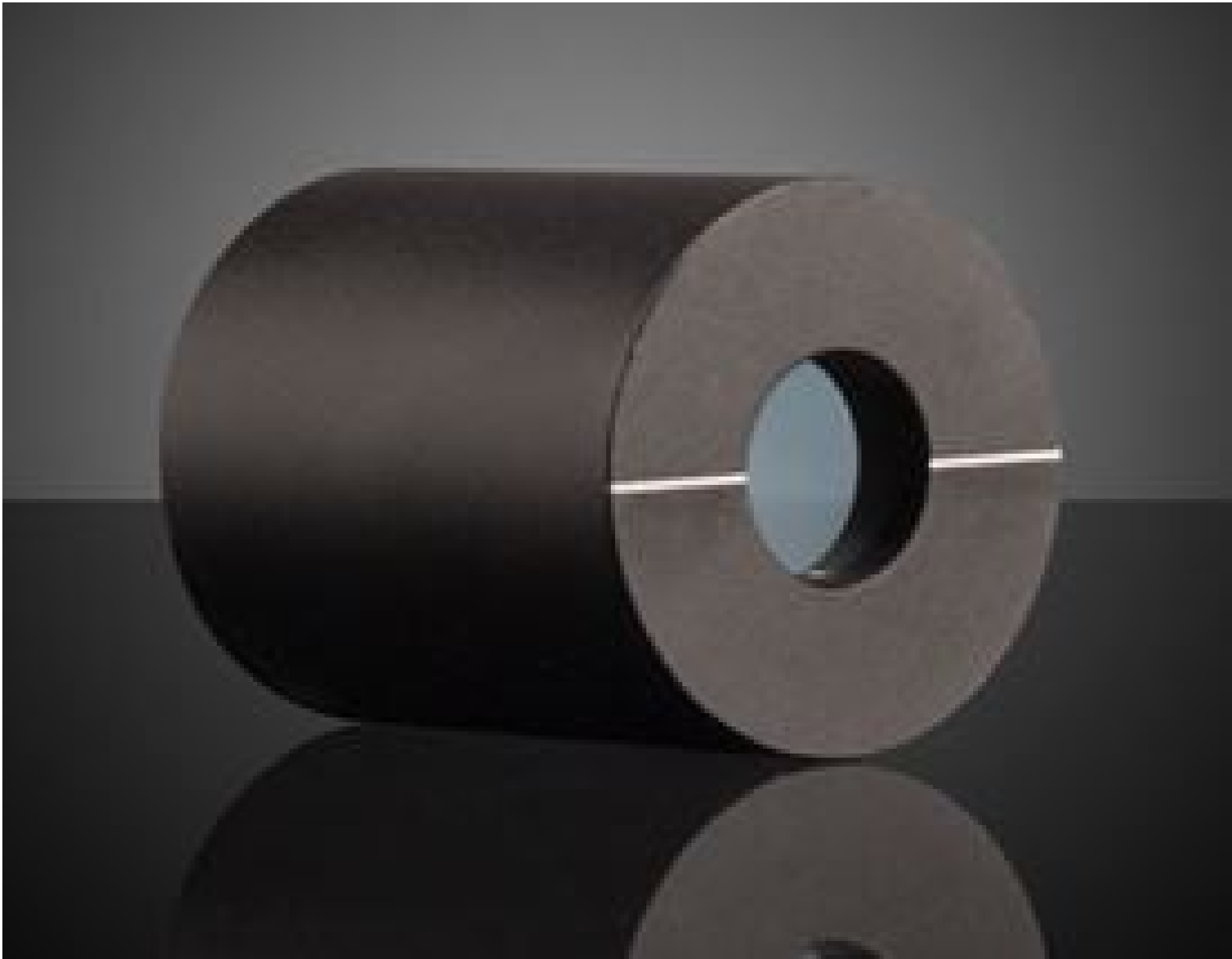

Glan-Thompson Polarizer

Stock **#89-545** [CONTACT US](#)



1



₹71,340.00

ADD TO CART

Qty 1-5
₹71,340.00
Qty 6+
₹67,860.00
Volume Pricing
Request Quote

Get Product Downloads

Clear Aperture CA (mm): 10.0
Coating: Single Layer MgF ₂
Diameter (mm): 25.40
Extinction Ratio:

<5 x 10 ⁻⁵
Substrate:  Calcite
Length (mm): 33.00
Surface Quality: 20-10
Type: Linear Polarizer
Construction: Crystalline Glan-Thompson Polarizer
Transmitted Wavefront, P-V: $\lambda/2$ @ 632.8nm
Beam Deviation (arcmin): <3
Transmitted Wavefront Distortion (RMS): $\lambda/4$ @ 632.8 nm
Wavelength Range (nm): 350 - 2200
Damage Threshold, By Design:  1 J/cm ² @ 1064nm, 10ns, 10Hz

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant