 



Hoya B390 (UV-VIS) 50.8mm Square, 1mm Thick, Colored Glass Bandpass Filter

See More by [Hoya](#)



Stock **#18-785** 10 TO 12 DAYS

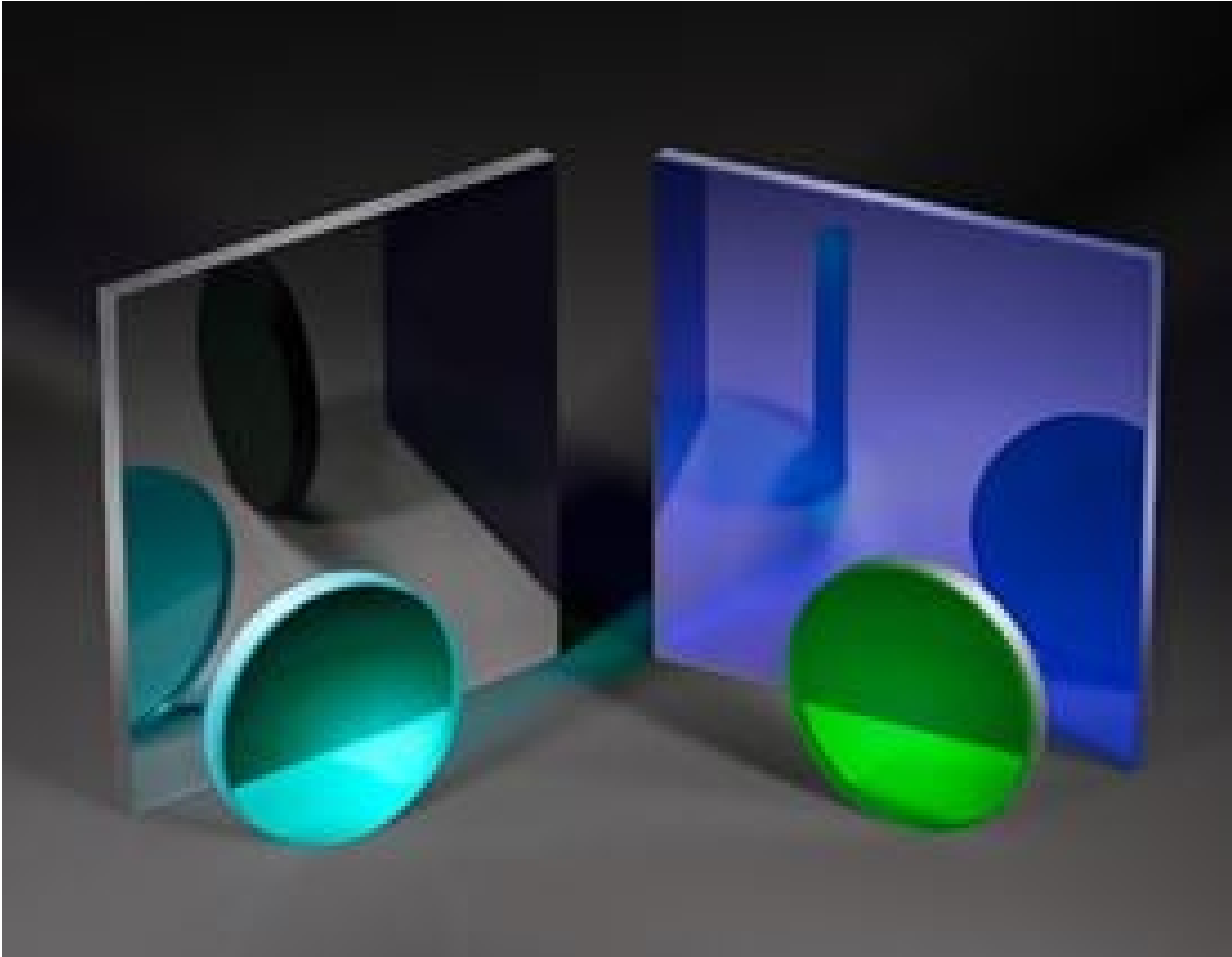

1



₹9,396.00

ADD TO CART

Qty 1-10

₹9,396.00

Qty 11+

₹8,352.00

Volume Pricing

[Request Quote](#)

Get Product Downloads



Dimensions (mm):
50.80 x 50.80

Center Wavelength CWL (nm):
390.00

Density (g/cm³): 2.57
Full Width-Half Max FWHM (nm): 125.00
Glass/Filter Number: Hoya B390
Substrate: ☐ Colored Glass
Coating: Uncoated
Color: Blue-Violet
Surface Quality: 60-40
Thickness (mm): 1.00
Thickness Tolerance (mm): ±0.1
Type: Bandpass Filter
Wavelength: UV-Vis
Parallelism (arcmin): ≤2
Dimensional Tolerance (mm): ±0.2

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View