

[See all 25 Products in Family](#)

## Iris Mount for 14.8mm Outer Diameter Irises



Iris Mount for 70mm Outer Diameter Irises, #53-921



Stock #23-120 [CONTACT US](#)

- 1 + MRP ₹5,146

Price inclusive of all taxes

**ADD TO CART**

### Volume Pricing

Qty 1-4	₹5,146 each
Qty 5-9	₹4,641 each
Qty 10-25	₹4,187 each
Need More?	<a href="#">Request Quote</a>

### Product Downloads

### Physical & Mechanical Properties

Compatible Iris Diameter (mm):  
14.8

Outer Diameter (mm):  
39.0

Thickness (mm):

6.00

Optical Axis Height (mm):

12.70

## Threading & Mounting

Mounting Threads:

M4 x0.7 and 8-32

Set Screw Thread:

4-40

## Regulatory Compliance

RoHS 2015:

Compliant

Certificate of Conformance:

[View](#)

Reach 235:

Compliant

Country of Origin:

China

Imported By:


Edmund Optics India Private Limited  
267, Greystone Building, Second Floor,  
6th Cross Rd, Binnamangala,  
Stage 1, Indiranagar, Bengaluru,  
Karnataka, India 560038  
Phone: +91- 80-6845 0000

## Product Details

- Multiple Iris Diameter Options Available
- Durable Anodized Aluminum Construction
- Set Screw Included

Iris Diaphragm Mounts fit our most popular sizes of [Iris Diaphragms](#) and are constructed from durable black anodized aluminum. These mounts feature a variety of different English post mounting options, and each utilize an included set screw to ensure a secure fit.

## Technical Information

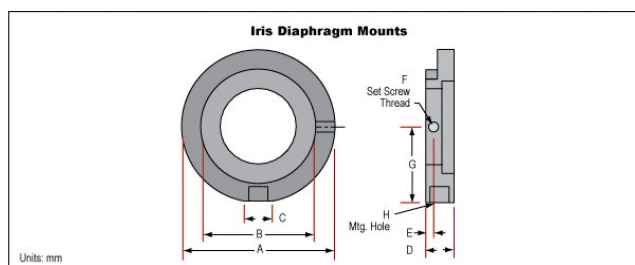

Iris Diameter	A	B	C	D	E	F	G	H	Stock No.
19.8	30.8	19.8	6.1	6.35	2.5	4-40	15.1	8-32	<a href="#">#53-918</a>
37.0	50.8	37.0	9.0	9.5	2.8	6-32	25.0	1/4-20	<a href="#">#53-919</a>
53.0	66.0	53.0	9.9	9.5	3.0	6-32	32.7	1/4-20	<a href="#">#53-920</a>
70.0	86.0	70.0	10.1	9.5	3.8	6-32	42.7	1/4-20	<a href="#">#53-921</a>
21.0	32.0	21.0	6.2	9.5	3.2	4-40	15.7	8-32	<a href="#">#54-862</a>
38.0	52.0	38.0	9.1	9.5	3.2	6-32	25.6	1/4-20	<a href="#">#54-863</a>
54.0	67.0	54.0	8.9	9.5	3.8	6-32	33.2	1/4-20	<a href="#">#54-864</a>
72.0	88.0	72.0	10.3	11.5	3.8	6-32	43.7	1/4-20	<a href="#">#54-865</a>

