


[See all 13 Products in Family](#)

Lumenera INFINITY 8-8M Microscopy Monochrome Camera

See More by [Teledyne Lumenera](#)

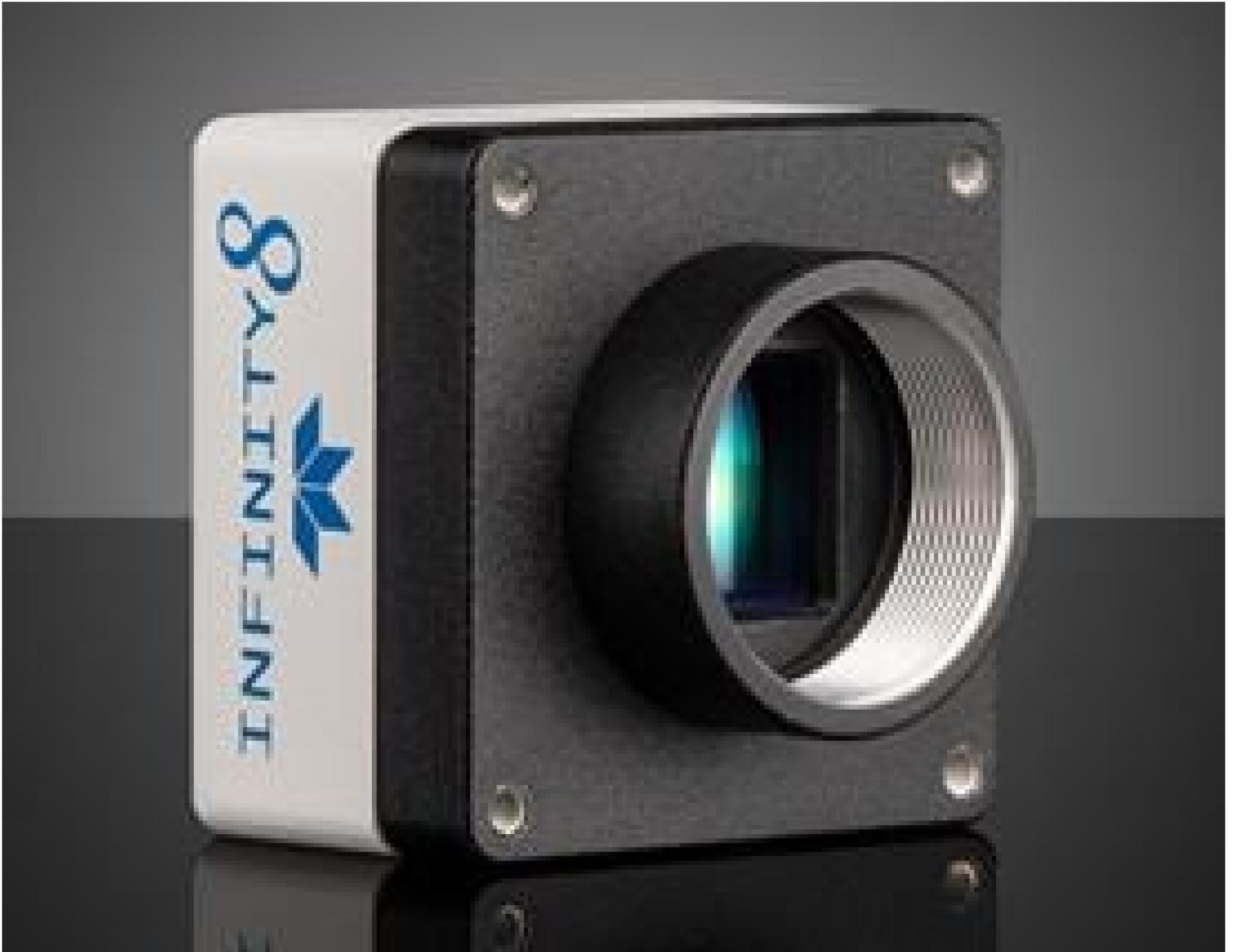

Stock #25-354 **1 In Stock**

- 1 + MRP ₹1,91,160

i Price inclusive of all taxes

ADD TO CART

Volume Pricing	
Qty 1+	₹1,91,160 each
Need More?	Request Quote

Product Downloads

Monochrome

Spectrum:

General

Monochrome Microscopy Camera

Type:

i8-LM00-08M

Model Number:

Manufacturer:

Teledyne Lumenera

INFINITY Camera Series:

Physical & Mechanical Properties

Dimensions (mm):
38.5 x 45 x 45 (includes lens mount)

Weight (g):
108

Housing:
Full

Sensor

Image Buffer:
128MB

Sensor Format:
1/1.8"

Resolution (Megapixels):
8.30

Frame Rate (fps):
44.00

Pixels (H x V):
3,840 x 2,160

Pixel Size, H x V (µm):
2.00 x 2.00

Sensing Area, H x V (mm):
7.68 x 4.32

Imaging Sensor:
Sony IMX334

Type of Sensor:
Progressive Scan CMOS

Shutter Type:
Rolling

Pixel Depth:
8/12 bit

Dynamic Range (dB):
73

Electrical

Power Consumption (W):
2.3 - 3.6

Hardware & Interface Connectivity

Interface:
USB 3.1

Power Supply:
Power over USB

GPIOs:
Not Specified

Synchronization:
Hardware Trigger (GPIO)

Interface Port Orientation:
Side Panel

GPIO Connector Type:
9-pin Hirose (JST)

Threading & Mounting

Mount:
C-Mount

Mounting Threads:
M3x0.5 (Integrated into Housing)

Environmental & Durability Factors

Operating Temperature (°C):
0 to +50

Storage Temperature (°C):
-30 to +70

Regulatory Compliance

Certificate of Conformance:
[View](#)

Country of Origin:
Canada

Imported By:
Edmund Optics India Private Limited

Product Details

- Exceptional Low Light Sensitivity
- Ideal for Life Sciences, Clinical, and Industrial Applications
- Affordable Price Point with Included Microscopy Software



Teledyne
Authorized
Distributor

Teledyne Lumenera INFINITY8 Microscopy Cameras offer an affordable solution for low light imaging in a compact form factor. Featuring low noise and large pixels, these cameras are ideal for a wide range of lighting conditions including the low light levels common in fluorescence imaging. Available with 1/1.8", 2/3", and 1" sensor sizes and megapixel range of 2 – 20 MP, each camera is compatible with Windows and Mac operating systems. Teledyne Lumenera INFINITY8 Microscopy Cameras include an INFINITY ANALYZE 7 software license, for camera operation and immediate analysis of the imaging results, and 3m Micro-B to Type-A USB cable.
