


TECHSPEC® Mounting Clamp, 180mm Bolt Circle Diameter

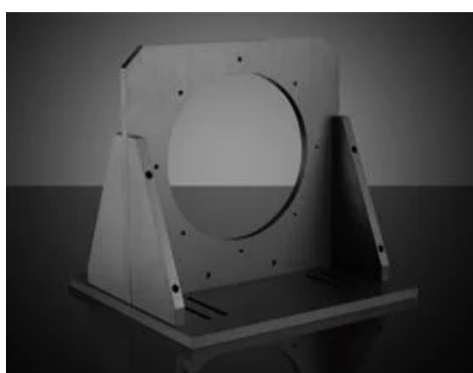

Stock #28-640 [CONTACT US](#)

1

MRP ₹1,00,890

Price inclusive of all taxes

[ADD TO CART](#)

Image shows 28-641



Volume Pricing

Qty	₹1,00,890
1+	each

Need More? [Request Quote](#)

Product Downloads

[STEP:step](#) [PDF Drawing:pdf](#)

[IGES:igs](#) [eDrawing:eprt](#)

[Download All](#)

General

Note: Includes mounting hardware and ball drivers

Physical & Mechanical Properties

Inner Diameter (mm): 180

Construction: Black Anodized Aluminum

Centerline Height (mm): 150

Regulatory Compliance

Certificate of Conformance: [View](#)

Country of Origin: China

Imported By: Edmund Optics India Private Limited
267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: +91-80-6845 0000

Product Details

- Large Field of View Telecentric Lens
- Up to 31.4 MegaPixels, 3.45µm Pixel Size Sensors
- Full Frame (35mm), C-Mount, T-Mount, M58-Mount, F-Mount Telecentric Lens
- Magnification from 0.037X to 0.377X

TECHSPEC® TitanTL® Telecentric Lenses are designed for machine vision systems and metrology applications that require a large field of view. These lenses feature large maximum sensor formats, a variety of working distance and magnification options, and a rear filter holder on the back of the lenses to allow for easy filter integration. On our 118mm, 182mm and 242mm FOV versions, the integrated mounting flange allows for ease of securing each lens without requiring an additional mount and provides an easy to locate reference plane. TECHSPEC® TitanTL® Telecentric Lenses contain shims that provide adjustment for variation in camera sensor location, an adjustable iris and a 3 set screw lens mount for simple rotational alignment to the camera. Typical applications include automotive and electronic inspection, measurement and gauging applications.

Note: Detailed inspection reports included with each lens.

Technical Information

Accessories

Note: Compatible accessories for individual stock numbers may vary. If unsure about which accessories work with your products, please contact us [here](#).

	Title	Compare	Stock Number	Price	Buy
MORE+	Mounting Clamp, 79mm Inner Diameter		#56-026	₹26,656 Request Quote	3 In Stock <input type="text" value="1"/>
MORE+	Mounting Clamp, 180mm Bolt Circle Diameter		#28-640	₹1,00,890 Request Quote	CONTACT US <input type="text" value="1"/>
MORE+	Mounting Clamp, 240mm Bolt Circle Diameter		#28-641	₹1,26,378 Request Quote	CONTACT US <input type="text" value="1"/>
MORE+	Mounting Clamp, 280mm Bolt Circle Diameter		#28-642	₹1,65,141 Request Quote	1 In Stock <input type="text" value="1"/>

Frequently Purchased Together



#34-016 - 0.191X, 4/3" C-Mount TitanTL® Telecentric Lens

₹4,07,960



#46-053 - SCHOTT VG9, 25.4mm Dia., 3mm Thick, Colored Glass Bandpass Filter

₹6,457



#54-998 - 80mm Sq., Fixed Filter Holder

₹12,208



#34-006 - 0.093X, 2/3" C-Mount TitanTL® Telecentric Lens

₹3,48,639

Resources

Media Type

- Application Note
- Video
- FAQ
- Glossary
- Published Article
- Technical Tool

APPLICATION NOTE
Anti-Reflection (AR) Coatings

APPLICATION NOTE
An Introduction to Optical Coatings

VIDEO
Wavelength and f#

APPLICATION NOTE
Understanding Focal Length and Field of View

APPLICATION NOTE
Introduction to Modulation Transfer Function

VIDEO
Edmund Optics Imaging: Telecentric...

[View More](#)