


[See all 3 Products in Family](#)

## OD 0.04 - 1.0, 50.8 x 25.4mm Stepped ND Filter

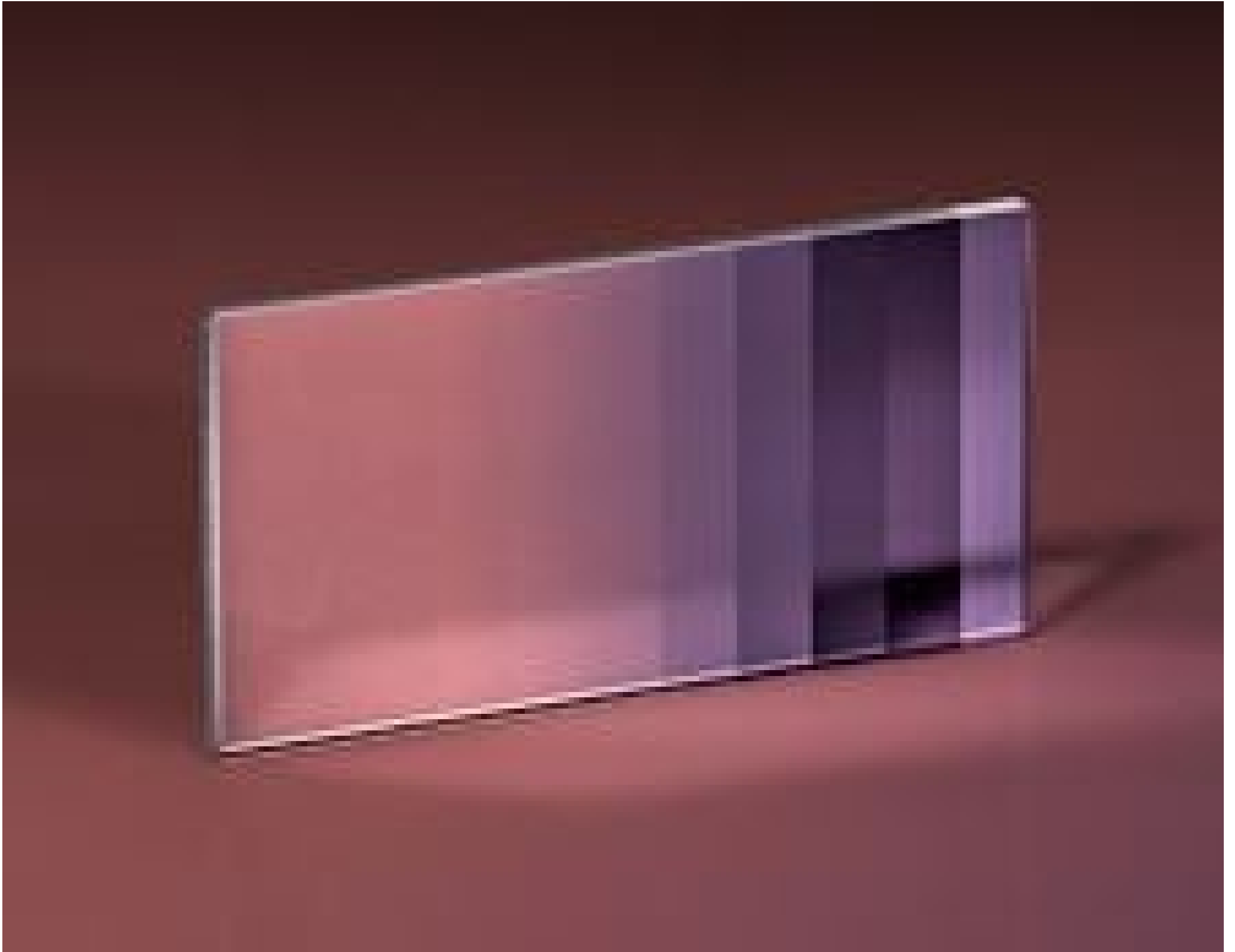

Stock #32-599 **1 In Stock**

1  MRP ₹21,692

 Price inclusive of all taxes

**ADD TO CART**

Volume Pricing	
Qty 1-10	₹21,692 each
Qty 11-25	₹19,573 each
Qty 26-49	₹18,665 each
Need More?	<a href="#">Request Quote</a>

### Product Downloads

#### General

Neutral Density Filter **Type:**

#### Physical & Mechanical Properties

25.4 x 50.8 **Dimensions (mm):**

2.0 **Length (inches):**

50.80 **Length (mm):**

0.062 **Thickness (inches):**

1.0 **Width (inches):**

25.40 **Width (mm):**

## Optical Properties

0.04 - 1.0 **Optical Density OD (Average):**

Float Glass **Substrate:**

Stepped Variable **Coating:**

400 - 700 **Blocking Wavelength Range (nm):**

## Regulatory Compliance

[Compliant](#) **Reach 181:**

[Compliant](#) **RoHS 2015:**

[View](#) **Certificate of Conformance:**

United States **Country of Origin:**


**Imported By:**  
Edmund Optics India Private Limited  
267, Greystone Building, Second Floor,  
6th Cross Rd, Binnamangala,  
Stage 1, Indiranagar, Bengaluru,  
Karnataka, India 560038  
Phone: +91- 80-6845 0000

## Product Details

- 11 Discrete Density Steps
- Design Wavelength of 400 - 700nm
- Density Neutrality of  $\pm 5\%$

Density and transmission vary in eleven equal steps across the surface length. The steps are abrupt changes and no light escapes between them. Spectrally flat neutral density coating. Ideal for applications requiring variable densities and known density values.

## Technical Information

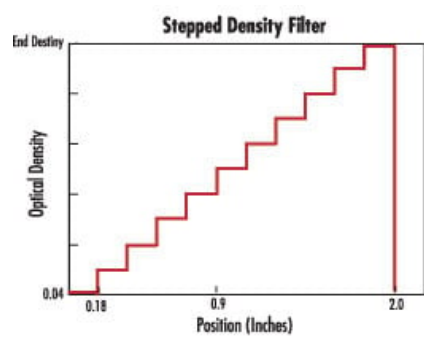

## Compatible Mounts