


[See all 3 Products in Family](#)

OD 0.04 - 1.0, 50.8 x 25.4mm Stepped ND Filter

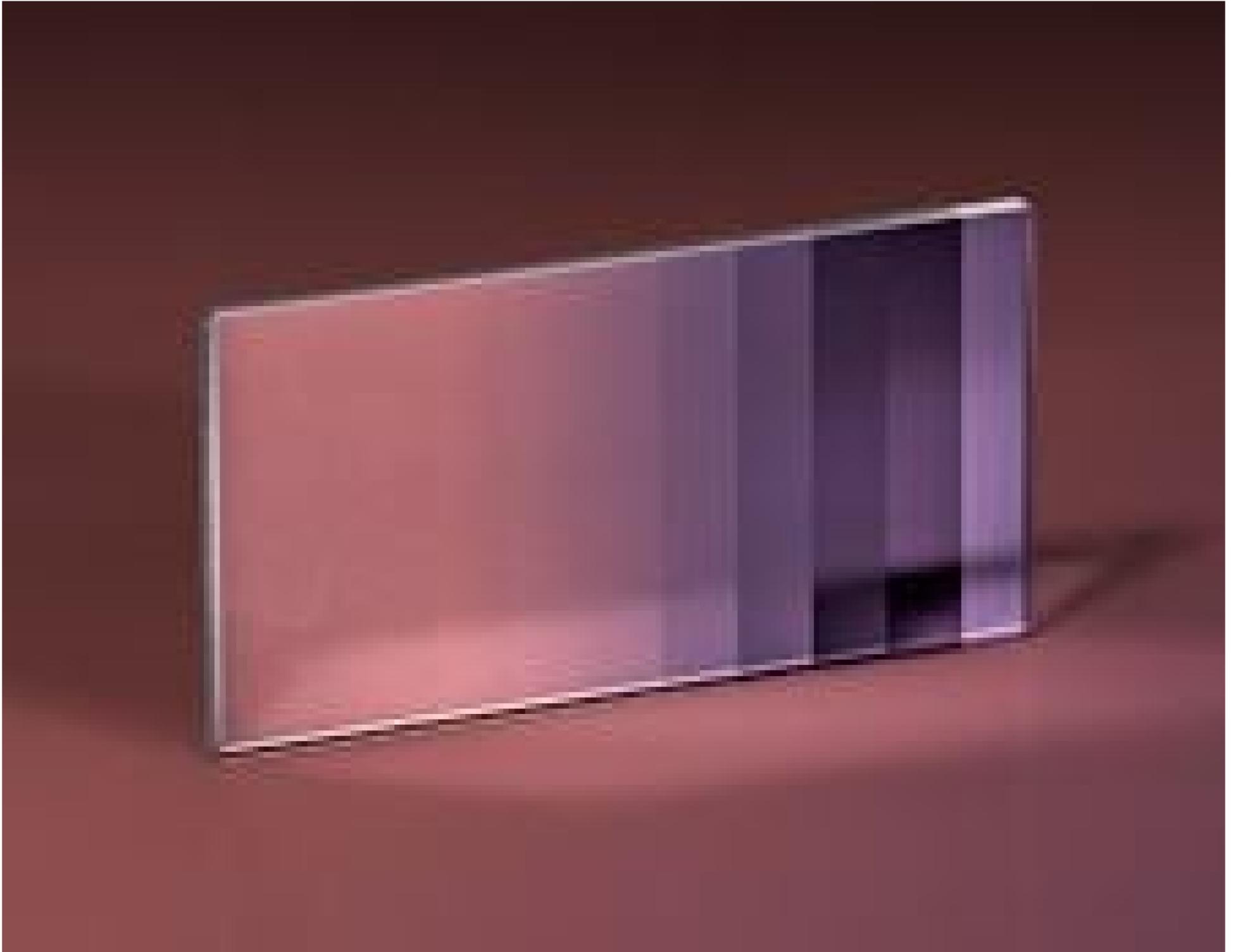

Stock #32-599 **2 In Stock**

- 1 + ₹15,336

ADD TO CART

Volume Pricing	
Qty 1-10	₹15,336 each
Qty 11-25	₹13,857 each
Qty 26-49	₹13,157 each
Need More?	Request Quote

Product Downloads

General

Neutral Density Filter **Type:**

Physical & Mechanical Properties

25.4 x 50.8 **Dimensions (mm):**

2.0 **Length (inches):**

50.80 **Length (mm):**

0.062 **Thickness (inches):**

1.0 **Width (inches):**

25.40 **Width (mm):**

Optical Properties

0.04 - 1.0 **Optical Density OD (Average):**

Float Glass **Substrate:**

Stepped Variable **Coating:**

400 - 700 **Blocking Wavelength Range (nm):**

Regulatory Compliance

Compliant **Reach 181:**

Compliant **RoHS 2015:**

View **Certificate of Conformance:**

United States **Country of Origin:**


Edmund Optics India Private Limited **Imported By:**

Product Details

- 11 Discrete Density Steps
- Design Wavelength of 400 - 700nm
- Density Neutrality of $\pm 5\%$

Density and transmission vary in eleven equal steps across the surface length. The steps are abrupt changes and no light escapes between them. Spectrally flat neutral density coating. Ideal for applications requiring variable densities and known density values.

Technical Information

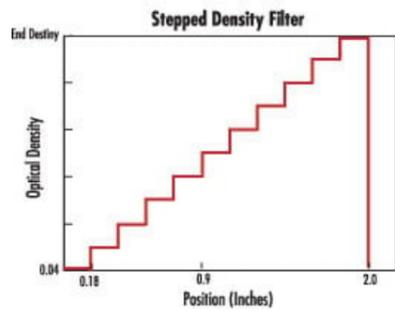

Compatible Mounts